

2-140-T Eclipse MR16



This refined trim facilitates versatile spotlighting from a diminutive aperture. Eclipse rotates, aims at max possible angles and admits full flux with an extremely shallow projection.

FEATURES

- Utilizes MR16
- 358° rotation
- 20° aiming
- Powder coated and plated trim ring finishes
- Accepts 1 media
- Clear glass lens included
- Trim clips designed for 5/8" ceiling thickness

DETAILS

Trim Class: 4"
Category: Recessed Downlight
Shape: Round
Adjustability: Aiming With Rotation




2-140-T-Eclipse-MR16-Specs • Subject to change without notice • Rev. 2017.01.23 • 1/4


Compatible Housings

NON-INSULATED

2-020
Round Non-Insulated
L 10 1/2" [267mm]
W 7 3/4" [197mm]
H 3 1/2" [90mm]

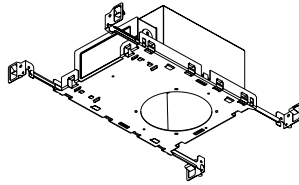


2-060
Round Non-Insulated
L 13 3/4" [349mm]
W 10 7/8" [276mm]
H 3 1/2" [90mm]

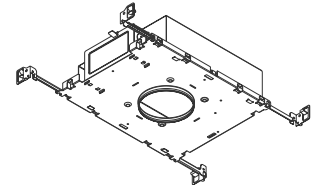


INSULATED

2-010
Round Insulated
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 7" [178mm]

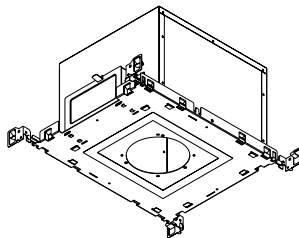


2-012
Round Insulated
L 22 1/2" [572mm]
W 8 1/2" [216mm]
H 5 7/8" [150mm]

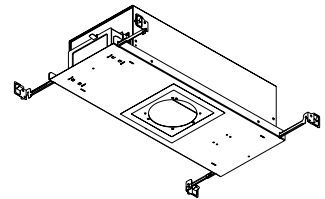


REMODEL

2-030
Round Remodel
L 14" [356mm]
W 4 1/2" [114mm]
H 5 1/8" [130mm]

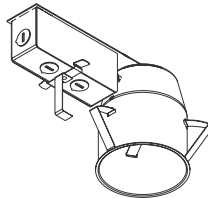


SPECIALIZED

2-060
Round Chicago Plenum
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 4 1/2" [115mm]

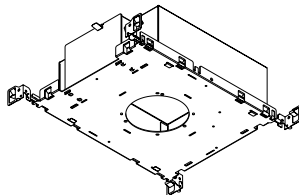

2-100
Round Concrete Housing
L 18" [457mm]
W 12" [305mm]
H 6" [152mm]

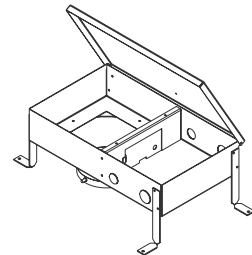

2-140-T-Eclipse-MR16-Specs • Subject to change without notice • Rev. 2017.01.23 • 3/4

2-140-T Eclipse MR16

Project

Type

Notes

Product Code

1 2 3 4

1. Trim

2-140-T Eclipse

2. Lamp

MR16 Halogen

3. Flange Finish

01 White

02 Chrome Plated

04 Black

05 Matte Silver

06 Bronze

CC Custom Color¹

4. Options

BC Black Center

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

2-140-T-Eclipse-MR16-Specs • Subject to change without notice • Rev. 2017.01.23 • 4/4
