

ML20S24DC DIFFUSION LED MAGNETIC DRIVER

DESCRIPTION


Diffusion ML20S24DC is a Magnetic Low Voltage, 24VDC Dimmable LED Driver

FEATURES

- * Nema 3R for Indoor/Outdoor use
- * Uses an assortment of dimmers including CFL/LED style
see dimmer compatibility list
- * Divider built into the enclosure so no need for a box
- * Standard 3/8" KO
- * Max load rated

SPECIFICATIONS

Input Voltage: 120V 60Hz
Max Input Current at full load: .22A
Output Voltage without load: 26VDC
Output Voltage: 23.5V DC
Max Wattage: 20W
Max Output Current: 0.8A
Efficiency: 83%
Load regulation: 0%
Ripple: 0%

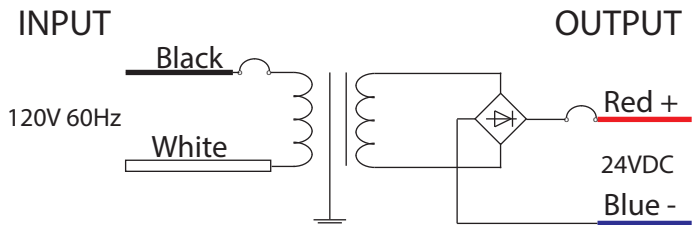

Project: _____
Type: _____
Date: _____
Part #: _____