

## ML10S24DC DIFFUSION LED MAGNETIC DRIVER

### DESCRIPTION


Diffusion ML10S24DC is a Magnetic Low Voltage, 24VDC Dimmable LED Driver

### FEATURES

- \* Nema 3R for Indoor/Outdoor use
- \* Uses an assortment of dimmers including CFL/LED style  
\*see dimmer compatibility list\*
- \* Divider built into the enclosure so no need for a box
- \* Standard 3/8" KO
- \* Max load rated

### SPECIFICATIONS

Input Voltage: 120V 60Hz  
 Max Input Current at full load: .11A  
 Output Voltage without load: 26VDC  
 Output Voltage: 24V DC  
 Max Wattage: 10W  
 Max Output Current: 0.4A  
 Efficiency: 83%  
 Load regulation: 0%  
 Ripple: 0%

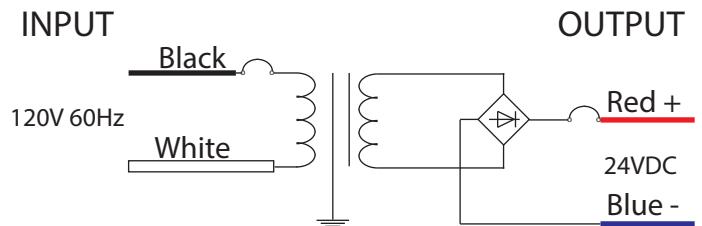

Project: \_\_\_\_\_  
 Type: \_\_\_\_\_  
 Date: \_\_\_\_\_  
 Part #: \_\_\_\_\_