

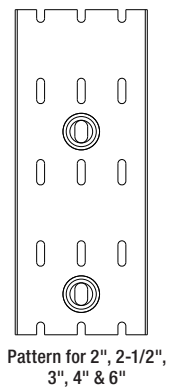
 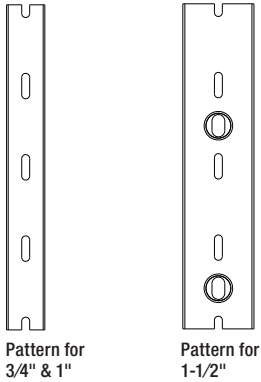


For a complete listing of solid wall dimensional details, see page B-4.

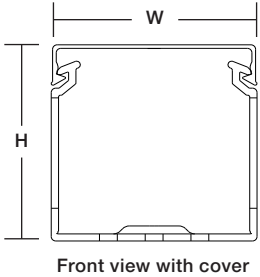

Bottom view



| Cat. no.         | Description (in.)          | Size (W x H) |               | Cover cat. no. | Duct std. ctn. qty. | Cover std. ctn. qty. | Length (ft.) |
|------------------|----------------------------|--------------|---------------|----------------|---------------------|----------------------|--------------|
|                  |                            | In.          | mm            |                |                     |                      |              |
| TYD75X1SP[ _ ]6  | 0.75 x 1 Solid wall duct   | 0.94 x 1.14  | 23.9 x 27.7   | TYD75CP[ _ ]6  | 120                 | 120                  | 6            |
| TYD75X15SP[ _ ]6 | 0.75 x 1.5 Solid wall duct | 0.94 x 1.60  | 23.9 x 39.6   |                |                     |                      |              |
| TYD75X2SP[ _ ]6  | 0.75 x 2 Solid wall duct   | 0.94 x 2.10  | 23.9 x 52.6   |                |                     |                      |              |
| TYD1X1SP[ _ ]6   | 1 x 1 Solid wall duct      | 1.25 x 1.14  | 31.8 x 27.7   | TYD1CP[ _ ]6   | 120                 | 120                  | 6            |
| TYD1X15SP[ _ ]6  | 1 x 1.5 Solid wall duct    | 1.25 x 1.60  | 31.8 x 39.9   |                |                     |                      |              |
| TYD1X2SP[ _ ]6   | 1 x 2 Solid wall duct      | 1.25 x 2.10  | 31.8 x 52.8   |                |                     |                      |              |
| TYD1X3SP[ _ ]6   | 1 x 3 Solid wall duct      | 1.25 x 3.05  | 31.8 x 77.7   |                |                     |                      |              |
| TYD1X4SP[ _ ]6   | 1 x 4 Solid wall duct      | 1.25 x 4.37  | 31.8 x 111.3  |                | 60                  |                      |              |
| TYD15X1SP[ _ ]6  | 1.5 x 1 Solid wall duct    | 1.75 x 1.14  | 44.5 x 27.7   | TYD15CP[ _ ]6  | 120                 | 120                  | 6            |
| TYD15X15SP[ _ ]6 | 1.5 x 1.5 Solid wall duct  | 1.75 x 1.60  | 44.5 x 39.9   |                |                     |                      |              |
| TYD15X2SP[ _ ]6  | 1.5 x 2 Solid wall duct    | 1.75 x 2.10  | 44.5 x 52.8   |                |                     |                      |              |
| TYD15X3SP[ _ ]6  | 1.5 x 3 Solid wall duct    | 1.75 x 3.05  | 44.5 x 77.7   |                |                     |                      |              |
| TYD15X4SP[ _ ]6  | 1.5 x 4 Solid wall duct    | 1.75 x 4.37  | 44.5 x 111.3  |                | 60                  |                      |              |
| TYD2X1SP[ _ ]6   | 2 x 1 Solid wall duct      | 2.25 x 1.24  | 57.2 x 28.4   | TYD2CP[ _ ]6   | 120                 | 120                  | 6            |
| TYD2X15SP[ _ ]6  | 2 x 1.5 Solid wall duct    | 2.25 x 1.70  | 57.2 x 40.4   |                |                     |                      |              |
| TYD2X2SP[ _ ]6   | 2 x 2 Solid wall duct      | 2.25 x 2.19  | 57.2 x 53.3   |                |                     |                      |              |
| TYD2X3SP[ _ ]6   | 2 x 3 Solid wall duct      | 2.25 x 3.14  | 57.2 x 78.2   |                | 60                  |                      |              |
| TYD2X4SP[ _ ]6   | 2 x 4 Solid wall duct      | 2.25 x 4.46  | 57.2 x 111.8  |                |                     |                      |              |
| TYD2X5SP[ _ ]6   | 2 x 5 Solid wall duct      | 2.25 x 5.15  | 57.2 x 129.3  |                |                     |                      |              |
| TYD25X2SP[ _ ]6  | 2.5 x 2 Solid wall duct    | 2.75 x 2.19  | 69.9 x 53.6   | TYD25CP[ _ ]6  | 120                 | 120                  | 6            |
| TYD25X3SP[ _ ]6  | 2.5 x 3 Solid wall duct    | 2.75 x 3.14  | 69.9 x 78.2   |                | 60                  |                      |              |
| TYD25X4SP[ _ ]6  | 2.5 x 4 Solid wall duct    | 2.75 x 4.46  | 69.9 x 111.8  |                |                     |                      |              |
| TYD3X1SP[ _ ]6   | 3 x 1 Solid wall duct      | 3.25 x 1.24  | 82.6 x 29.0   | TYD3CP[ _ ]6   | 120                 | 120                  | 6            |
| TYD3X2SP[ _ ]6   | 3 x 2 Solid wall duct      | 3.25 x 2.19  | 82.6 x 54.9   |                | 60                  |                      |              |
| TYD3X3SP[ _ ]6   | 3 x 3 Solid wall duct      | 3.25 x 3.14  | 82.6 x 79.8   |                |                     |                      |              |
| TYD3X4SP[ _ ]6   | 3 x 4 Solid wall duct      | 3.25 x 4.46  | 82.6 x 113.5  |                |                     |                      |              |
| TYD3X5SP[ _ ]6   | 3 x 5 Solid wall duct      | 3.25 x 5.15  | 82.6 x 130.6  |                |                     |                      |              |
| TYD4X15SP[ _ ]6  | 4 x 1.5 Solid wall duct    | 4.25 x 1.70  | 108.0 x 42.4  | TYD4CP[ _ ]6   | 60                  | 120                  | 6            |
| TYD4X2SP[ _ ]6   | 4 x 2 Solid wall duct      | 4.25 x 2.19  | 108.0 x 55.1  |                |                     |                      |              |
| TYD4X3SP[ _ ]6   | 4 x 3 Solid wall duct      | 4.25 x 3.14  | 108.0 x 80.0  |                |                     |                      |              |
| TYD4X4SP[ _ ]6   | 4 x 4 Solid wall duct      | 4.25 x 4.46  | 108.0 x 113.8 |                | 30                  |                      |              |
| TYD4X5SP[ _ ]6   | 4 x 5 Solid wall duct      | 4.25 x 5.15  | 108.0 x 130.8 |                |                     |                      |              |
| TYD6X4SP[ _ ]6   | 6 x 4 Solid wall duct      | 6.25 x 4.46  | 158.8 x 114.0 | TYD6CP[ _ ]6   | 30                  | 60                   | 6            |

[ ] = space for colour identifier:

- G = Grey
- W = White
- B = Black
- I = Intrinsic blue

- Standard lengths are 6 feet.
- + Catalogue number must be completed by adding suffix G for grey, W for white, I for intrinsic blue, B for black.
- Example: TYD75X1SPG6 is a 0.75" x 1" solid wall grey duct.
- To order duct without mounting holes, add suffix NM to catalogue number.
- Example: TYD75X1SPG6NM is a 0.75" x 1" solid wall grey duct with no mounting holes.
- To order adhesive-backed duct, add suffix A to catalogue number.
- Example: TYD75X1SPG6A is a 0.75" x 1" solid wall grey duct with adhesive backing. Shelf life for adhesive is 1 year.
- PVC vinyl duct is CSA certified, UL® Recognized and CE compliant.


## Wide slot wiring duct

A

# Greater sidewall rigidity with increased versatility.

## Wide slot wiring duct — PVC




- Wide fingers and slots increase rigidity and enable easier insertion of wiring bundles
- Non-slip cover does not slide easily and resists vibration
- Rounded edges keep hands and wires free of abrasion
- Dual score lines are designed to yield clean breakoffs at the base of the slot and the duct
- Cover attaches flush with sidewall for finished look
- Improved flush sidewall and cover style for greater wire capacity
- Constructed of flame-retardant PVC
- Integrated mounting holes — larger sizes include staggered holes for mounting flexibility (see page B-5 for illustration)
- Lead-free construction

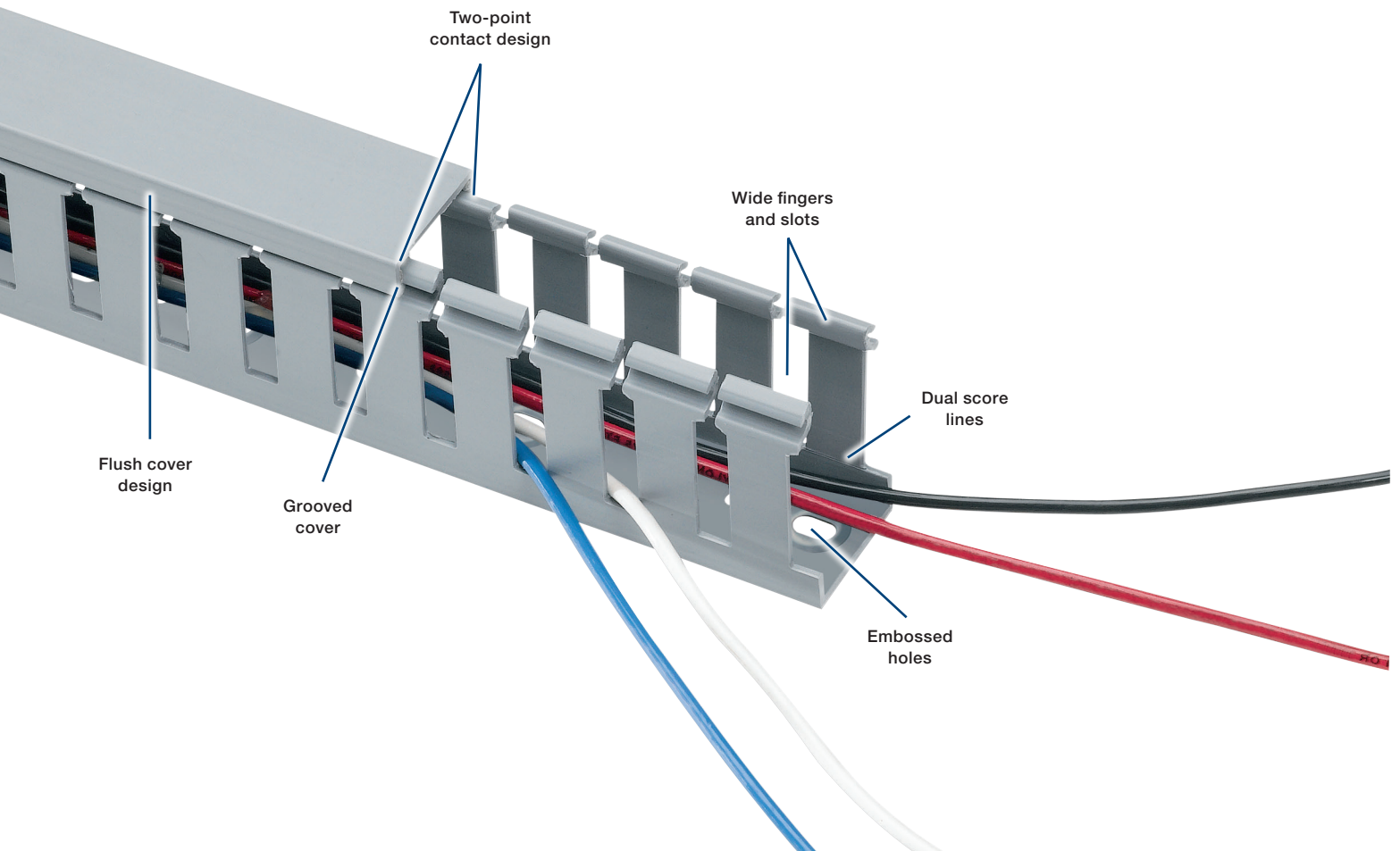


For a complete listing of wide slot dimensional details, see page B-5.



A

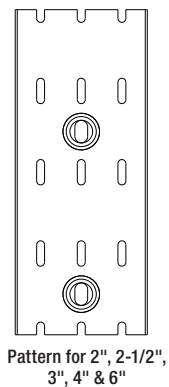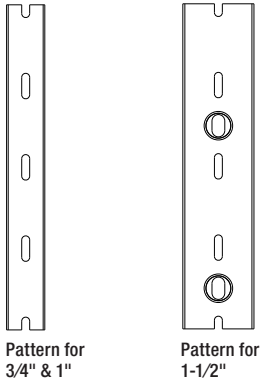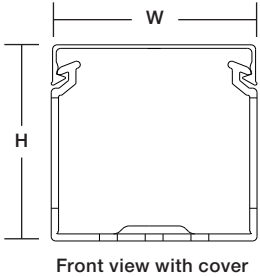

Bottom view

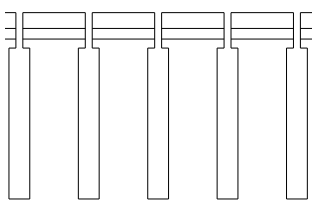

| Cat. no.         | Description (in.)         | Size (W x H) |               | Cover cat. no. | Duct std. ctn. qty. | Cover std. ctn. qty. | Length (ft.) |
|------------------|---------------------------|--------------|---------------|----------------|---------------------|----------------------|--------------|
|                  |                           | In.          | mm            |                |                     |                      |              |
| TYD75X1WP[ _ ]6  | 0.75 x 1 Wide slot duct   | 0.94 x 1.14  | 23.9 x 27.7   | TYD75CP[ _ ]6  | 120                 | 120                  | 6            |
| TYD75X15WP[ _ ]6 | 0.75 x 1.5 Wide slot duct | 0.94 x 1.60  | 23.9 x 39.6   |                |                     |                      |              |
| TYD75X2WP[ _ ]6  | 0.75 x 2 Wide slot duct   | 0.94 x 2.10  | 23.9 x 52.6   |                |                     |                      |              |
| TYD1X1WP[ _ ]6   | 1 x 1 Wide slot duct      | 1.25 x 1.14  | 31.8 x 27.7   | TYD1CP[ _ ]6   | 120                 | 120                  | 6            |
| TYD1X15WP[ _ ]6  | 1 x 1.5 Wide slot duct    | 1.25 x 1.60  | 31.8 x 39.9   |                |                     |                      |              |
| TYD1X2WP[ _ ]6   | 1 x 2 Wide slot duct      | 1.25 x 2.10  | 31.8 x 52.8   |                |                     |                      |              |
| TYD1X3WP[ _ ]6   | 1 x 3 Wide slot duct      | 1.25 x 3.05  | 31.8 x 77.7   |                |                     |                      |              |
| TYD1X4WP[ _ ]6   | 1 x 4 Wide slot duct      | 1.25 x 4.37  | 31.8 x 111.3  |                | 60                  |                      |              |
| TYD15X1WP[ _ ]6  | 1.5 x 1 Wide slot duct    | 1.75 x 1.14  | 44.5 x 27.7   | TYD15CP[ _ ]6  | 120                 | 120                  | 6            |
| TYD15X15WP[ _ ]6 | 1.5 x 1.5 Wide slot duct  | 1.75 x 1.60  | 44.5 x 39.9   |                |                     |                      |              |
| TYD15X2WP[ _ ]6  | 1.5 x 2 Wide slot duct    | 1.75 x 2.10  | 44.5 x 52.8   |                |                     |                      |              |
| TYD15X3WP[ _ ]6  | 1.5 x 3 Wide slot duct    | 1.75 x 3.05  | 44.5 x 77.7   |                |                     |                      |              |
| TYD15X4WP[ _ ]6  | 1.5 x 4 Wide slot duct    | 1.75 x 4.37  | 44.5 x 111.3  |                | 60                  |                      |              |
| TYD2X1WP[ _ ]6   | 2 x 1 Wide slot duct      | 2.25 x 1.24  | 57.2 x 28.4   | TYD2CP[ _ ]6   | 120                 | 120                  | 6            |
| TYD2X15WP[ _ ]6  | 2 x 1.5 Wide slot duct    | 2.25 x 1.70  | 57.2 x 40.4   |                |                     |                      |              |
| TYD2X2WP[ _ ]6   | 2 x 2 Wide slot duct      | 2.25 x 2.19  | 57.2 x 53.3   |                |                     |                      |              |
| TYD2X3WP[ _ ]6   | 2 x 3 Wide slot duct      | 2.25 x 3.14  | 57.2 x 78.2   |                | 60                  |                      |              |
| TYD2X4WP[ _ ]6   | 2 x 4 Wide slot duct      | 2.25 x 4.46  | 57.2 x 111.8  |                |                     |                      |              |
| TYD2X5WP[ _ ]6   | 2 x 5 Wide slot duct      | 2.25 x 5.15  | 57.2 x 129.3  |                |                     |                      |              |
| TYD25X2WP[ _ ]6  | 2.5 x 2 Wide slot duct    | 2.75 x 2.19  | 69.9 x 53.6   | TYD25CP[ _ ]6  | 120                 | 120                  | 6            |
| TYD25X3WP[ _ ]6  | 2.5 x 3 Wide slot duct    | 2.75 x 3.14  | 69.9 x 78.2   |                | 60                  |                      |              |
| TYD25X4WP[ _ ]6  | 2.5 x 4 Wide slot duct    | 2.75 x 4.46  | 69.9 x 111.8  |                |                     |                      |              |
| TYD3X1WP[ _ ]6   | 3 x 1 Wide slot duct      | 3.25 x 1.24  | 82.6 x 29.0   | TYD3CP[ _ ]6   | 120                 | 120                  | 6            |
| TYD3X2WP[ _ ]6   | 3 x 2 Wide slot duct      | 3.25 x 2.19  | 82.6 x 54.9   |                | 60                  |                      |              |
| TYD3X3WP[ _ ]6   | 3 x 3 Wide slot duct      | 3.25 x 3.14  | 82.6 x 79.8   |                |                     |                      |              |
| TYD3X4WP[ _ ]6   | 3 x 4 Wide slot duct      | 3.25 x 4.46  | 82.6 x 113.5  |                |                     |                      |              |
| TYD3X5WP[ _ ]6   | 3 x 5 Wide slot duct      | 3.25 x 5.15  | 82.6 x 130.6  |                |                     |                      |              |
| TYD4X15WP[ _ ]6  | 4 x 1.5 Wide slot duct    | 4.25 x 1.70  | 108.0 x 42.4  | TYD4CP[ _ ]6   | 60                  | 120                  | 6            |
| TYD4X2WP[ _ ]6   | 4 x 2 Wide slot duct      | 4.25 x 2.19  | 108.0 x 55.1  |                |                     |                      |              |
| TYD4X3WP[ _ ]6   | 4 x 3 Wide slot duct      | 4.25 x 3.14  | 108.0 x 80.0  |                |                     |                      |              |
| TYD4X4WP[ _ ]6   | 4 x 4 Wide slot duct      | 4.25 x 4.46  | 108.0 x 113.8 |                | 30                  |                      |              |
| TYD4X5WP[ _ ]6   | 4 x 5 Wide slot duct      | 4.25 x 5.15  | 108.0 x 130.8 |                |                     |                      |              |
| TYD6X4WP[ _ ]6   | 6 x 4 Wide slot duct      | 6.25 x 4.46  | 158.8 x 114.0 | TYD6CP[ _ ]6   | 30                  | 60                   | 6            |



= space for colour identifier:

G = Grey



W = White



B = Black



I = Intrinsic blue



• Standard lengths are 6 feet.

+ Catalogue number must be completed by adding suffix G for grey, W for white, I for intrinsic blue, B for black.

Example: TYD75X1WPG6 is a 0.75" x 1" wide slot grey duct.

To order duct without mounting holes, add suffix NM to catalogue number.

Example: TYD75X1WPG6NM is a 0.75" x 1" wide slot grey duct with no mounting holes.

To order adhesive-backed duct, add suffix A to Catalogue Number.

Example: TYD75X1WPG6A is a 0.75" x 1" wide slot grey duct with adhesive backing. Shelf life for adhesive is 1 year.

PVC vinyl duct is CSA certified, UL® Recognized and CE compliant.