

Basket Troffers

Avante




FEATURES

- Features optimum mix of directional and diffuse reflected light for balanced illumination
- Available in 2'x2' and 2'x4' symmetric distributions for general area lighting
- Injection-molded plastic light traps prevent light leaks between shielding and end plates
- Basket diffuser formed from round hole perforated steel and finished in matte white powder paint
- Matte-white polyester powder paint finished reflectors provide uniform light distribution

ORDERING INFORMATION

Catalog Number	UPC	Description	# of Lamps	Length	Wattage	# of Ballast	Voltage	Lamp Included	Pallet Qty	Standard Carton Qty	
2AV G 2 17 MDR MVOLT GEB10IS	745972199269	2x2 Recessed Direct/Indirect	2	24"	17	1	120 - 277	N	28	1	
2AV G 2 32 MDR MVOLT GEB10IS	784231145494	2x4 Recessed Direct/Indirect	2	48"	32	1	120 - 277	N	14	1	
2AV G 2 CF40 MDR MVOLT GEB10RS	784231145524	2x2 Recessed Direct/Indirect	2	24"	40	1	120 - 277	N	28	1	
AVSM 2 32 MDR DLS MVOLT GEB10IS	784231164211	1x4 Surface or Suspended, Direct/Indirect	2	48"	32	1	120 - 277	N	21	1	
2AV G 3 17 MDR MVOLT GEB10IS	745972189413	2x2 Recessed Direct/Indirect	3	24"	17	2	120 - 277	N	28	1	
2AV G 3 32 MDR MVOLT 1/3 GEB10IS	784231145517	2x4 Recessed Direct/Indirect	3	48"	32	1	120 - 277	N	14	1	
2AV G 3 32 MDR MVOLT GEB10IS	784231145500	2x4 Recessed Direct/Indirect	3	48"	32	2	120 - 277	N	14	1	

DIMENSIONS

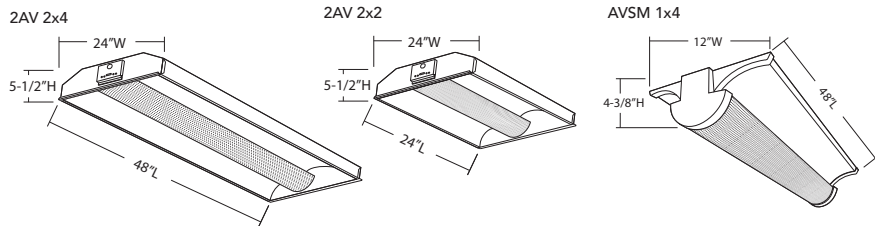

Certain airborne contaminants can diminish integrity of acrylic. See pg.156 for Acrylic Compatibility table for suitable uses.

Lensed Troffers

2GT8




FEATURES

- Recessed lensed fixture for grid T-bar ceilings
- Low-profile design ideal for restricted plenum applications
- Smooth hemmed sides and smooth ends promote easy handling during installation
- Standard steel door frame has superior structural integrity with premium extruded appearance and mitered corners
- 100% acrylic lens with prism pattern

ORDERING INFORMATION

Catalog Number	UPC	Description	# of Lamps	Wattage	# of Ballast	Voltage	Pre-Wired	Lamp Included	Lamp Type	Standard Carton Qty.	
2GT8 2 32 A12 MVOLT GEB10IS	784231155004	2x4 Recessed Troffer	2	32	1	120 - 277	N	N	-	28	1
GT8 2 32 A12 MVOLT GEB10IS	784231179116	1x4 Recessed Troffer	2	32	1	120 - 277	N	N	-	40	1
GT8 F 2 32 A12 MVOLT GEB10IS	784231179154	1x4 Recessed Troffer, Flanged	2	32	1	120 - 277	N	N	-	14	1
2GT8 3 32 A12 MVOLT GEB10IS	784231159330	2x4 Recessed Troffer	3	32	2	120 - 277	N	N	-	28	1
2GT8 3 32 A12 MVOLT 1/3 GEB10IS	784231139479	2x4 Recessed Troffer	3	32	1	120 - 277	N	N	-	28	1
2GT8 3 32 A12 MVOLT 1/3 GEB10IS LP735	784231163891	2x4 Recessed Troffer	3	32	1	120 - 277	N	Y	700 series, 3500K	28	1
2GT8 3 32 A12 MVOLT 1/3 GEB10IS PWS1836 LP735	784231139523	2x4 Recessed Troffer	3	32	1	120 - 277	Y	Y	700 series, 3500K	28	1
2GT8 4 32 A12 MVOLT GEB10IS	784231150023	2x4 Recessed Troffer	4	32	2	120 - 277	N	N	-	28	1
2GT8 4 32 A12 MVOLT 1/4 GEB10IS	784231139462	2x4 Recessed Troffer	4	32	1	120 - 277	N	N	-	28	1
2GT8 4 32 A12 MVOLT 1/4 GEB10IS LP735	784231162453	2x4 Recessed Troffer	4	32	1	120 - 277	N	Y	700 series, 3500K	28	1
2GT8 4 32 A12 MVOLT 1/4 GEB10IS LP741	784231165171	2x4 Recessed Troffer	4	32	1	120 - 277	N	Y	700 series, 4100K	28	1
2GT8 4 32 A12 MVOLT 1/4 GEB10IS PWS1836 LP741	784231165607	2x4 Recessed Troffer	4	32	1	120 - 277	Y	Y	700 series, 4100K	28	1
2GT8 4 32 A12 MVOLT 1/4 GEB10IS PWS1836 LP735	784231139486	2x4 Recessed Troffer	4	32	1	120 - 277	Y	Y	700 series, 3500K	28	1
2GT8 2 U316 A12 MVOLT GEB10IS	784231145067	2x2 Recessed Troffer	2	32-U lamp	1	120 - 277	N	N	-	56	1

DIMENSIONS

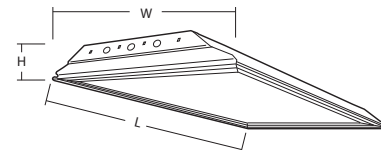

Width: 12" (1x4) or 24" (2x2; 2x4)
 Length: 24" (2x2) or 48" (1x4; 2x4)
 Height: 4-1/2" (1x4) or 3-3/16" (2x2; 2x4)

Certain airborne contaminants can diminish integrity of acrylic. See pg.156 for Acrylic Compatibility table for suitable uses.

ACCESSORIES

- DGA14 Drywall Grid Adapter (Use with any 1x4 grid fixture)
- DGA22 Drywall Grid Adapter (Use with any 2x2 grid fixture)
- DGA24 Drywall Grid Adapter (Use with any 2x4 grid fixture)
- L2GT8 A12 Replacement Lens for 2x4 Lensed Troffer