

# Switches Decorator Switches


15 & 20A, 120/277 & 347VAC; 20A, 120VAC

Pass & Seymour  
**legrand**


Switches

## Features


- Impact-resistant thermoplastic back body & frame.
- Cushioned thermoplastic paddle assures smooth, quiet, long term operation.
- Unique single rocking butterfly contact provides long term consistent performance with significantly fewer moving parts.
- Internal back & side wire capability for easy installation with #14 - 10 stranded or solid copper/copper clad wire. Terminals made of high conductivity brass & serrated for maximum wire gripping.
- Color-coded back bodies for positive identification of switch rating.
- Silver alloy contacts integrally formed to the butterfly actuator assures reliable performance.
- Integral autoground clip for positive ground to metal boxes.
- Brass binding head terminal screws are combination phillips/slotted. All terminal screws backed out, ready to install.

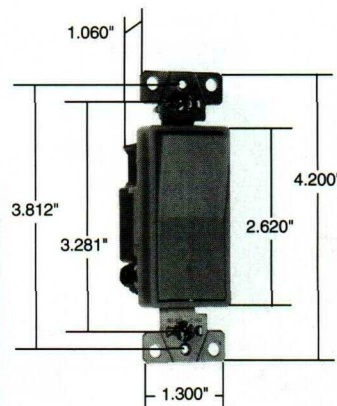

2601 Series

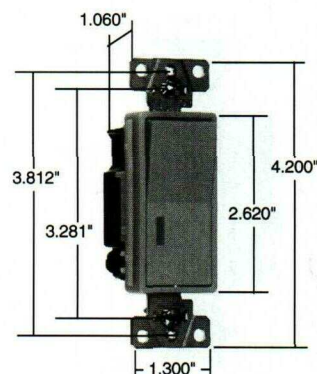

2625, 2626, 2629 Series

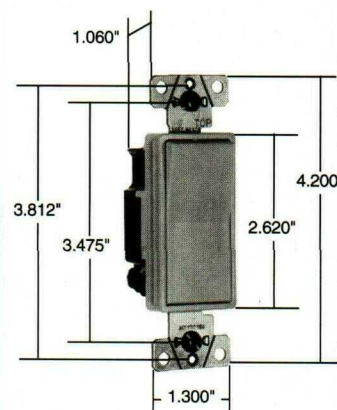

2601347 Series

Catalog Number				Rating A. VAC	Color	3rd Party Compliance	
Single Pole	Double Pole	Three Way	Four Way			UL20	C22.2 111
<b>Specification Grade Rocker Switch Back &amp; Side Wire</b>							
2601-I		2603-I	2604-I	15 120/277	Ivory	•	•
2601-W		2603-W	2604-W	15 120/277	White	•	•
2601-GRY		2603-GRY		15 120/277	Gray	•	•
2601-BK		2603-BK		15 120/277	Black	•	•
2601-LA		2603-LA	2604-LA	15 120/277	Light Almond	•	•
2621-I	2622-I	2623-I	2624-I	20 120/277	Ivory	•	•
2621-W	2622-W	2623-W	2624-W	20 120/277	White	•	•
2621	2622	2623	2624	20 120/277	Brown	•	•
2621-GRY	2622-GRY	2623-GRY	2624-GRY	20 120/277	Gray	•	•
2621-BK	2622-BK	2623-BK	2624-BK	20 120/277	Black	•	•
2621-RED	2622-RED	2623-RED	2624-RED	20 120/277	Red	•	•
2621-LA	2622-LA	2623-LA	2624-LA	20 120/277	Light Almond	•	•
<b>Illuminated Rocker (Lighted when OFF) Back &amp; Side Wire</b>							
2625-I		2626-I		20 120	Ivory	•	•
2625-W		2626-W		20 120	White	•	•
2625-LA		2626-LA		20 120	Light Almond	•	•
<b>Pilot Lighted Rocker (Lighted when ON) Back &amp; Side Wire</b>							
2629-I				20 120	Ivory	•	•
2629-W				20 120	White	•	•
2629-LA				20 120	Light Almond	•	•

Catalog Number				Rating A. VAC	Color	3rd Party Compliance	
Single Pole	Double Pole	Three Way	Four Way			UL20	C22.2 111
<b>Specification Grade Rocker Switch Back &amp; Side Wire</b>							
2601347-I		2603347-I		15 347	Ivory	•	•
2601347-W		2603347-W		15 347	White	•	•
2601347-GRY		2603347-GRY		15 347	Gray	•	•
2621347-I	2622347-I	2623347-I	2624347-I	20 347	Ivory	•	•
2621347-W	2622347-W	2623347-W	2624347-W	20 347	White	•	•
2621347-GRY		2623347-GRY	2624347-GRY	20 347	Gray	•	•
2621347-BK		2623347-BK	2624347-BK	20 347	Black	•	•
2621347-RED		2623347-RED	2624347-RED	20 347	Red	•	•
* Denotes Canadian catalog number. All Canadian products have Combination Slotted/Robertson Head Brass Screws.							

All devices listed on this page conform to NEMA WD-1.

Decorator Switches



**Heavy-duty, brass alloy, one-piece contact arm** virtually eliminates contact bounce.

**Side and back wire** with #14 - #10 AWG copper or copper-clad wire.


**Durable, thermoplastic toggle** withstands impacts and constant use.

**Cam control and spring actuator** for positive "makes and breaks" with a minimum of arcing.

**Oversized silver-alloy contacts** for long life and better heat dissipation.

**Heavy-duty bumpers** for quiet, smooth operation.

**Grounding terminal is standard.**

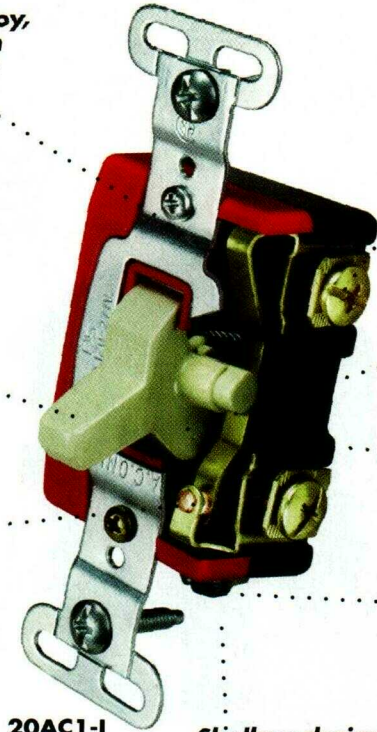

**20AC1-I**

**Shallow design** for easier installation.

**Readily installed in the plant or at the office — you can rely on all of our switches for years of quiet, trouble-free operation.**

### HP Conversion Table – Switches


15 Amp	1/2 Horsepower at 120VAC 2 Horsepower at 240VAC
20 Amp	1 Horsepower at 120VAC 2 Horsepower at 240VAC
30 Amp	2 Horsepower at 120VAC 2 Horsepower at 240VAC

## Index


Device	Rating	Page Number
Horsepower Rating Chart		A-1
Specification Grade AC Switches	15, 20 & 30A, 120, 277 & 120/277VAC	A-3
Lock Switch Keys		A-3
Specification Grade & Security AC Switches	15 & 20A, 347VAC; 20A, 120/277VAC	A-4
Commercial Specification Grade AC Switches	15 & 20A, 120/277VAC	A-5
TradeMaster® Toggle Switches	15A, 120VAC	A-6
Decorator Switches	15 & 20A, 120/277 & 347VAC; 20A, 120VAC	A-7
TradeMaster® Decorator Switches	15A, 120 & 120/277VAC	A-8
Combination Switches	15 & 20A, 120 & 120/277VAC; 15A, 125V	A-9
Manual Controllers	20 & 30A 1Ø; 20 & 30A 3Ø	A-10
Manual Controllers	40A 1Ø; 40A 3Ø	A-11
Manual Controllers	15, 20 & 30A, 120/277VAC	A-12
Canopy Switches & 911 Locator	6A, 120V & 3A, 250V; 15A, 120VAC	A-13
Wall Box Timers - Rotary	125, 125-T, 250 & 277VAC, 60 Hz	A-14
Wall Box Timers - Toggle	500W, 1/3 HP, 120VAC, 60 Hz	A-15




## Industrial

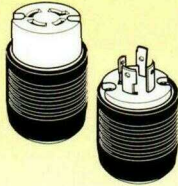


Turnlok® Locking Devices  
Section I

 


Turnlok® Locking Devices  
Section I

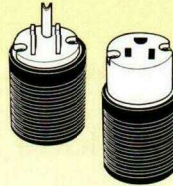


Straight Blade  
Section B, H

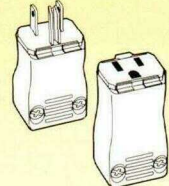

 
MaxGrip® II Straight Blade  
Section B, H




Straight Blade  
Section B

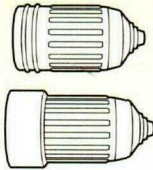

 Straight Blade &  
Turnlok® Locking Devices  
Section I, H




AC Switches  
Section A

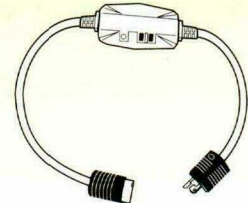

Portable GFCI  
Section F


## Commercial

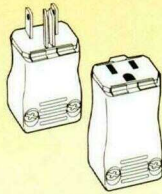


Straight Blade & MaxGrip® II  
Section B, H



 
Straight Blade  
Section B




AC Switches  
Section A

 


SpecGuard™ TVSS & IG Devi  
Section G

 


TVSS & IG Devices  
Section G

 

Straight Blade & Hospital Grade  
Section B, C

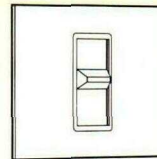

 Lumaspec® Dimmers &  
Fan Speed Controls  
Section M




Occupancy Sensors  
Section L


## Residential



 
TradeMaster® Decorator Switches  
Section D



 TradeMaster® Decorator Receptacles  
Section D



TradeMaster® GFCIs  
Section E, F

 


Lumaspec® Dimmers &  
Fan Speed Controls  
Section M




TradeMaster® Switches  
Section D



TradeMaster® Receptacles  
Section D

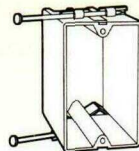

Slater® Plastic Boxes  
Section Q

 

Lumaspec® Dimmers  
Section M