



Modern low-profile Screwless Wall Plates fit for today's homes and hospitality settings.

RWP26, RWP262, RWP263, RWP264, RWP265, RWP266

Part of the redesigned radiant® collection of wiring devices and home automation controls, Legrand's broad offering of screwless wall plates are a step above ordinary with modern low profiles that fit more flush to the wall than standard wall plates. These wall plates color-match radiant® devices and are equipped with one-piece plastic subplates and screws to align devices and ensure proper positioning. Ideal for residential, multi-dwelling, commercial office and hospitality applications, radiant® screwless wall plates are available in one- to six-gang configurations, each in six standard colors and three metallic finishes.

Features & Benefits

Redesigned screwless wall plates feature a lower, more modern profile in keeping with today's design trends.

Molded of rugged .065" thick polycarbonate.

One-piece plastic subplate mounts over the device for easy retrofit and lower profile.



An extra 3/8" width and height than standard-size wall plates for more tolerance in covering ragged sheet rock openings.

Opening accommodates all NEMA 26-opening devices.


Subplate screws align devices to ensure proper positioning of wall plates.

RWP26LA


- Part of the radiant® collection.
- New, lower profile.

- Available in Ivory, White, Brown, Gray, Black, and Light Almond; and three metallic finishes – Nickel, Dark Bronze, Graphite.


3rd Party Compliance

 Listed to UL514. CSA Certified.

Wall Plate Dimensions/Materials

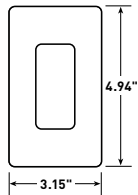

radiant®
Screwless
Wall Plate

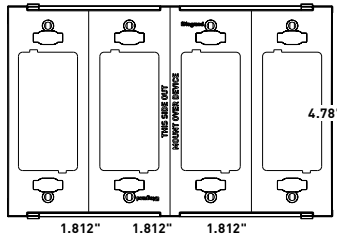

radiant® Screwless
Wall Plate Plastic Subplate

Materials

Body Construction	Molded of .065" thick polycarbonate
Sub-plate Construction	Polyphenylene Ether and Polystyrene
Mounting Screws	Steel

radiant® Screwless Polycarbonate Wall Plates

- Available in 26-style openings.
- Extra 3/8" width and height than standard size wall plates.
- Provide better sheet rock coverage with standard size appearance.
- Molded of .065" thick polycarbonate.
- One-piece plastic subplate.
- Available in three metallic finishes and six standard colors.

Wall Plate Dimensions







1 gang	3.15" x 4.94"
2 gang	4.96" x 4.94"
3 gang	6.77" x 4.94"
4 gang	8.59" x 4.94"
5 gang	10.40" x 4.94"
6 gang	12.21" x 4.94"

Subplate Dimensions

1 gang	1.81" x 4.78" x .15"
2 gang	3.62" x 4.78" x .15"
3 gang	5.44" x 4.78" x .15"
4 gang	7.25" x 4.78" x .15"
5 gang	9.06" x 4.78" x .15"
6 gang	10.87" x 4.78" x .15"

Ordering Information

radiant® Metallic Finish Screwless Wall Plates – Polycarbonate Screwless 26 Openings – Plastic Subplate included

Description	Color	26 Openings
One Gang 	Nickel	RWP26NI
	Dark Bronze	RWP26DBCC6
	Graphite	RWP26GCC6
Two Gang 	Nickel	RWP262NI
	Dark Bronze	RWP262DBCC6
	Graphite	RWP262GCC6
Three Gang 	Nickel	RWP263NI
	Dark Bronze	RWP263DBCC6
	Graphite	RWP263GCC6
Four Gang 	Nickel	RWP264NI
	Dark Bronze	RWP264DB
Five Gang 	Nickel	RWP265NI
	Dark Bronze	RWP265DB
Six Gang 	Nickel	RWP266NI
	Dark Bronze	RWP266DB



One Gang
Nickel



Two Gang
Dark Bronze




Three Gang
Graphite


Ordering Information

radiant® Screwless Wall Plates – Polycarbonate Screwless Wall Plates – Plastic Subplate included


Description	Color	26 Openings
One Gang	Ivory	RWP26I
	White	RWP26W
	Brown	RWP26
	Gray	RWP26GRY
	Black	RWP26BK
	Light Almond	RWP26LA
	Two Gang	Ivory
White		RWP262W
Brown		RWP262
Gray		RWP262GRY
Black		RWP262BK
Light Almond		RWP262LA
Three Gang		Ivory
	White	RWP263W
	Brown	RWP263
	Gray	RWP263GRY
	Black	RWP263BK
	Light Almond	RWP263LA
	Four Gang	Ivory
White		RWP264W
Brown		RWP264
Gray		RWP264GRY
Black		RWP264BK
Light Almond		RWP264LA
Five Gang		Ivory
	White	RWP265W
	Brown	RWP265
	Gray	RWP265GRY
	Black	RWP265BK
	Light Almond	RWP265LA
	Six Gang	Ivory
White		RWP266W
Brown		RWP266
Gray		RWP266GRY
Black		RWP266BK
Light Almond		RWP266LA

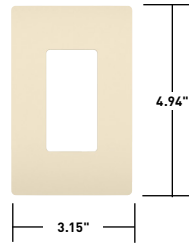


One Gang

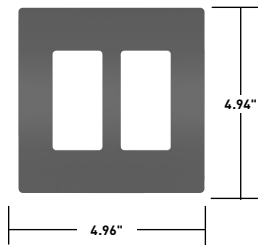

Two Gang

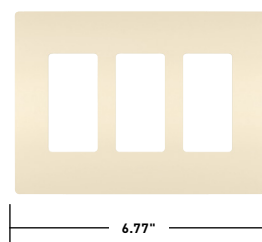

Three Gang

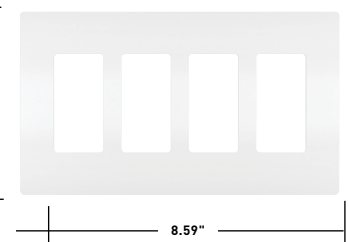

Four Gang



**One Gang
Plastic Subplate**



**Two Gang
Plastic Subplate**

Screwless 26 Openings Plastic Subplate included

Description	Height	Width
One Gang	4.94"	3.15"
Two Gang	4.94"	4.96"
Three Gang	4.94"	6.77"
Four Gang	4.94"	8.59"
Five Gang	4.94"	10.40"
Six Gang	4.94"	12.21"

Screwless Plastic Subplate Dimensions

Description	Height	Width
One Gang	4.78"	1.81"
Two Gang	4.78"	3.62"
Three Gang	4.78"	5.44"
Four Gang	4.78"	7.25"
Five Gang	4.78"	9.06"
Six Gang	4.78"	10.87"