

SLEXW

RAINSTORM NEMA4X/EEMAC4X



Approvals:
CSA Certified to C22.2 #141-15 and C860



DESCRIPTION

The SLEXW series of NEMA4X and EEMAC4X rated weatherproof signs is designed to operate in extreme environments. The fully gasketed housing is suitable for outdoor and wash-down locations. Available in AC only, AC/DC and internally self-powered versions.

CIRCUITRY - AC & AC/DC

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 1.9W power consumption single or double face
- Emergency DC wattages as follows:

UDC					IB	
6V	12V	24V	120V	347V	120V	347V
1.0W	1.4W	3.5W	1.9W	1.8W	3.1W	2.9W


CIRCUITRY - SELF-POWERED

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 2W power consumption single or double face
- High-performance, sealed Ni-Cad battery
- 90 minutes emergency duration (standard)
120 minutes emergency duration is optional
- Solid state transfer and battery charger

MECHANICAL

- Heavy-duty glass fibre reinforced polyester construction
- Lens with one piece, molded gasket
- Four integral mounting holes (one per corner) protected behind polycarbonate cover
- Lens secured to housing with four oversized captive screws
- The housing is supplied standard in a grey industrial finish. Face plate standard grey.

DIMENSIONS

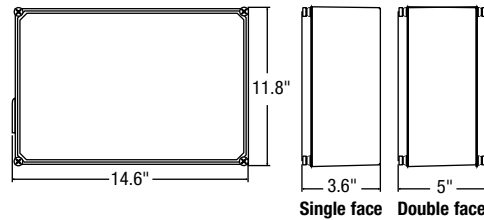

ORDERING GUIDE

Series	Nbr of faces	Mounting	Frame color	Mask color	DC Voltage	Options†
SLEXW	1 - Single face 2 - Double face	CM - Ceiling mount WM - Wall mount EM - End mount PM - Pendant mount	GY - Grey	GY - Grey (standard)	NDC - AC only UDC - Universal DC backup voltage 6, 12 or 24VDC IB - Self-powered for 90 minutes	WG* , BO , WO , OP , TP

† For detailed options descriptions, please consult the options page.

* Specify mounting.