
 


 
 

 


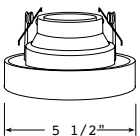


Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 Beveled Lensed	 5"	 Wet Location	4402 ABZ 4" Decorative Beveled Lensed Trim - Classic Aged Bronze 4402 SC 4" Decorative Beveled Lensed Trim - Satin Chrome 4402 WH 4" Decorative Beveled Lensed Trim - White	IC44N / IC44N W / IC44N S / TC44 / TC44 V / TC44 S / TC44R: 50W MR16
			4401 ABZ 4" Decorative Beveled Dome Lensed Trim - Classic Aged Bronze 4401 SC 4" Decorative Beveled Dome Lensed Trim - Satin Chrome 4401 WH 4" Decorative Beveled Dome Lensed Trim - White	IC44N / IC44N W / IC44N S / TC44 / TC44 V / TC44 S / TC44R: 50W MR16
			4404 HZSC 4" Decorative Beveled Cone Trim - Haze Cone, Satin Chrome Trim Ring 4404 WHZABZ 4" Decorative Beveled Cone Trim - Wheat Haze Cone, Classic Aged Bronze Trim Ring	IC44N / IC44N W / IC44N S / TC44 / TC44 V / TC44 S / TC44R: 50W MR16
 Beveled Cone	 5" Adjustment 30° Vertical	 Wet Location	4403 FROSTWH 4" Decorative Beveled Cylinder Trim - Frosted Glass, White Trim Ring 4403 FROSTSC 4" Decorative Beveled Cylinder Trim - Frosted Glass, Satin Chrome Trim Ring	IC44N / IC44N W / IC44N S / TC44 / TC44 V / TC44 S / TC44R: 50W MR16
			4450 MESHSC 4" Decorative Glass Cylinder Trim - Mesh Glass, Satin Chrome Trim Ring	IC44N / IC44N W / IC44N S / TC44 / TC44 V / TC44 S / TC44R: 50W MR16
 Frosted Glass	 5"	 Wet Location	4481 CLEAR 4" Decorative Frosted Glass Trim - Perimeter Frosted Clear Glass	IC44N / IC44N W / IC44N S / TC44 / TC44 V / TC44 S / TC44R: 50W MR16
			4480 FROST 4" Decorative Solid Glass Collar Trim - Frosted Glass	IC44N / IC44N W / IC44N S / TC44 / TC44 V / TC44 S / TC44R: 50W MR16
 Solid Glass Collar	 5 1/2"			

Housing and trim can be ordered together or separate, but will always ship separately.