

## TC-Rated 5" and 6" 1400 Lumen LED Downlights

Delivering high-performance illumination for retail and commercial environments

The latest generation of the TC20LED and TC22LED 1400 lumen LED downlights are more efficient than ever before. They feature sophisticated optics and an array of dimmable driver options. The eldoLED driver option delivers smooth and flicker-free deep dimming performance. These downlights are intended for use in non-insulated applications and produce over 1400 lumens of brilliant LED illumination.

### Features include:

- Dedicated, TC-rated 5" or 6" new-construction housings
- Ultra-efficient 20-watt operation, provides 37% energy savings compared to 32-watt CFLs
- Deeply regressed LED diffusing lens produces even aperture luminance and low glare
- Wide flood optic (standard); medium flood, narrow flood, or spot optics are optional
- Superior fixture-to-fixture color uniformity
- 90+ CRI ensures outstanding color rendering
- High-purity aluminum housing provides uninterrupted heat transfer
- 50,000-hour service life



# Juno® TC-Rated 5" and 6" 1400 Lumen LED Downlights

Boasting over 1400 lumens of high-quality white light, Juno TC20LED and TC22LED Downlights are ideal for the higher ceilings typical of retail and commercial environments. Open, lensed, wall wash, and ultra-low-glare hyperbolic trims are available in a variety of colors and finishes. Options include emergency battery back-up and a Chicago Plenum version. The fixtures are ENERGY STAR® certified when used with select trims.

## Ordering Information

### 5" TC 1400 Lumen Series Generation 4 LED Downlights

Example: TC20LED G4 14LM 27K 90CRI MVOLT EZ1 BR

Series	Gen	Lumens	CCT	CRI	Voltage/Driver	Options
<b>TC20LED</b> 5" New Construction Housing	<b>G4</b>	<b>14LM</b> 1400 Lumens	<b>27K</b> 2700K <b>30K</b> 3000K <b>35K</b> 3500K <b>40K</b> 4000K	<b>90CRI</b> 90 CRI	<b>MVOLT EZ1*</b> Multi-Volt (120-277V) eldoLED 0-10V, 1% dim  <b>MVOLT EZ10*</b> Multi-Volt (120-277V) eldoLED 0-10V, 10% dim  <b>MVOLT ECOS3†</b> Lutron® Hi-Lume® Dimmable Driver	<b>BR</b> Emergency Battery Back-Up with Remote Switch  <b>CP †</b> Chicago Plenum



5" Universal Voltage



5" Emergency Backup with Remote Switch



5" Chicago Plenum

\*A+ Capable † Not available with emergency option.

### 6" TC 1400 Lumen Series Generation 4 LED Downlights

Example: TC22LED G4 14LM 27K 90CRI MVOLT EZ1 BR

Series	Gen	Lumens	CCT	CRI	Voltage/Driver	Options
<b>TC22LED</b> 6" New Construction Housing	<b>G4</b>	<b>14LM</b> 1400 Lumens	<b>27K</b> 2700K <b>30K</b> 3000K <b>35K</b> 3500K <b>40K</b> 4000K	<b>90CRI</b> 90 CRI	<b>MVOLT EZ1*</b> Multi-Volt (120-277V) eldoLED 0-10V, 1% dim  <b>MVOLT EZ10*</b> Multi-Volt (120-277V) eldoLED 0-10V, 10% dim  <b>MVOLT ECOS3†</b> Lutron® Hi-Lume® Dimmable Driver	<b>BR</b> Emergency Battery Back-Up with Remote Switch  <b>CP †</b> Chicago Plenum



6" Universal Voltage



6" Emergency Backup with Remote Switch



6" Chicago Plenum

\*A+ Capable † Not available with emergency option.

## Accessories


Catalog No.	Description
<b>HB1</b>	Two 13-1/2" - 25" Real Nail® 3 bar hangers
<b>HB26</b>	Two 26" C-channel bar hangers
<b>HB50</b>	Two 50" C-channel bar hangers
<b>LB27</b>	Two 27" linear bar hangers

## LED Optics

Catalog No.	Description
<b>LEDOPTICG3 MFL</b>	Medium Flood Optic (50°)
<b>LEDOPTICG3 NFL</b>	Narrow Flood Optic (37°)
<b>LEDOPTICG3 SP</b>	Spot Optic (10°)

## Extensive Trim Options

Juno TC-Rated LED recessed housings are compatible with a broad selection of existing Juno 5" and 6" open, lensed and hyperbolic trims. A dedicated wall wash scoop is also available for wall wash applications.

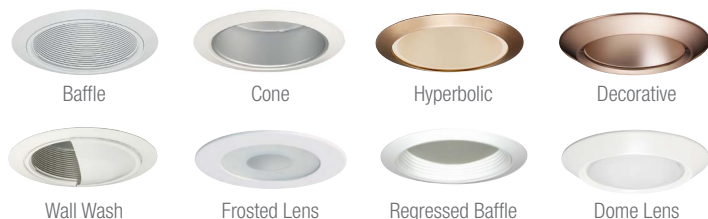

A+ Capable configurations support A+ Certified Solutions. A+ Certified solutions from Acuity Brands help you quickly and confidently select and implement lighting systems that are both compatible and consistent. Go to [www.acuitybrands.com/APlus](http://www.acuitybrands.com/APlus) or contact your local Acuity Brands representative for more information.



All trademarks referenced are property of their respective owners. Specifications subject to change without notice. Printed in the U.S.A.