

JUNO®**TRAC-MASTER®**

Classics

UNIVERSALS**T308, T301, T620, T63,
T64, T691 and T359**

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

Universals offer a wide range of lamp options depending on the application.

Socket Medium base porcelain with nickel plated copper screw shell • Socket adjustable for proper lamp positioning (except T359).

Juno Universal Trac Adapter Universally compatible with both Trac-Master 1-circuit or 2-circuit trac, Trac-Lites trac, monopoints and special mountings • Also UL Recognized for use on ConTech® LT Series track • Copper alloy contacts provide precise spring action - no arcing and will not take a set • True, positive electrical ground • On/off switch included • Patented embossed polarity arrows on bottom of adapter • Spring-loaded positive latch with embossed polarity arrows secures trac light to trac • Two-position power contact provided for two-circuit application.

Alternate TEK Trac Adapter Compatible with Juno TEK trac system • System specific and assembled to trac fixture • Integrally polarized construction to prevent reverse installation – only allows insertion in proper orientation • Rotary circuit selector enables simple switching between circuits • Integral on/off switch enables individual fixtures to be switched for servicing.

Alternate GTYPE Trac Adapter Compatible with track systems based on GES type track, including Lithonia LT Commercial Track (not LTS type) • System specific and assembled to trac fixture • Consult factory for additional information.

Alternate HTYPE Trac Adapter Compatible with track systems which use a H-type track adapter, including Lithonia LTS Decorative Track (not LT type) • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

Alternate LTYPE Trac Adapter Compatible with track systems which use a L-type track adapter • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

Labels UL listed, CSA certified.

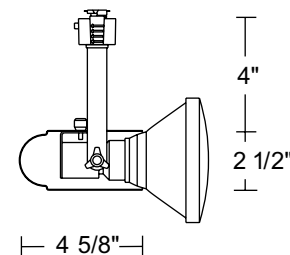
Specifications subject to change without notice.

**Line Voltage Universal**

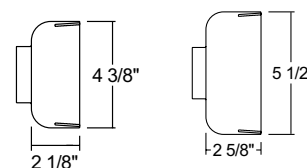
Construction Drawn steel housing with steel yoke.

Aiming 90° vertical aiming capability and 358° rotation • One locking knob provided.

Catalog Number	Description	Finish	Lamp
T308 WH	Universal w/Universal Trac Adapter	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
T308 BL	Universal w/Universal Trac Adapter	Black	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
T308 TEK WH	Universal w/TEK Trac Adapter	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
T308 TEK BL	Universal w/TEK Trac Adapter	Black	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38

**ACCESSORIES**

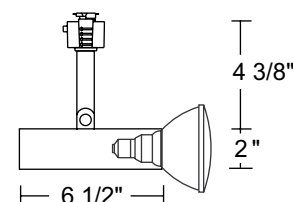
Catalog Number	Finish	Description	Max. Lamp
T63 WH	White w/ Black Baffle	Baffled Hood	75W PAR30L/65W BR30
T63 BL	Black w/Black Baffle	Baffled Hood	75W PAR30L/65W BR30
T64 WH	White w/Black Baffle	Baffled Hood	150W PAR38/120W BR40
T64 BL	Black w/Black Baffle	Baffled Hood	150W PAR38/120W BR40

**Line Voltage Universal**

Construction Steel housing with Lexan® polycarbonate stem.

Aiming 90° vertical aiming capability and 358° rotation.

Catalog Number	Finish	Lamp
T301 WH	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38
T301 BL	Black	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38



ConTech is a registered trademark of ConTech Lighting.

AcuityBrands.

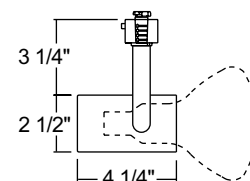
1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925 • Visit us at www.acuitybrands.com/juno-trac
Printed in U.S.A. ©2017-2018 Acuity Brands Lighting, Inc. Rev. 05/16/18

TRAC-MASTER®

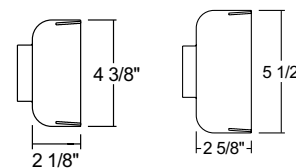
Classics

UNIVERSALS**T308, T301, T620, T63,
T64, T691 and T359****Economy Line Voltage Universal****Construction** Steel housing with steel yoke.**Aiming** 90° vertical aiming capability and 358° rotation.

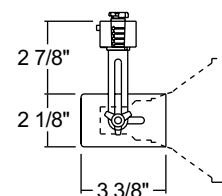
Catalog Number	Description	Finish	Lamp
T620 WH	Universal w/Universal Trac Adapter	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
T620 BL	Universal w/Universal Trac Adapter	Black	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
T620 TEK WH	Universal w/TEK Trac Adapter	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
T620 TEK BL	Universal w/TEK Trac Adapter	Black	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38

**ACCESSORIES**

Catalog Number	Finish	Description	Max. Lamp
T63 WH	White w/ Black Baffle	Baffled Hood	75W PAR30L/65W BR30
T63 BL	Black w/ Black Baffle	Baffled Hood	75W PAR30L/65W BR30
T64 WH	White w/ Black Baffle	Baffled Hood	150W PAR38/120W BR40
T64 BL	Black w/ Black Baffle	Baffled Hood	150W PAR38/120W BR40

**Hi-Tech Mini Swivel Universal****Construction** Steel housing with slotted steel swivel.**Aiming** 90° vertical aiming capability and 358° rotation • One locking knob provided.

Catalog Number	Description	Finish	Lamp
T691 WH	Universal w/Universal Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/50W PAR38
T691 BL	Universal w/Universal Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 NA	Universal w/Universal Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 TEK WH	Universal w/TEK Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/50W PAR38
T691 TEK BL	Universal w/TEK Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 TEK NA	Universal w/TEK Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 GTYPE WH	Universal w/G-Type Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/50W PAR38
T691 GTYPE BL	Universal w/G-Type Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 GTYPE NA	Universal w/G-Type Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 HTYPE WH	Universal w/H-Type Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/50W PAR38
T691 HTYPE BL	Universal w/H-Type Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 HTYPE NA	Universal w/H-Type Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 LTYPE WH	Universal w/L-Type Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/50W PAR38
T691 LTYPE BL	Universal w/L-Type Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
T691 LTYPE NA	Universal w/L-Type Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38

**Mini Swivel Universal****Construction** Porcelain socket mounted to low profile steel swivel.**Aiming** 90° vertical aiming capability and 358° rotation.

Catalog Number	Finish	Lamp
T359 WH	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38
T359 GTYPE WH	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38
T359 HTYPE WH	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38
T359 LTYPE WH	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38

