



# TRAC-MASTER®

Classics

## STUDIO I

### T393, T395 and T397

Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

### PRODUCT DESCRIPTION

The Studio I in white with black phenolic baffles and striking details will enhance any traditional environment.

**Construction** Drawn steel housing with steel yoke.

**Aiming** 90° vertical aiming capability and 358° rotation • One locking knob provided.

**Juno Universal Trac Adapter** Universally compatible with both Trac-Master 1-circuit or 2-circuit trac, Trac-Lites trac, monopoints and special mountings • Also UL Recognized for use on ConTech® LT Series track • Copper alloy contacts provide precise spring action - no arcing and will not take a set • True, positive electrical ground • On/off switch included • Patented embossed polarity arrows on bottom of adapter • Spring-loaded positive latch with embossed polarity arrows secures trac light to trac • Two-position power contact provided for two-circuit application.


**Alternate GTYPE Trac Adapter** Compatible with track systems based on GES type track, including Lithonia LT Commercial Track (not LTS type) • System specific and assembled to trac fixture • Consult factory for additional information.

**Alternate HTYPE Trac Adapter** Compatible with track systems which use a H-type track adapter, including Lithonia LTS Decorative Track (not LT type) • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

**Alternate LTYPE Trac Adapter** Compatible with track systems which use a L-type track adapter • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.


**Labels** UL listed • CSA certified • Union made • Assembled in U.S.A.

Specifications subject to change without notice.

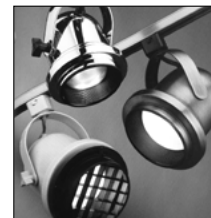

### Line Voltage PAR/R20

Catalog Number	Description	Baffle	Finish	Lamp
<b>T393 WH</b>	Studio I w/Universal Trac Adapter	Black	White	50W R20/50W PAR20
<b>T393 GTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	50W R20/50W PAR20
<b>T393 HTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	50W R20/50W PAR20
<b>T393 LTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	50W R20/50W PAR20

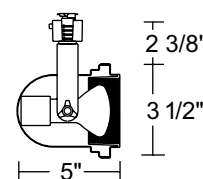

### ACCESSORIES

Cat. No.	Description	Cat. No.	Description
<b>HCLBL 375</b>	Hexcell Louver - Black	<b>UVF 375</b>	UV Filter
<b>CCLBL 375</b>	Cube Cell Louver - Black	<b>SOLITE 375</b>	Uniformity Lens (Solite)
<b>SNOOTBL 375</b>	Snoot - Black	<b>PRISM 375</b>	Prismatic Spread Glass Lens
<b>CGF 375</b>	Color Glass Filter	<b>LSPREAD 375</b>	Linear Spread Glass Lens
<b>DCCF 375</b>	Dichroic Color Correction Filter	<b>T560BL</b>	3-1/2" Diameter Accessory Holder - Black
<b>DGF 375</b>	Dichroic Glass Filter	<b>T71BL</b>	3-3/4" Diameter Barn Doors - Black †
<b>DIFF 375</b>	Diffusion Glass Lens	<b>T40N<sup>1</sup></b>	Monopoint

See specification sheet [D1.2.2](#) for details. Other accessories can be found on specification sheet [D1.2.0](#).

† Barn Doors accept Color Filters, Lenses, Snoot and Louvers.

Notes:

1 Add finish code to complete catalog number (Example: T40N WH).

ConTech is a registered trademark of ConTech Lighting.



1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925 • Visit us at [www.acuitybrands.com/juno-trac](http://www.acuitybrands.com/juno-trac)  
Printed in U.S.A. ©2017-2018 Acuity Brands Lighting, Inc. Rev. 05/16/18

**TRAC-MASTER®**

Classics

**STUDIO I****T393, T395 and T397****Line Voltage BR30/PAR30L**

Catalog Number	Description	Baffle	Finish	Lamp
<b>T395 WH</b>	Studio I w/Universal Trac Adapter	Black	White	75W BR30/75W PAR30L
<b>T395 GTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	75W BR30/75W PAR30L
<b>T395 HTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	75W BR30/75W PAR30L
<b>T395 LTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	75W BR30/75W PAR30L

**ACCESSORIES**


Cat. No.	Description	Cat. No.	Description
<b>HCLBL 469</b>	Hexcell Louver - Black	<b>UVF 469</b>	UV Filter
<b>CCLBL 469</b>	Cube Cell Louver - Black	<b>SOLITE 469</b>	Uniformity Lens (Solite)
<b>SNOOTBL 469</b>	Snoot - Black	<b>PRISM 469</b>	Prismatic Spread Glass Lens
<b>CGF 469</b>	Color Glass Filter	<b>LSPREAD 469</b>	Linear Spread Glass Lens
<b>DCCF 469</b>	Dichroic Color Correction Filter	<b>T57OBL</b>	4-11/16" Diameter Accessory Holder - Black
<b>DGF 469</b>	Dichroic Glass Filter	<b>T72BL</b>	4-11/16" Diameter Barn Doors - Black †
<b>DIFF 469</b>	Diffusion Glass Lens	<b>T40N<sup>1</sup></b>	Monopoint

See specification sheet [D1.2.2](#) for details. Other accessories can be found on specification sheet [D1.2.0](#).

† Barn Doors accept Color Filters, Lenses, Snoot and Louvers.

Notes:

1 Add finish code to complete catalog number (Example: T40N WH).

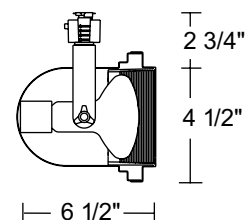**Line Voltage BR40/PAR38**

Catalog Number	Description	Baffle	Finish	Lamp
<b>T397 WH</b>	Studio I w/Universal Trac Adapter	Black	White	150W PAR38/120W BR40
<b>T397 GTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	150W PAR38/120W BR40
<b>T397 HTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	150W PAR38/120W BR40
<b>T397 LTYPE WH</b>	Studio I w/Universal Trac Adapter	Black	White	150W PAR38/120W BR40

**ACCESSORIES**

Cat. No.	Description	Cat. No.	Description
<b>CGF 550</b>	Color Glass Filter	<b>T58OBL</b>	5-1/2" Diameter Accessory Holder - Black
<b>CCLBL 550</b>	Cube Cell Louver - Black	<b>T40N<sup>1</sup></b>	Monopoint
<b>T58OBL</b>	5-1/2" Diameter Accessory Holder - Black		

See specification sheet [D1.2.2](#) for details. Other accessories can be found on specification sheet [D1.2.0](#).

† Barn Doors accept Color Filters, Lenses and Louvers.

Notes:

1 Add finish code to complete catalog number (Example: T40N WH).

