



TLP324OPAL



TLP316ORANGEPEEL



TLP328COBALT

Cylinder

Hand blown cased glass with opal interior and satin nickel plated support spider.

Wrap

Precision cut, interleaved layers of suede polycarbonate or parchment sheet captured by nickel plated support spider and cap nuts.

Disc

Precision aluminum casting with integrated aperture ring securely supports tempered glass disc. Use of dichroic lamps washes inverted cone with a decorative aura.

CATALOG #	LAMP/CORDSET
TLP324	LED 12V, 5W LED NEW
	HALOGEN 12V OR 24V, 50W MAX T4 HALOGEN GY6.35 BI-PIN CAPSULE OR MR16CG COVER GLASS

FINISHES:



OPAL

MAIZE

DIMENSIONS



Pendant cordset required. Must be ordered separately.

CATALOG #	LAMP/CORDSET
TLP316	LED 12V, 5W LED NEW
	HALOGEN 12V OR 24V, 50W MAX T4 HALOGEN GY6.35 BI-PIN CAPSULE OR MR16CG COVER GLASS

FINISHES:




FROST

ORANGE PEEL

PARCHMENT

DIMENSIONS

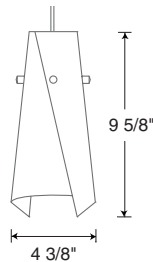

Pendant cordset required. Must be ordered separately.

CATALOG #	LAMP
TLP328	HALOGEN 12V OR 24V, 50W MAX MR16CG COVER GLASS

FINISHES:

 


FROST

COBALT

AMBER

DIMENSIONS



Pendant cordset required. Must be ordered separately.

For Cordset and Mounting Options – see pages 224-225

When ordering add finish name after catalog number. Example: TLP324OPAL

See website for details, www.junolightinggroup.com