

Mountings



TT528 Surface Mount Bracket
For mounting on T-bar or rigid ceiling. Supports track housing 1-1/2" from ceiling. Use two for each track tube section.
Finishes: **BL** Black, **WH** White



TT529 Wall Mount Bracket
For mounting track tube from wall. Track tube extends 17-1/4" from wall. Use two for each track tube section.
Finishes: **BL** Black, **WH** White



TT590 12IN T-Bar Pendant Stem Kit
TT590 18IN (12", 18", 24", 36", 48")
TT590 24IN Use two for 4' or 8' of track tube. Continuous runs require one every 4'.
TT590 36IN 4'. Mechanically suspends and electrically feeds track tube.
TT590 48IN Feed wires can be routed through pipe.

TT591 12IN Rigid Ceiling Pendant Stem Kit
TT591 18IN (12", 18", 24", 36", 48")
TT591 24IN Use two for 4' and 8' of track tube. Continuous runs require one every 4'.
TT591 36IN Similar to above but for rigid ceiling.
TT591 48IN
Finishes: **BL** Black, **WH** White



TT595 T-Bar Ceiling Pendant Cable
Mechanical suspension for track tubes. Continuous runs require one every 4'. Adjustable 48" cable.
Finishes: **BL** Black, **WH** White

TT596 T-Bar Ceiling Pendant Cable
Similar to above but with 48" electrical feed flexible wireway and wires.
Finishes: **BL** Black, **WH** White

TT597 Rigid Ceiling Pendant Cable
Mechanical suspension for track tubes. Continuous runs require one every 4'. Adjustable 48" cable.
Finishes: **BL** Black, **WH** White

TT598 Rigid Ceiling Pendant Cable
Similar to above but with 48" electrical feed flexible wireway and wires.
Finishes: **BL** Black, **WH** White




T94 Slope Ceiling Adapter
Allows TT590 or TT591 pendant to hang straight down from sloped ceilings. Can be used to electrically feed track at up to a 60° angle.
Finishes: **BL** Black, **WH** White



T96 Pendant Stem Coupling
Joins pendant stems for use in higher ceiling applications.
Finishes: **BL** Black, **WH** White

Juno® Recessed Trac-Master™ System

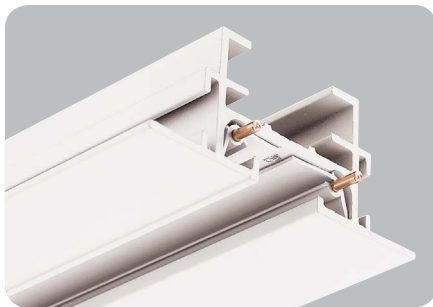


Recessed track provides a clean, built-in and finished look to lighting designs. Juno recessed track installs into plasterboard and suspended ceilings for polished, professional decor. One-circuit Trac-Master recessed track sections allow track lights to be mounted flush to the ceiling.

Key Features

- Extruded aluminum channel and thermoplastic insulator
- Debossed polarity line
- 12 gauge solid copper conductors
- Concealed wireway on top of track section
- 20 Amp capacity
- UL Listed, CSA Certified
- Can be cut to custom length by installer

Recessed Track Sections For dry ceilings (Straight runs only)

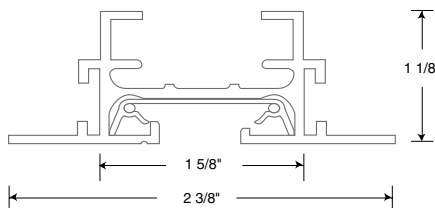

Series	Description	Finishes
TREC 4FT	4' Recessed Track (One Circuit. Actual length 43-7/8")	WH White
TREC 8FT	8' Recessed Track (One Circuit. Actual length 91-7/8")	WH White

Recessed Track Connectors



T121 Feed End Connector
With wiring box for electrifying track.
Finishes: **WH** White



T123 Mini Straight Joiner Connector
Mechanically and electrically joins two track sections end to end.
Finishes: **WH** White

Juno® Monopoints

Monopoints increase the versatility of Juno Trac fixtures by allowing them to be mounted where track sections do not offer the best aesthetic or functional solution.

Outlet Box Monopoints



T40N Monopoint
Mounts directly to outlet box. Accepts Juno 120V track lights. Dimensions: 4-3/4" Dia. x 5/8" H
Finishes: **BL** Black, **WH** White, **SL** Silver



T58 Monopoint
Mounts directly to outlet box. To be used with T537 or T538 Transformer. Dimensions: 6-1/2" Dia. x 1/2" H
Finishes: **BL** Black, **WH** White, **SL** Silver, **BZ** Bronze

T40F Monopoint (Flush Mount)
Dimensions: 5-1/4" Dia. x 1/32" H
Finishes: **BL** Black, **WH** White, **SL** Silver



T41N Duopoint
Mounts directly to outlet box. Accepts two Juno 120V track lights. Dimensions: 13" W x 4" D x 5/8" L
Finishes: **BL** Black, **WH** White, **SL** Silver

Special Monopoints



T42N Weighted Base
For portable use. Accepts Juno 120V track lights. Supplied with 8' cord and plug. Dimensions: 4-3/4" Dia. x 5/8" H
Finishes: **BL** Black, **WH** White



T45 Pin-Up/Monopoint
Accepts Juno 120V track lights. 8' cord and plug supplied. Dimensions: 2" W x 4-1/4" H x 1/2" D
Finishes: **BL** Black, **WH** White



T46 Clamp Monopoint
Clamps to pipe or planking up to 2-1/2" thick. Accepts all Juno 120V track lights. 8' 3-wire black cord and plug supplied.

Monopoints for 6" Recessed Housings



T57N Monopoint Cover – Line Voltage
Permits Juno line voltage track lights to be attached directly to Juno 6" recessed housings. Dimensions: 7-5/8" Dia. x 3/16" H
Finishes: **WH** White



T539 Monopoint Cover – Low Voltage
Contains integral electronic transformer. Permits Juno low voltage lights to be attached directly to Juno 6" recessed housings. Dimensions: 7-5/8" D x 3/16" H
Finishes: **WH** White

Low Voltage 4" Recessed Monopoints



T543 Monopoint Transformers
For new construction. Includes 50VA-12V magnetic transformer, pre-wired recessed housing, canopy, adjustable bar hangers and thermal protector. Accepts Juno Trac lights that operate using a separate low voltage transformer. Dimensions: Canopy: 5" Dia. x 1/4" H
Recessed Housing: 5-1/4" H
Finishes: **WH** White