

JUNO[®]**TRAC-MASTER**[®]

Fixture Accessories

LIGHT CONTROL ACCESSORIES

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

A wide variety of functional accessories are compatible with most Juno trac fixtures. Refer to fixture specification sheet to confirm compatibility.

Louvers

Visually shields lamp and reduces glare.



Series	Diameter
HCLBL (With hexagonal cells)	138 2.75" Diameter
	175 1.75" Diameter
	200 2" Diameter
	275 2.75" Diameter
	300 3" Diameter
	375 3.75" Diameter
	469 4-11/16" Diameter



CCLBL (With square cells)	375 3.75" Diameter
	469 4-11/16" Diameter
	550 5.5" Diameter



CBLBL CBLSL CBLWH	RECT2 Rectangular 7" X 4"
--	----------------------------------

Snoot

Visually shields lamp and reduces glare.



Series	Diameter
SNOOTBL	175 1.75" Diameter
	200 2" Diameter
	300 3" Diameter
	375 3.75" Diameter
	469 4-11/16" Diameter

SNOOTBL SNOOTSL SNOOTSTN SNOOTWH	390 3.9" Diameter
---	--------------------------

SNOOTBL SNOOTSL SNOOTWH	RECT2 Rectangular 7" X 4"
--	----------------------------------

Eyebrow

Reduces uplight, visually shields lamp and reduces glare.



Series	Diameter
EYEBROWBL	175 1.75" Diameter
	200 2" Diameter
	300 3" Diameter
	375 3.75" Diameter
	469 4-11/16" Diameter
	RECT2 Rectangular 7" X 4"

Cross Baffle

Visually shields lamp and reduces glare.



Series	Diameter
XBAFLBL	375 3.75" Diameter
	469 4-11/16" Diameter

Barn Doors

Adjustable doors control glare. Attaches to fixture.



T71BL
Black Barn Doors. For trac fixtures T303, T313, T326, T393, T423
Accepts 3 3/4" diameter accessories.

T72BL
Black Barn Doors. For trac fixtures T305, T315, T327, T338, T340, T395, T425.
Accepts 4 11/16" diameter accessories.

T73BL
Black Barn Doors. For trac fixtures T307, T317, T328, T342, T397, T427.
Accepts 5 1/2" diameter accessories.

T73WH
White Barn Doors. For trac fixtures T307, T317, T328, T342, T397, T427.
Accepts 5 1/2" diameter accessories.

T74BL
Black Barn Doors. For Flex12 TFG116, TFP116 and Trac12 TL109, TL116, TLP116,
Wishbone T480, Delta 200 T216, TP216 and Mini Spots T430, T431 and T442.
Accepts 1 3/4" diameter accessories.

T7470BL
Black Barn Doors. For use with Flex12 TF130, Trac12 TL117, TL130, TL301, Universal
T401 and Trapezia T630 that use MR16 lamps with cover glass. Also requires T7400
Accessory Holder (order separately).

TBDR BLCK 375
Black Barn Doors. For various trac fixtures including T254L, T262L, T263L, T385L
and T387L. Accepts 3 3/4" diameter accessories.

TBDR BLCK 440
Black Barn Doors. For various trac fixtures including T271L and T272L. Accepts
4 11/16" diameter accessories.

TBDR BLCK 469
Black Barn Doors. For various trac fixtures including T209L, T255L, T265L and
T267L. Accepts 4 11/16" diameter accessories.

TBDR BLCK RECT2
Black Barn Doors. For various rectangular trac fixtures including T258L, T259L and
T260L.

TW71BL
Black Barn Doors. For Wireform[®] trac fixtures T435.
Accepts 3 3/4" diameter accessories.

TW72BL
Black Barn Doors. For Wireform[®] trac fixtures T437.
Accepts 4 11/16" diameter accessories.

TW75BL
Black Barn Doors. For Wireform[®] trac fixtures T433.
Accepts 3 3/4" diameter accessories.


Specifications subject to change without notice.

TRAC-MASTER®

Fixture Accessories

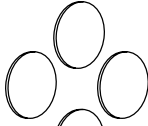
LIGHT CONTROL ACCESSORIES

Color Filters

 
Series	Diameter	Color Filter	
	CGF		
	175	1.75" Diameter	MPINK Medium Pink
	200	2" Diameter	WRWD Warm Red
	275	2.75" Diameter	DLTBLUE Daylight Blue
	300	3" Diameter	MBLU Medium Blue
	375	3.75" Diameter	MAMB Medium Amber
	469	4-11/16" Diameter	MGRN Medium Green
550	5.5" Diameter		

Dichroic Color Filters

Provides more saturated color than a Color Filter.

Series	Diameter	Color Filter	
	DGF		
	175	1.75" Diameter	DRED Red
	200	2" Diameter	MGRN Medium Green
	275	2.75" Diameter	MBLU Medium Blue
	300	3" Diameter	DYEL Yellow
	375	3.75" Diameter	MAGEN Magenta
	469	4-11/16" Diameter	CYAN Cyan

Dichroic Color Correction Filters

Series	Diameter	Color Filter	
	DCCF		
	175	1.75" Diameter	HAL2700 Halogen-to-Incandescent
	200	2" Diameter	HIDINC HID-to-Incandescent
	275	2.75" Diameter	HL4250 Halogen-to-Daylight
	300	3" Diameter	
	375	3.75" Diameter	
469	4-11/16" Diameter		

Beam Control Lenses

 
Prismatic Spread Glass Lens Coarse prismatic lens reduces striations and enlarges the beam.

Linear Spread Glass Lens Oval pattern linear spread lens directs beam into an elongated oval shape.

Solite Lens Eliminates striations without altering size of beam.

 
Diffusion Lens Frosted lens softens the beam and lightly diffuses the pattern.

UV Filter Optivex Museum Quality UV Filter. Filters out transmission below 400nm.

Series	Diameter
	PRISM
	LSPREAD
	SOLITE
	DIFF
	UVF
175	1.75" Diameter
200	2" Diameter
275	2.75" Diameter
300	3" Diameter
375	3.75" Diameter
469	4-11/16" Diameter

Accessory Holder

Attaches to fixture.



T560BL

For trac fixtures T303, T313, T326, T393, T423. Accepts 3 3/4" diameter accessories.

T570BL

For trac fixtures T305, T315, T327, T338, T340, T395, T425. Accepts 4 11/16" diameter accessories.

T580BL

For trac fixtures T307, T317, T328, T342, T397, T427. Accepts 5 1/2" diameter accessories.

T660BL

For Strap trac fixtures, Delta 200 T218. Accepts 3 3/4" diameter accessories.

T670BL

For Strap trac fixtures, Delta 200 T219. Accepts 4 11/16" diameter accessories.

TAH BLCK 375

For trac fixture T1020. Accepts 3.75" diameter accessories.

TAH BLCK 469

For trac fixtures T1030, T1031S. Accepts 4 11/16" diameter accessories.

TAH BLCK 550

For trac fixture T1038. Accepts 5.5" diameter accessories.

MR16 Accessory Holder

Attaches to MR16 lamp without the use of tools or clips.



T7400BL, T7400SA

For use with Flex12 TF130, TF301, Trac12 TL117, TL130, TL301, Flyback T227, TP216, Universal T401 and Trapezia T630. Accepts up to two 2" media and/or T7470BL, T7470SA Barn Doors.

Series	Diameter
T7400BL	200 2" Diameter
T7400SA	

Accessory Spring Kits

TASK1

For Gimball 6 fixtures. Accepts 2" diameter accessories.

TASK2

For Concentricity 16 fixtures. Accepts 2" diameter accessories.