


Horizontal Baffle ☆

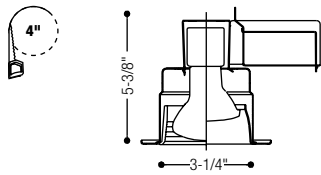


- 0029BK** Black Baffle
- 0029WH** White Baffle


Frame-In Kit	Ceiling	Wattage	Lamping
Complete Units	Non-IC	50W 50W	PAR20 R20



 WH



Black Baffle

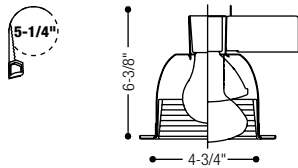


- 0039BK** Black Baffle
- 0039WH** White Baffle

Frame-In Kit	Ceiling	Wattage	Lamping
Complete Units	Non-IC	75W 75W 40W	PAR30 BR30 A19

Phenolic step baffle. For general lighting, space 6' between luminaires. For task lighting, use medium beam spread lamps.

Shower Light ☆

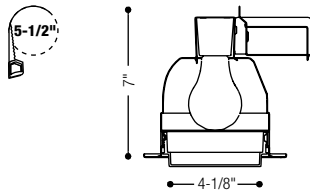

- 0033WH** White Lexan®

Frame-In Kit	Ceiling	Wattage	Lamping
Complete Units	Non-IC	40W	A19



WH

For fast and easy shower remodeling. Virtually unbreakable Lexan diffuser. CSA-certified for wet locations, showers and spas.