




These trims are offered in 3-3/4", 5-1/4" and 6-3/4" aperture sizes in Specular Clear or Clear Diffuse finishes. Specular Clear finish offers superior performance and provides an Iridescent-Free coating to eliminate rainbowing. Clear Diffuse is a semi-specular finish that diffuses light and provides a soft, even illumination that minimizes the mirror image typically found on specular finishes.

Performance Vertical Open Downlight ☆☆☆☆

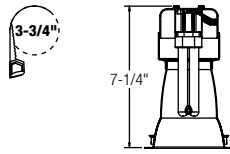


2001CL Specular Clear
2001CD Clear Diffuse

18W TTT		
Ht. to Workplane	F.C	Beam 99° Dia.
4'	15	6'
5'	10	7'
6'	7	8'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Watts Sq. Ft.
4'	60	2.06
5'	41	1.43
6'	27	0.92

Frame-In Kit	Ceiling	Wattage	Lamping
2001F13U			
2001F13-347	Non-IC	13W	(1) Triple or Quad
2001F18U			
2001F18-347	Non-IC	18W	(1) Triple
2001F13ICUN	IC/Airseal®	13W	(1) Triple or Quad
2001F18ICUN	IC/Airseal®	18W	(1) Triple

2001CL

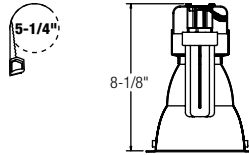


1001CL Specular Clear
1001CD Clear Diffuse

26W TTT		
Ht. to Workplane	F.C	Beam 90° Dia.
6'	14	8'
7'	10	9'
8'	8	10'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Watts Sq. Ft.
4'	54	1.69
5'	38	1.17
6'	24	0.75

Frame-In Kit	Ceiling	Wattage	Lamping
1001F13U			
1001F13-347	Non-IC	13W	(1) Triple or Quad
1001F18U			
1001F18-347	Non-IC	18W	(1) Triple
1001F26U			
1001F26-347	Non-IC	26W	(1) Triple
1001FR18U			
1001FR18-347	Non-IC Remodeler	18W	(1) Triple
1001FR26U			
1001FR26-347	Non-IC Remodeler	26W	(1) Triple

1001CL

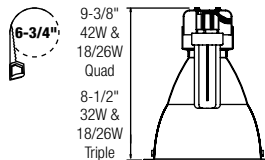

1101CL Specular Clear
1101CD Clear Diffuse

42W TTT		
Ht. to Workplane	F.C	Beam 76° Dia.
6'	40	6'
8'	24	8'
10'	15	10'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Watts Sq. Ft.
5'	88	1.91
6'	56	1.22
7'	32	0.69

Frame-In Kit	Ceiling	Wattage	Lamping
1101F13U			
1101F13-347	Non-IC	13W	(1) Triple or Quad
1101F18U			
1101F18-347	Non-IC	18W	(1) Triple or Quad
1101F2642U			
1101F2642-347	Non-IC	26W 32/42W	(1) Triple or Quad (1) Triple
1101FR18U			
1101FR18-347	Non-IC Remodeler	18W	(1) Triple or Quad
1101FR2642U			
1101FR2642-347	Non-IC Remodeler	26W 32/42W	(1) Triple or Quad (1) Triple

1101CL

Note: For dimming options, please consult the corresponding product Spec Sheet on www.canlyte.com.