




Versatile, low brightness downlight. Precision-fitted die-cast aluminum step baffle is finished in black or white and the recessed lamp reduces glare. Anobrite® aluminum reflector concentrates output from A and self-ballasted compact fluorescent lamps.

Premium Die-Cast Step Baffle ☆☆

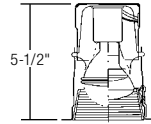


**2005BK** Black Baffle  
**2005WB** White Baffle

Frame-In Kit	Ceiling	Wattage	Lamping
<b>2002</b>	Non-IC	50W 75W 60W	PAR20 PAR16/R20 A19
<b>2003RS</b>	Non-IC Remodeler	50W 75W 60W	PAR20 PAR16/R20 A19
<b>2002AIC</b>	IC/Airseal®	50W 45W 50W	PAR20 PAR16 R20

50W PAR20		
Ht. to Floor	F.C. At 30" Above Floor	Beam Dia.
8'	53	5'
9'	38	5.5'
10'	29	6'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	40	36
5'	29	24
6'	19	12

**2005BK**

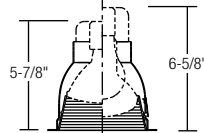


**1005BK** Black Baffle  
**1005WB** White Baffle

Frame-In Kit	Ceiling	Wattage	Lamping
<b>1002</b>	Non-IC	75W 75W 75W	PAR30 BR30 A19
<b>1004ICN</b>	Non-IC	75W 40W	PAR30 A19
<b>1003RS</b>	Non-IC Remodeler	75W 75W	PAR30 BR30
<b>1004ICRS</b>	Non-IC Remodeler	75W 40W	PAR30 A19
<b>1000IC</b>	IC	75W 65W 40W	PAR30 BR30 A19
<b>1004ICN</b>	IC/Airseal®	50W 65W (60W)	PAR30 BR30
<b>1004ICXN</b>	IC/Airseal®	75W 65W 40W	PAR30 BR30 A19
<b>1004ICRS</b>	IC/Airseal® Remodeler	50W 65W (60W)	PAR30 BR30

75W PAR30		
Ht. to Floor	F.C. At 30" Above Floor	Beam Dia.
8'	61	6'
9'	43	7'
10'	33	8'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	63	55
5'	45	37
6'	34	18

**1005BK**

( ) = Max wattage for BK.

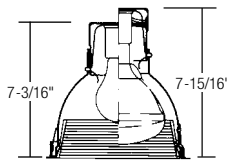

**1105BK** Black Baffle  
**1105WB** White Baffle

Frame-In Kit	Ceiling	Wattage	Lamping
<b>1102P1</b>	Non-IC	150W 150W 150W 100W	PAR38 BR40 A21 A19
<b>1104ICN</b>	Non-IC	90W 85W 120W	PAR38 BR30 BR40
<b>1103RS</b>	Non-IC Remodeler	75W 150W 150W 100W	A19 PAR38 BR40 A21
<b>1104ICRS</b>	Non-IC Remodeler	90W 85W 120W 75W	PAR38 BR30 BR40 A19
<b>1100IC</b>	IC	100W 100W 60W	PAR38 BR40 A19
<b>1104ICN</b>	IC/Airseal®	75W 65W 40W	PAR38 BR40 A19
<b>1104ICXN</b>	IC/Airseal®	100W 100W 60W	PAR38 BR40 A19
<b>1104ICRS</b>	IC/Airseal® Remodeler	75W 65W 60W (52)	PAR38 BR40 A19

150W PAR38		
Ht. to Floor	F.C. At 30" Above Floor	Beam Dia.
8'	175	3.5'
9'	125	4'
10'	94	4.5'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	88	81
5'	63	54
6'	42	27

**1105BK**

( ) = Max wattage for BK.