


Opal Disk ☆☆




**1021** Opal Glass

75W A19		
Ht. to Floor	F.C.	Beam Dia.
	At 30" Above Floor	
8'	3	33'
9'	2	37'
10'	1.5	41'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	17	11
5'	12	7
6'	8	4

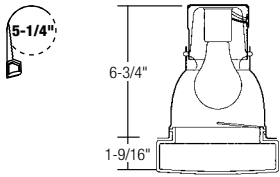

Cased opal glass gives widespread, even illumination. Diffuser removes easily with twist-tite action. Sturdy hinge supports glass, assuring safe relamping. Gasket keeps out dirt and moisture. Suitable for wet locations, showers and spas.

Frame-In Kit	Ceiling	Wattage	Lamping
<b>1002</b>	Non-IC	75W	A19
<b>1003RS</b>	Non-IC Remodeler	75W	A19
<b>1000IC</b>	IC	40W	A19
<b>1004ICXN</b>	IC/Airseal®	40W	A19

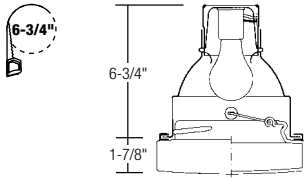


**1121** Opal Glass

100W A19		
Ht. to Floor	F.C.	Beam Dia.
	At 30" Above Floor	
8'	8	22'
9'	6	25'
10'	4	28'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	38	25
5'	27	17
6'	18	9

**1121**

Frame-In Kit	Ceiling	Wattage	Lamping
<b>1102P1</b>	Non-IC	100W	A19
<b>1104ICN</b>	Non-IC	75W	A19
<b>1103RS</b>	Non-IC Remodeler	100W	A19
<b>1104ICRS</b>	Non-IC Remodeler	75W	A19
<b>1100IC</b>	IC	60W	A19
<b>1104ICN</b>	IC/Airseal®	40W	A19
<b>1104ICXN</b>	IC/Airseal®	52W	A19
<b>1104ICRS</b>	IC/Airseal® Remodeler	40W	A19

Lexan® Dish ☆

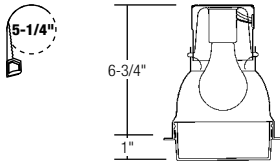


**1078** Opal Lexan®

60W A19		
Ht. to Floor	F.C.	Beam Dia.
	At 30" Above Floor	
8'	2.5	39'
9'	2	43'
10'	1.5	48'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	12	8
5'	9	5
6'	6	3



Even illumination from durable Lexan® diffuser, supplied with gasket to keep out dirt and moisture. Easy twist-lock relamping. Aluminum reflector finished in white. Economical choice for low budget applications. Suitable for wet locations, showers and spas.

Frame-In Kit	Ceiling	Wattage	Lamping
<b>1002</b>	Non-IC	60W	A19
<b>1003RS</b>	Non-IC Remodeler	60W	A19
<b>1000IC</b>	IC	40W	A19

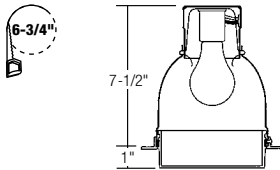

**1178SH** Opal Lexan®

75W A19		
Ht. to Floor	F.C.	Beam Dia.
	At 30" Above Floor	
8'	5	27'
9'	3	30'
10'	2.5	34'
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	25	16
5'	18	11
6'	12	5

**1178SH**

Frame-In Kit	Ceiling	Wattage	Lamping
<b>1102P1</b>	Non-IC	75W	A19
<b>1104ICN</b>	Non-IC	40W	A19
<b>1103RS</b>	Non-IC Remodeler	75W	A19
<b>1104ICRS</b>	Non-IC Remodeler	40W	A19
<b>1100IC</b>	IC	40W	A19
<b>1104ICN</b>	IC/Airseal®	40W	A19
<b>1104ICXN</b>	IC/Airseal®	40W	A19
<b>1104ICRS</b>	IC/Airseal® Remodeler	40W	A19