


Adjustable Premium Cone ☆☆☆



- 304ABPX** Antique Brass Reflector and Self-Flange
- 304STPX** Brushed Steel Reflector and Self-Flange

Note: Frame-in Kit not applicable: **303MRE**.

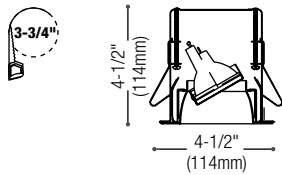


Brushed Steel Reflector and Self-Flange

Frame-In Kit	Ceiling	Wattage	Lamping
<b>LOW VOLTAGE</b>			
<b>302MRSPX</b>	Non-IC	50W	MR16
<b>302MREX</b>		37W	MR16 IR
<b>302MRLX</b>			
<b>300MRSPX</b>	Non-IC Remodeler	50W	MR16
<b>3401MREX</b>		37W	MR16 IR
<b>302MRIC7SPX</b>	IC	50W	MR16
<b>302MRIC9SPX</b>		37W	MR16 IR
<b>302MRAICSPX</b>	IC/Airseal®	50W	MR16
<b>302MRAICEX</b>		37W	MR16 IR
<b>INCANDESCENT</b>			
<b>302ESX</b>	Non-IC	50W	ES/ESD16 (GU10)
<b>300ESX</b>	Non-IC Remodeler	50W	ES/ESD16 (GU10)
<b>302ESICX</b>	IC	50W	ES/ESD16 (GU10)
<b>302ESAICX</b>	IC/Airseal®	50W	ES/ESD16 (GU10)
<b>HID</b>			
<b>3401MH39MRE1</b>	Non-IC Remodeler	39W	MR16CMH

One-piece steel reflector and flange for uniform look. Recessed lamp rotates 360° horizontally and 35° vertically, can be aimed without removing trim. For mounting plates for use with remodelers see p. 552. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 553.

Adjustable Premium Die-Cast Step Baffle ☆☆☆

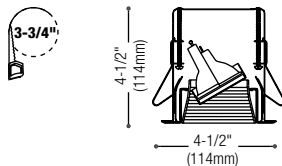

- 305BKX** Black Step Baffle and White Flange
- 305ALPX** Aluminum Painted Step Baffle and Self-Flange
- 305WHWX** White Step Baffle and Self-Flange

Note: Frame-in Kit not applicable: **303MRE**.



Aluminum Painted Step Baffle and Self-Flange



White Step Baffle and Self-Flange

Frame-In Kit	Ceiling	Wattage	Lamping
<b>LOW VOLTAGE</b>			
<b>302MRSPX</b>	Non-IC	50W	MR16
<b>302MREX</b>		37W	MR16 IR
<b>302MRLX</b>			
<b>300MRSPX</b>	Non-IC Remodeler	50W	MR16
<b>3401MREX</b>		37W	MR16 IR
<b>302MRIC7SPX</b>	IC	50W	MR16
<b>302MRIC9SPX</b>		37W	MR16 IR
<b>302MRAICSPX</b>	IC/Airseal®	50W	MR16
<b>302MRAICEX</b>		37W	MR16 IR
<b>INCANDESCENT</b>			
<b>302ESX</b>	Non-IC	50W	ES/ESD16 (GU10)
<b>300ESX</b>	Non-IC Remodeler	50W	ES/ESD16 (GU10)
<b>302ESICX</b>	IC	50W	ES/ESD16 (GU10)
<b>302ESAICX</b>	IC/Airseal®	50W	ES/ESD16 (GU10)
<b>HID</b>			
<b>3401MH39MRE1</b>	Non-IC Remodeler	39W	MR16CMH

One-colour luminaire features a one-piece die-cast flange and step baffle (except 305BKX). Recessed lamp rotates 360° horizontally and 35° vertically, can be aimed without removing trim. For mounting plates for use with remodelers see p. 552. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 553.