



Performance Vertical Open Downlight ☆☆☆




Frame-In Kit	Ceiling	Wattage	Lamping
2001F13U	Non-IC	13W	(1) Triple or Quad
2001F13-347	Non-IC	13W	(1) Triple or Quad
2001F18U	Non-IC	18W	(1) Triple
2001F18-347	Non-IC	18W	(1) Triple
2001F13ICUN	IC/Airseal®	13W	(1) Triple or Quad
2001F18ICUN	IC/Airseal®	18W	(1) Triple

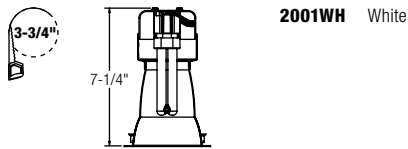

These trims are offered in 3-3/4", 5-1/4" and 6-3/4" aperture sizes in White. White finish blends into ceiling for minimal impact on ceiling appearance.

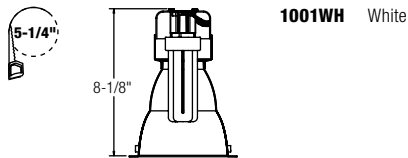

Frame-In Kit	Ceiling	Wattage	Lamping
1001F13U	Non-IC	13W	(1) Triple or Quad
1001F13-347	Non-IC	13W	(1) Triple or Quad
1001F18U	Non-IC	18W	(1) Triple
1001F18-347	Non-IC	18W	(1) Triple
1001F26U	Non-IC	26W	(1) Triple
1001F26-347	Non-IC	26W	(1) Triple
1001FR18U	Non-IC Remodeler	18W	(1) Triple
1001FR18-347	Non-IC Remodeler	18W	(1) Triple
1001FR26U	Non-IC Remodeler	26W	(1) Triple
1001FR26-347	Non-IC Remodeler	26W	(1) Triple

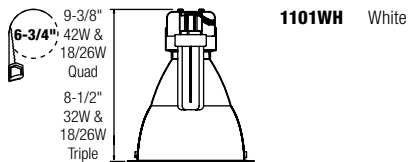

Frame-In Kit	Ceiling	Wattage	Lamping
1101F13U	Non-IC	13W	(1) Triple or Quad
1101F13-347	Non-IC	13W	(1) Triple or Quad
1101F18U	Non-IC	18W	(1) Triple or Quad
1101F18-347	Non-IC	18W	(1) Triple or Quad
1101F2642U	Non-IC	26W	(1) Triple or Quad
1101F2642-347	Non-IC	32/42W	(1) Triple
1101FR18U	Non-IC Remodeler	18W	(1) Triple or Quad
1101FR18-347	Non-IC Remodeler	18W	(1) Triple or Quad
1101FR2642U	Non-IC Remodeler	26W	(1) Triple or Quad
1101FR2642-347	Non-IC Remodeler	32/42W	(1) Triple

Note: For dimming options, please consult the corresponding product Spec Sheet on www.canlyte.com.