


Contour ☆☆




**316WHX** White

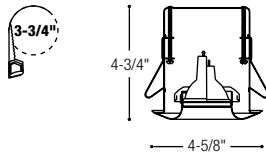

Frame-In Kit	Ceiling	Wattage	Lamping
<b>LOW VOLTAGE</b>			
<b>302MRSPX</b>	Non-IC	50W	MR16
<b>302MREX</b>		37W	MR16 IR
<b>302MRLX</b>			
<b>300MRSPX</b>	Non-IC Remodeler	50W	MR16
<b>3401MREX</b>		37W	MR16 IR
<b>303MRE</b>	Non-IC Remodeler	37W	MR16 IR
<b>302MRIC7SPX</b>	IC	50W	MR16
<b>302MRIC9SPX</b>		37W	MR16 IR
<b>302MRAICSPX</b>	IC/Airseal®	50W	MR16
<b>302MRAICEX</b>		37W	MR16 IR
<b>INCANDESCENT</b>			
<b>302ESX</b>	Non-IC	50W	ES/ESD16 (GU10)
<b>300ESX</b>	Non-IC Remodeler	50W	ES/ESD16 (GU10)
<b>302ESICX</b>	IC	50W	ES/ESD16 (GU10)
<b>302ESAICX</b>	IC/Airseal®	50W	ES/ESD16 (GU10)

Simple contoured architectural flange for unique new appearance. Specially designed for task areas and wet locations such as showers. Gasket included for shower applications, can be removed. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For mounting plates for use with remodelers see p. 552. For thicker ceilings see extra thick ceiling housing accessories on p. 553.

Shower Light ☆☆

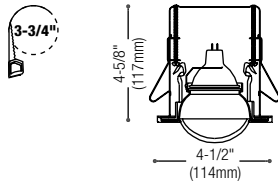

**376WHX** White Frosted Glass and White Flange

*Note: Frame-in Kit not applicable: 303MRE and ES16 Frame-in Kits.*



Frame-In Kit	Ceiling	Wattage	Lamping
<b>LOW VOLTAGE</b>			
<b>302MRSPX</b>	Non-IC	50W	MR16
<b>302MREX</b>		37W	MR16 IR
<b>302MRLX</b>			
<b>300MRSPX</b>	Non-IC Remodeler	50W	MR16
<b>3401MREX</b>		37W	MR16 IR
<b>302MRIC7SPX</b>	IC	37W	MR16 IR
<b>302MRIC9SPX</b>	IC	50W	MR16
		37W	MR16 IR
<b>302MRAICSPX</b>	IC/Airseal®	50W	MR16
<b>302MRAICEX</b>		37W	MR16 IR

Simple architectural flange with glass diffuser for a new appearance. Specially designed for wet locations such as showers (gasket included). For mounting plates for use with remodelers see p. 552. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 553.