



A-Shape LED

20A30/LED/865/P/E26/ND 4/1FB

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
RoHS mark	RoHS mark
Nominal Lifetime (Nom)	25000 h
Switching Cycle	50000X
Technical Type	20-160W
Light Technical	
Color Code	865 [CCT of 6500K]
Beam Angle (Nom)	150 °
Luminous Flux (Nom)	2300 lm
Luminous Flux (Rated) (Nom)	2300 lm
Color Designation	Cool Daylight
Correlated Color Temperature (Nom)	6500 K
Luminous Efficacy (rated) (Nom)	115.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	20 W
Lamp Current (Nom)	175 mA
Wattage Equivalent	160 W

Starting Time (Nom)	1 s
Warm Up Time to 60% Light (Nom)	1 s
Power Factor (Nom)	0.9
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	85 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Frosted
Product Data	
Order product name	20A30/LED/865/P/E26/ND 4/1FB
EAN/UPC - Product	046677479282
Order code	929001854704
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001854704
Net Weight (Piece)	0.190 kg

A-Shape LED


Dimensional drawing

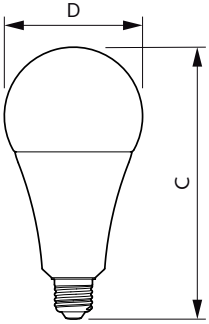


Bulb A95 120V 19-160W 2300lm 6500K E26

Product	D	C
20A30/LED/865/P/E26/ND 4/1FB	95 mm	185 mm


Photometric data

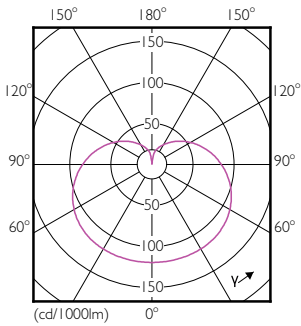

LEDbulb 20W A30 E26 865 15D ND

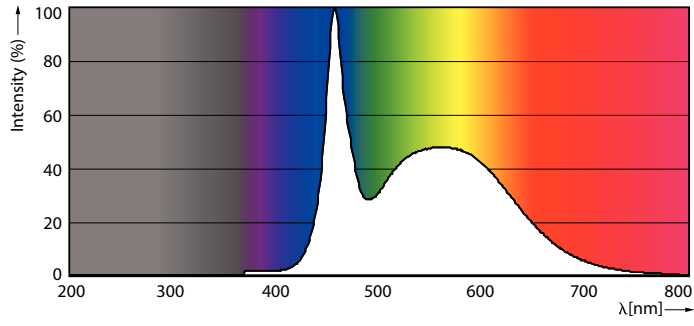



LEDbulb 20W A30 E26 865 15D ND

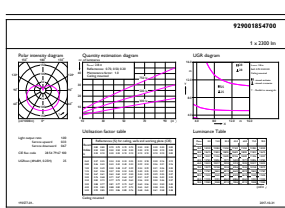

LEDbulb 20W A30 E26 865 15D ND

A-Shape LED

Lifetime

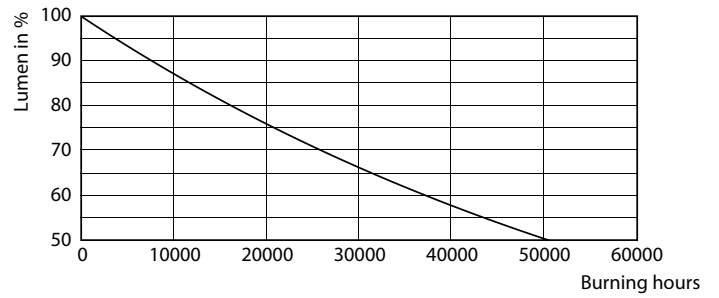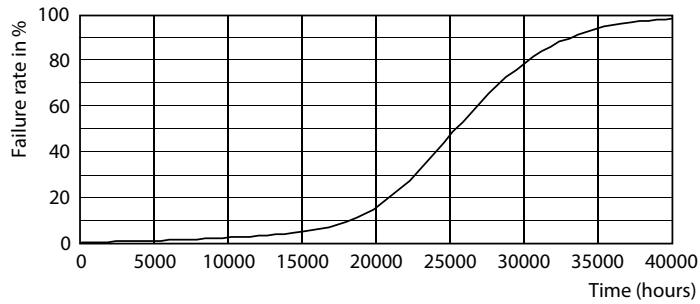

LEDbulb 20W A30 E26 865 15D ND

LEDbulb 20W A30 E26 865 15D ND

