



A-Shape LED

9.5A19/PER/827-22/P/E26/WG 6/1FB

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
RoHS mark	RoHS mark
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Technical Type	9.5-60W
Light Technical	
Color Code	822-827 [tunable warm white]
Beam Angle (Nom)	250 °
Luminous Flux (Nom)	800 lm
Luminous Flux (Rated) (Nom)	800 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2200-2700 K
Luminous Efficacy (rated) (Nom)	84.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	9.5 W
Lamp Current (Nom)	105 mA
Wattage Equivalent	60 W

Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.8
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	85 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Frosted
Product Data	
Order product name	9.5A19/PER/827-22/P/E26/WG 6/1FB
EAN/UPC - Product	046677479442
Order code	929001837304
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001837304
Net Weight (Piece)	0.084 kg

A-Shape LED


Dimensional drawing

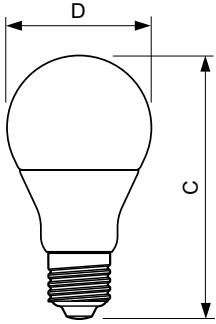


Bulb A19 9.5-60W 800lm 2200-2700K E26 D

Product	D	C
9.5A19/PER/827-22/P/E26/WG 6/1FB	62 mm	111.3 mm


Photometric data

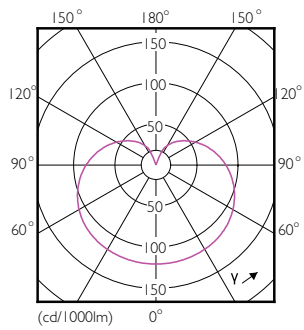

40W E26 A19 FR 250D 822-827 2200-2700K

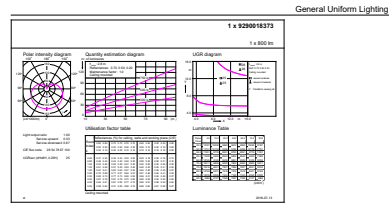



60W E26 A19 FR 250D 822-827 2200-2700K

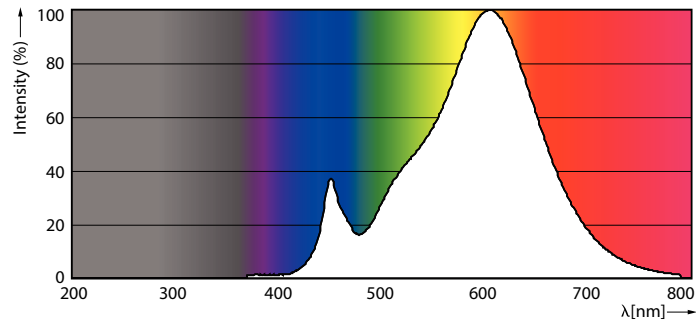

40W E26 A19 FR

A-Shape LED

Lifetime

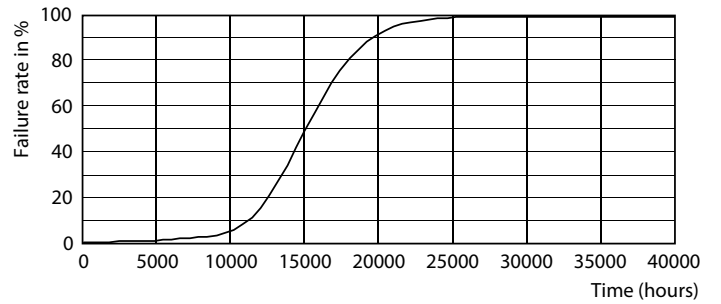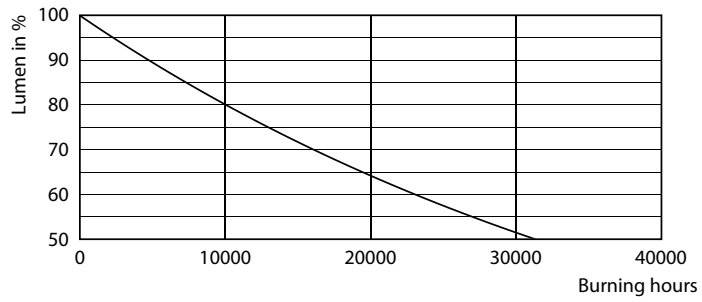

40W E26 A19 FR

40W E26 A19 FR

