

## FEATURES & SPECIFICATIONS

### INTENDED USE

Ideal where high brightness and good illumination levels are required such as retail, light industrial and warehouses.

### ATTRIBUTES

Fixture can be assembled with snap together components and requires no tools. Available in one lamp or two lamp configuration.

### CONSTRUCTION

Heavy-duty channel, die-formed from Code-gauge steel.

Sturdy channel cover secured by captive quarter-turn latch for easy access to wireway.

Combination endplate/channel connector furnished with each fixture.

### FINISH

Five-stage iron phosphate pretreatment ensures superior paint adhesion and rust resistance. Painted parts finished with high-gloss, baked white enamel.

### ELECTRICAL SYSTEM

**MVOLT ballasts are electronic, full light output-reduced energy. Less than 10% THD. Multi-volt operation, 120-277V.**

**120V ballasts are thermally protected, resetting, Class P, LPF, non-PCB, UL Listed, CSA Certified.**

**Rapid-start ballasts are sound rated A.**

### INSTALLATION

For unit or row installations, surface or suspended mounting.

### LISTING

UL listed to US and Canadian safety standards. Optional: Mexico NOM.

### WARRANTY

1-year limited warranty. Complete warranty terms located at [www.acuitybrands.com/CustomerResources/Terms\\_and\\_conditions.aspx](http://www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx)

NOTE: Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

Catalog Number
Notes
Type

Contractor Select

# Strip Lights



C Specifications	Z1 Specifications	Z2 Specifications	S Specifications
Length: 24 (61.0)	Length: 24 (61.0)	Length: 24 (61.0)	Length: 18 (45.7)
36 (91.4)	36 (91.4)	36 (91.4)	24 (61.0)
48 (122.0)	48 (122.0)	48 (122.0)	36 (91.4)
72 (182.9)	96 (243.9)	96 (243.9)	48 (122.0)
96 (243.9)	Width: 2-1/4 (5.7)	Width: 2-1/4 (5.7)	Width: 2-3/4 (6.9)
Width: 4-3/8 (11.1)	Depth: 1-1/4 (3.1)	Depth: 1-1/4 (3.1)	Depth: 1-3/4 (4.4)
Depth: 2-1/8 (5.4)			

All dimensions are inches (centimeters).

## ORDERING INFORMATION

Catalog Number	UPC	Description	# of Lamps	Length	Wattage	Voltage	Ballast Type	Lamp Included	Pallet Qty.	Standard Carton Qty.
C232 MV	745975079711	T8 general-purpose strip	2	48"	32	120-277	Electronic, instant start	N	99	1
TC232 MV	745975080809	T8 general-purpose strip	4	96"	32	120-277	Electronic, instant start	N	99	1
C225 MV	745975081219	T8 general-purpose strip	2	36"	25	120-277	Electronic, instant start	N	99	1
C217 MV	745975081493	T8 general-purpose strip	2	24"	17	120-277	Electronic, instant start	N	198	1
C296	745973789766	T12 general-purpose strip	2	96"	75	120	Electronic, rapid start	N	99	1
C296T8 MV	745977076145	T8 general-purpose strip	2	96"	75	120-277	Electronic, instant start	N	99	1
Z117 MV	745976682675	T8 low-profile strip	1	24"	17	120-277	Electronic, instant start	N	448	1
Z125 MV	745976682705	T8 low-profile strip	1	36"	25	120-277	Electronic, instant start	N	224	1
Z132 MV	745976682736	T8 low-profile strip	1	48"	32	120-277	Electronic, instant start	N	224	1
TZ132 MV	745976682767	Tandem, T8 low-profile strip	2	96"	32	120-277	Electronic, instant start	N	224	1
Z217 MV	745976682781	T8 low-profile strip	2	24"	17	120-277	Electronic, instant start	N	448	1
Z225 MV	745976682927	T8 low-profile strip	2	36"	25	120-277	Electronic, instant start	N	224	1
Z232 MV	745976682941	T8 low-profile strip	2	48"	32	120-277	Electronic, instant start	N	224	1
TZ232 MV	745976682989	Tandem, T8 low-profile strip	4	96"	32	120-277	Electronic, instant start	N	224	1


# Strip Lights

## DIMENSIONS


Inches (centimeters). Subject to change without notice.

### Z STRIPS

#### T8 DIMENSIONS

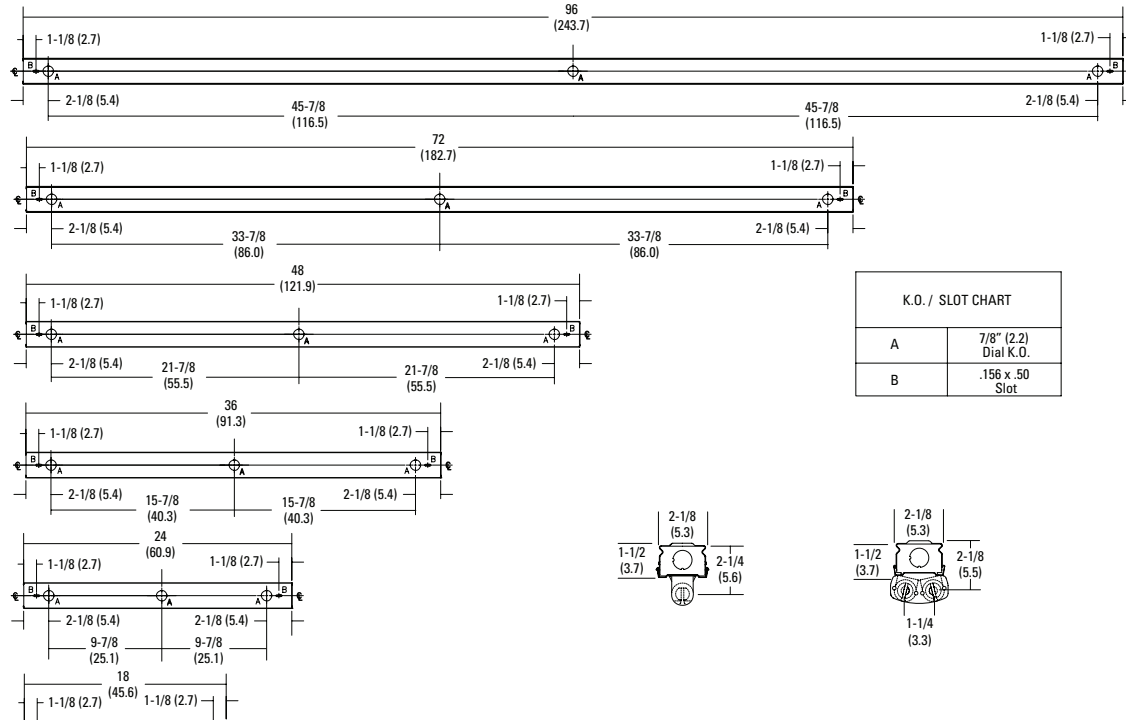

#### T5 DIMENSIONS

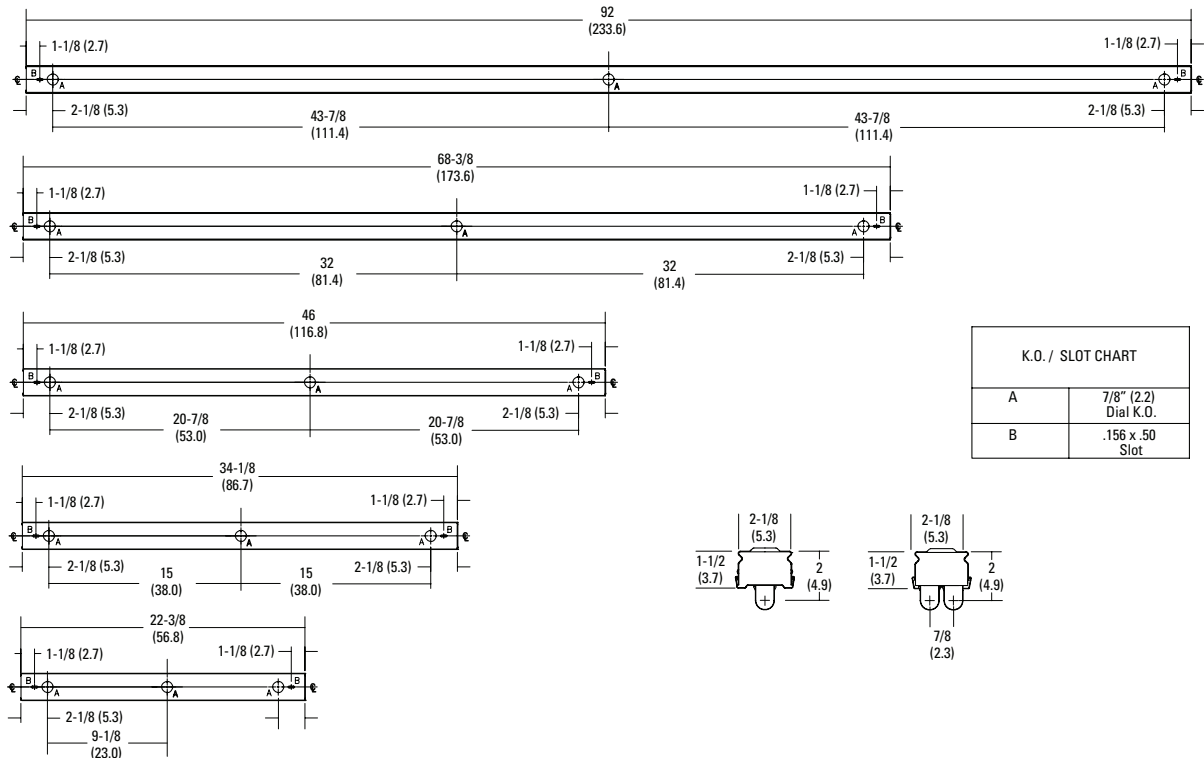


# Strip Lights

## DIMENSIONS (continued)

Inches (centimeters). Subject to change without notice.

### C STRIPS

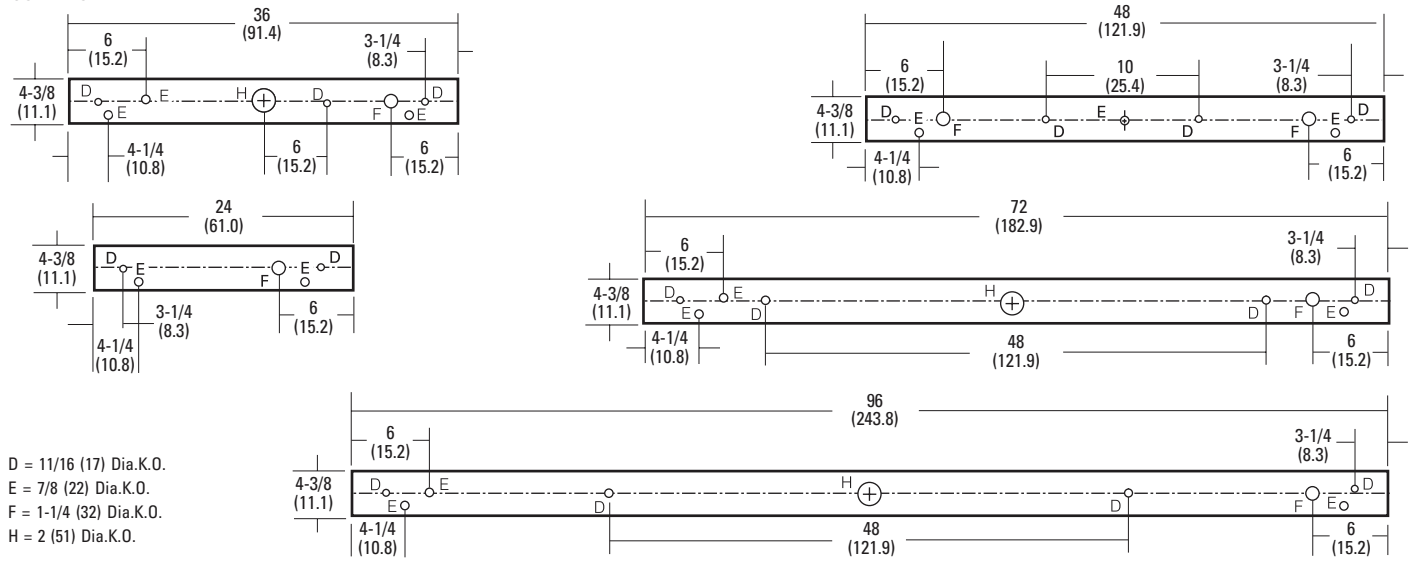

## PHOTOMETRICS

See [www.acuitybrands.com](http://www.acuitybrands.com).