


## Set-Screw Wire Connectors



- Eliminates need for restripping wire each time connection is disturbed
- Solid brass sleeves in three sizes handle 18 through 12 AWG wires
- Set-screw easily and securely applies maximum compression to conductors to ensure a vibration-resistant splice
- Permits fast visual inspection of splice
- Tough, flame-retardant shell rated at 150°C (302°F)
- UL Listed to 486C and CSA Certified to C22.2 #188 ; comply with Federal Specification W-S-610E

Model	Wire Combination Range	Quantity	Cat. No.
10	300V 22 thru 16 AWG Min. 1 #20 w/1 #22 Max. 2 #14 w/1 #16	Box of 100	<b>30-210</b>
		Carton of 1,000	<b>30-310</b>
11	600V 22 thru 14 AWG Min. 1 #14 w/1 #20 Max. 3 #14 w/2 #18	Box of 100	<b>30-211</b>
		Carton of 1,000	<b>30-311</b>
22	600V 20 thru 10 AWG Min. 1 #16 w/3 #18 Max. 2 #10 w/1 #12	Box of 100	<b>30-222</b>
		Carton of 1,000	<b>30-322</b>

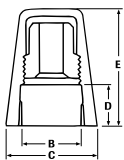

### Dimensions (Inches)

Model	Insert		Shell			
	A	B	C	D	E	
10	1/8	5/16	1/2	19/64	45/64	
11	3/16	3/8	33/64	13/32	63/64	
22	1/4	1/2	11/16	13/32	1-1/64	



## Set-Screw Holder

- Convenient tool for holding and tightening set-screw connectors
- Accepts IDEAL Models 11 and 22 set-screw connectors



For Connector Models	Cat. No.
11 & 22	<b>K-2422</b>

## Noalox® Anti-Oxidant



- Anti-oxidant and anti-seizing compound improves efficiency and service life of aluminum electrical applications
- Suspended zinc particles penetrate and cut aluminum oxide
- Provides additional inner-strand and inner-conductor current paths for improved conductivity and cooler connections
- Carrier material excludes air to prevent further oxidation
- For use with all types of pressure-type wire connectors including screw-on, tap, service entrance and split-bolt
- Reduces galling and seizing on aluminum conduit joints – promotes good ground continuity

Description	Cat. No.
1/2-oz. Tube	<b>30-024</b>
4-oz. Squeeze bottle	<b>30-026</b>
8-oz. Squeeze bottle	<b>30-030</b>
8-oz. Brush cap	<b>30-031</b>
1-gal. Bucket	<b>30-032</b>
5-gal. Bucket	<b>30-040</b>

