


Greenie® Grounding Connector

- Designed for making ground connections and bonding non-metallic sheathed cable
- Contoured wings for maximum leverage
- Live-action, square-wire spring provides superior grounding connections
- Tough, UL 94V-2 flame-retardant shell
- UL Listed to 467 and CSA Certified to C22.2 #188; complies with Federal Specification W-S-610E

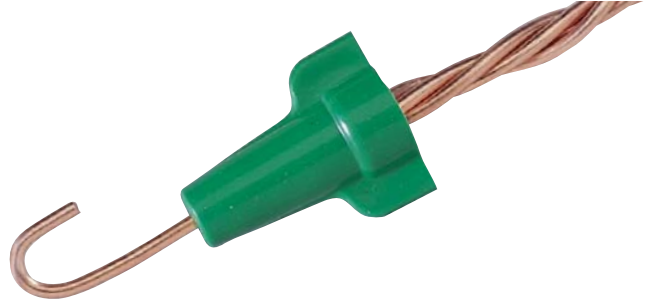

Model	Wire Combination Range	Wire Combination Range (mm)	Quantity	Cat. No.
92®	14 thru 10 AWG Min. 2 #14 Max. 3 #12 & 1 #14	2,5mm ² to 6,0mm ² Min. 2-2,5mm ² Max. 3-4,0mm ² w/1-2,5mm ²	Box of 100	30-092
			Jar of 150	30-092J
			Carton of 1,000	30-192
			Keg of 5,000 (10 bags, 500 ea.)	30-292



Greenie® Grounding Connector fully meets the intent of the N.E.C. and specifically aids in compliance with the following:

ARTICLE 250: GROUNDING

- 250-146 Connecting Receptacle Grounding Terminal to Box
- 250-148 Continuity and Attachment of Equipment Grounding Conductors to Boxes
 - (B) Grounding continuity
 - (D) Nonmetallic boxes