


## Cable Cutter

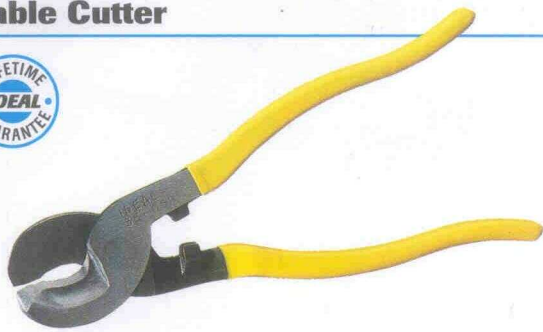

- Drop-forged, high-carbon steel construction
- Precision-ground, hardened cutting edges provide accurate cuts without cable distortion
- Designed for maximum leverage with minimum effort
- Cuts 2/0 aluminum and copper
- Vinyl-coated, comfort-grip handles
- Lifetime guarantee

Description	Cat. No.
9-1/2 in. Cable Cutter	35-052

## Ratcheting Cable Cutters

- Hardened steel blades ensure consistent cuts and long-term durability
- Rounded blade design minimizes cable distortion during cutting
- Quick release mechanism simplifies blade back-out
- Locking mechanism keeps handles closed for easy storage
- High-leverage foot provides stability and leverage when making multiple cuts
- Ergonomic, non-slip handles provide excellent grip and comfort
- 750 KCMIL Ratcheting Cable Cutter is designed to cut 750 KCMIL (MCM) and smaller hard-drawn copper and aluminum cables
- Telco Ratcheting Cable Cutter jaw cuts up to 2,700 pair telephone cable and Stalpath® type communications cable




Description	Cat. No.
<b>750 KCMIL (MCM) Ratcheting Cable Cutter</b>	<b>35-053</b>
Holster	35-024
Replacement blade	35-057
<b>Telco Ratcheting Cable Cutter</b>	<b>35-055</b>
Replacement blade	35-054

Not for cutting steel or ASCR

**CAUTION:** Comfort-grip handles are not designed for protection against electrical shock. Do not use on live circuits.

## Ratcheting Cable Cutter

- Cuts hand drawn copper up to 400 KCMIL (MCM) and soft copper, aluminum and multiple conductor cable up to 600 KCMIL (MCM)
- Hardened steel blades ensure consistent cuts and long-term durability
- Rounded blade design minimizes cable distortion during cutting
- Quick release mechanism simplifies blade back-out
- Locking mechanism keeps handles closed for easy storage
- Ergonomic, non-slip handles provide excellent grip and comfort

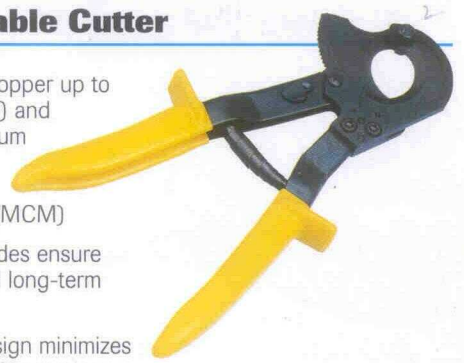

Description	Cat. No.
400 KCMIL (MCM) Ratcheting Cable Cutter	35-056
Replacement blade	35-085

Not for cutting steel or ASCR

## Battery Powered Cable Cutter

- Cuts up to 750 KCMIL hard-drawn copper and up to 1,000 KCMIL copper and aluminum
- Hardened steel blades ensure consistent cuts and long-term durability
- Blade brush keeps debris out of blade area
- Tough plastic housing withstands rugged use
- Three-way switch allows for partial cuts, adjustments and backing off cable
- 12V battery rated for 1,000 charges
- Wrist loop provides added security when cutting overhead cable



Description	Cat. No.
Battery Powered Cable Cutter Kit (Includes cutter, battery, 120V charger, carrying case)	35-064
Battery Powered Cable Cutter Kit (Includes cutter, battery, 220V charger, carrying case)	35-070
Battery Powered Cable Cutter	35-067
Battery only	35-065
120V Battery charger	35-068
220V Battery charger	35-074
Replacement moving blade	35-071
Carrying case	35-073

Not for use on ASCR cable