

## Wire Marker Booklets

- Convenient pocket-size booklets
- Plastic-impregnated cloth construction for long-lasting durability
- Resists abrasion, moisture, dirt and oil
- Perforated 1-1/2 in. markers can be separated into half-length sizes
- Non-smear black legend ensures high visibility
- Self-sticking on wire and cable

### Specifications:

Temperature Range: -40°F to 180°F (-40°C to 82°C)


Adhesion: 45 oz./in. width ultimate



### Legend Assortments\*

Legend	Quantity	Cat. No.
0-9	45 Markers each	44-101
A-Z 0-15 +, -, /	10 Markers each	44-102
1-45	10 Markers each	44-103
46-90	10 Markers each	44-104
1, 2, 3	150 Markers each	44-105
A, B, C	150 Markers each	44-106
T1, T2, T3	150 Markers each	44-107
L1, L2, L3	150 Markers each	44-108
1-15 16-90 A-Z +, -, /, 0	6 Markers each 4 Markers each 2 Markers each 2 Markers each	44-109
1, 2, 3 A, B, C T1, T2, T3 L1, L2, L3	45 Markers each 45 Markers each 30 Markers each 30 Markers each	44-110
+, -, AC, DC POS, NEG, GND NEUT SPARE, BLANK	45 Markers each 33 Markers each 27 Markers each 21 Markers each	44-111

\*Ten pages per booklet with each page bearing the legend assortment indicated. All booklets (except 44-111) contain 450 wire markers and 450 terminal markers. Booklet 44-111 includes 348 wire markers and 348 terminal markers.

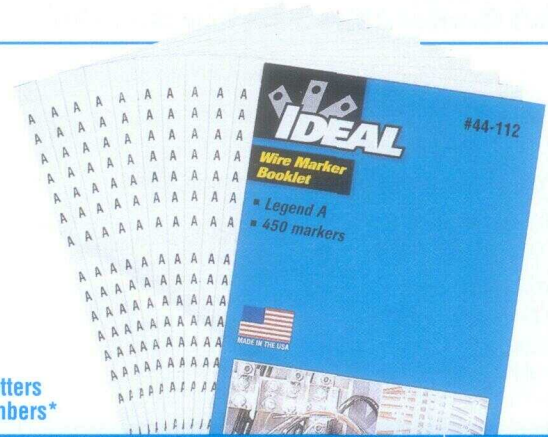

### Solid Letters and Numbers\*

Legend	Cat. No.
A	44-112
B	44-113
C	44-114
D	44-115
E	44-116
F	44-117
G	44-118
H	44-119
I	44-120
J	44-121
K	44-122
L	44-123
M	44-124
N	44-125
O	44-126
P	44-127
Q	44-128
R	44-129
S	44-130
T	44-131
U	44-132
V	44-133
W	44-134
X	44-135
Y	44-136
Z	44-137
0	44-138
1	44-139
2	44-140
3	44-141
4	44-142
5	44-143
6	44-144
7	44-145
8	44-146
9	44-147

\*Ten pages per booklet with each page bearing the legend assortment indicated. All booklets contain 450 wire markers and 450 terminal markers.