

Split-Jaw™ Smart Meter

Features



- Measures 0.1-200AAC*
- Measures 1.3-750VAC
- Measures 0.1-1000VDC
- Measures 0.1-2000Ω
- Audible continuity
- Data hold
- Integral lead storage
- Replaceable test leads
- Auto power off
- Low battery indication
- 2-year warranty

Electrical Tester

61-096
Split-Jaw™




**EASY
NO DIAL
TO USE**



AC/DC Volts



AC Amps

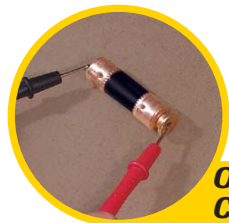

Ohms/
Continuity

AUTOMATICALLY SENSES & DISPLAYS

Accessories

Optional	
Carrying Case	C-90

Specifications	61-096	
AC VOLTAGE	1.3 - 750 V	1.5%
DC VOLTAGE	1.8 - 1000 V -0.6 - 1000 V	1.0%
AC CURRENT	0.6 - 200.0 A	3.0%
RESISTANCE	0 - 2000 Ω	1.0%

*Note: Jaw opening is 0.6 in. (16mm) - up to 1/0 copper cable

