


Standard and Heavy-Duty Toggle Switches

- Great for power tool and motor control switch applications
- Rugged long-wearing solid brass/nickel-plated bushings
- 1/2 in. diameter mounting hole
- Dielectric Strength: 1500V
- Mechanical Life: 100,000 cycles
- Operating Temperature: 32°F to 185°F (0°C to 85°C)
- DC Rating: Factory tested 100,000 cycles to 21 Amp 14.8 VDC
- Bulk packaging of 100 available upon request

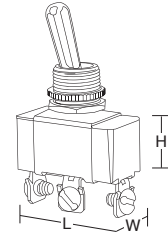

Toggle Switches

Product	Description	Poles	Circuitry	Termination Style	No. of Terminals	Rating			Dimensions (L" x W" x H")	Cat. No.
						Amps 125 VAC	Amps 277 VAC	HP 125-250 VAC		
	Toggle Switch with On-Off Faceplate	SPST	On-Off	Screw	2	20	10	3/4	1.13 x .57 x .61	774011 774011BK†
	Toggle Switch with On-Off Faceplate	SPST	On-Off	Spade	2	20	10	3/4	1.13 x .57 x .61	774008 774008BK†
	Toggle Switch	SPST	On-Off	"O" Ring & Screw	2	20	10	3/4	1.13 x .57 x .61	774010
	Toggle Switch	SPST	(On)-Off	Screw	2	20	10	3/4	1.13 x .57 x .61	774093
	Toggle Switch	SPST	On-(Off)	Screw	2	20	10	3/4	1.13 x .57 x .61	774088 774088BK†
	Toggle Switch w/boot	SPST	On-Off	Wire leads w/boot	2	20	20	1-1/2	1.18 x .68 x .75	774111 774111BK†
	Toggle Switch	SPDT	On-On	Screw	3	20	10	3/4	1.13 x .57 x .61	774012
	Toggle Switch	SPDT	On-On	Spade	3	20	10	3/4	1.13 x .57 x .61	774100
	Toggle Switch	SPDT	On-Off-On	Screw	3	20	10	3/4	1.13 x .57 x .61	774013
	Toggle Switch	SPDT	On-Off-On	Spade	3	20	10	3/4	1.13 x .57 x .61	774027
	Toggle Switch	SPDT	On-Off-(On)	Screw	3	20	10	3/4	1.13 x .57 x .61	774094
	Toggle Switch	SPDT	(On)-Off-(On)	Screw	3	20	10	3/4	1.13 x .57 x .61	774009
	Heavy-Duty Toggle Switch	DPST	On-Off	Screw	4	20	10	1-1/2	1.30 x .76 x .80	774014 774014BK†
	Heavy-Duty Toggle Switch	DPST	On-Off	Spade	4	20	10	1-1/2	1.30 x .76 x .80	774005 774005BK†
	Heavy-Duty Toggle Switch	DPST	(On)-Off	Screw	4	20	10	1-1/2	1.30 x .76 x .80	774103
	Heavy-Duty Toggle Switch	DPST	On-(Off)	Screw	4	20	10	1-1/2	1.30 x .76 x .80	774105

() denotes momentary action

†Bulk Package of 100