


## RJ-45 Modular Strain Relief Boots

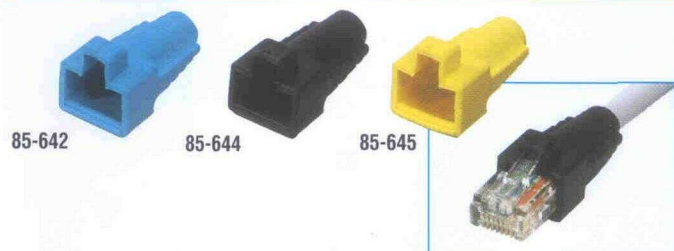

85-642      85-644      85-645

Provide strain relief for terminated RJ-45 plugs. Color coded for easy identification. Sanoprene material; UV and chemical-resistant to prevent cracking and splitting.

| Description | Qty. | Cat. No.      |
|-------------|------|---------------|
| Blue        | 10   | <b>85-642</b> |
| Black       | 10   | <b>85-644</b> |
| Yellow      | 10   | <b>85-645</b> |

## Patch Cables

**NEW**




85-731

350 MHz UTP Patch Cables provide quick and easy interconnection for system additions, moves or changes.

- Slim, contoured boots provide strain relief and save space on over-crowded patch panels
- Snagless modular connectors
- Terminated to 568B wiring and color code configurations, with 24 AWG stranded copper conductors
- Five colors and six lengths for installation versatility

| Description   | Gray Cat. No. | Blue Cat. No. | Black Cat. No. | Yellow Cat. No. | Red Cat. No.  |
|---------------|---------------|---------------|----------------|-----------------|---------------|
| 3 ft. (1m)    | <b>85-731</b> | <b>85-737</b> | <b>85-743</b>  | <b>85-749</b>   | <b>85-755</b> |
| 5 ft. (1.5m)  | <b>85-732</b> | <b>85-738</b> | <b>85-744</b>  | <b>85-750</b>   | <b>85-756</b> |
| 7 ft. (2.1m)  | <b>85-733</b> | <b>85-739</b> | <b>85-745</b>  | <b>85-751</b>   | <b>85-757</b> |
| 10 ft. (3m)   | <b>85-734</b> | <b>85-740</b> | <b>85-746</b>  | <b>85-752</b>   | <b>85-758</b> |
| 15 ft. (4.5m) | <b>85-735</b> | <b>85-741</b> | <b>85-747</b>  | <b>85-753</b>   | <b>85-759</b> |
| 25 ft. (7.6m) | <b>85-736</b> | <b>85-742</b> | <b>85-748</b>  | <b>85-754</b>   | <b>85-760</b> |

## TelCom Modular Plugs

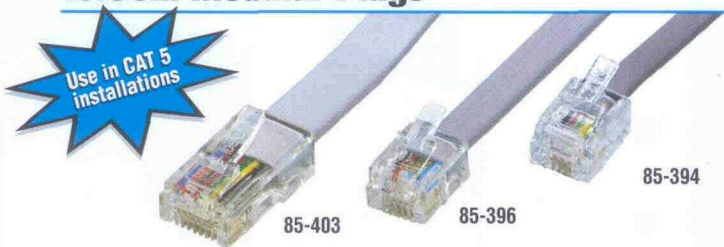

All plugs are manufactured to comply with FCC 68 guidelines and are UL Listed. IDEAL modular plugs are capable of supporting the latest EIA/TIA cable system performance categories when installed in compliance with appropriate EIA/TIA standards and methods. The position and contact configurations cover the popular styles. Includes plugs for round cable with solid conductors and plugs for flat cable and stranded conductors.

| Description                                  | Qty. | Cat. No.      |
|--|------|---------------|
| 6-Position 4-Contact Flat Stranded           | 25   | <b>85-351</b> |
|  | 50   | <b>85-401</b> |
|  | 100  | <b>86-401</b> |
| 6-Position 6-Contact Flat Stranded           | 25   | <b>85-352</b> |
|  | 50   | <b>85-402</b> |
|  | 100  | <b>86-402</b> |
| 6-Position 6-Contact DEC Flat Stranded       | 25   | <b>85-349</b> |
|  | 50   | <b>85-399</b> |
|  | 100  | <b>86-399</b> |
| 4-Position 4-Contact Flat Stranded (Handset) | 25   | <b>85-348</b> |
|  | 50   | <b>85-398</b> |
|  | 100  | <b>86-398</b> |
| 8-Position 8-Contact Flat Stranded           | 25   | <b>85-353</b> |
|  | 50   | <b>85-403</b> |
|  | 100  | <b>86-403</b> |
| 8-Position 8-Contact Keyed Flat Stranded     | 25   | <b>85-347</b> |
|  | 50   | <b>85-397</b> |
|  | 100  | <b>86-397</b> |
| 6-Position 4-Contact Round Solid             | 25   | <b>85-344</b> |
|  | 50   | <b>85-394</b> |
|  | 100  | <b>86-394</b> |
| 6-Position 6-Contact Round Solid             | 25   | <b>85-345</b> |
|  | 50   | <b>85-395</b> |
|  | 100  | <b>86-395</b> |
| 6-Position 6-Contact DEC Round Solid         | 25   | <b>85-343</b> |
|  | 50   | <b>85-393</b> |
|  | 100  | <b>86-393</b> |
| 4-Position 4-Contact Round Solid (Handset)   | 25   | <b>85-342</b> |
|  | 50   | <b>85-392</b> |
|  | 100  | <b>86-392</b> |
| 8-Position 8-Contact Round Solid             | 25   | <b>85-346</b> |
|  | 50   | <b>85-396</b> |
|  | 100  | <b>86-396</b> |
| 8-Position 8-Contact Keyed Round Solid       | 25   | <b>85-341</b> |
|  | 50   | <b>85-391</b> |
|  | 100  | <b>86-391</b> |