



BU2 SERIES

The economical choice

Air quality is a top concern for today's families, and the Broan series is the ideal solution. Designed with simplicity in mind, the BU2 range hood models are made to exacting standards and offer the most for the money.

- 2-speed blower, HVI* certified
- One standard efficiency aluminum filter, easy to clean
- 75 W bulb (not included) and direct lighting
- Available in convenient 24" and 30" width
- Contemporary styling in stainless steel, white and black
- Four-way convertible range hood: horizontal, vertical, round and non-ducted
- Use charcoal filter 41F for a non-ducted installation

SPECIFICATIONS

WIDTH	MODEL	COLOR	VOLTS	AMPS	CFM	SONES	DUCTING
24"	BU224SS	STAINLESS STEEL	120	2.5	160	6.5	3 1/4" X 10" (H-V) 7" ROUND
24"	BU224WH	WHITE WITH BLACK TRIM	120	2.5	160	6.5	3 1/4" X 10" (H-V) 7" ROUND
30"	BU230SS	STAINLESS STEEL	120	2.5	160	6.5	3 1/4" X 10" (H-V) 7" ROUND
30"	BU230WW	WHITE	120	2.5	160	6.5	3 1/4" X 10" (H-V) 7" ROUND
30"	BU230WH	WHITE WITH BLACK TRIM	120	2.5	160	6.5	3 1/4" X 10" (H-V) 7" ROUND
30"	BU230BL	BLACK	120	2.5	160	6.5	3 1/4" X 10" (H-V) 7" ROUND

OPTIONS

BP29	ALUMINUM REPLACEMENT FILTER
41F	CHARCOAL REPLACEMENT FILTER

1 2


2-SPEED ROCKER CONTROL



1-LEVEL LIGHTING
(BULB NOT INCLUDED)



ONE STANDARD
EFFICIENCY FILTER

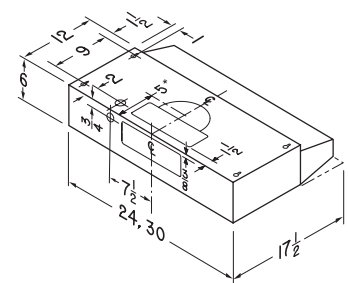

www.broan.ca

1-877-896-1119

Specifications subject to change without notice.



*THE HVI (HOME VENTILATING INSTITUTE) CERTIFIES THE PERFORMANCE OF NORTH AMERICAN HOME VENTILATING PRODUCTS. IF A RANGE HOOD IS NOT HVI CERTIFIED, THERE ARE NO GUARANTEES REGARDING ITS PERFORMANCE.