
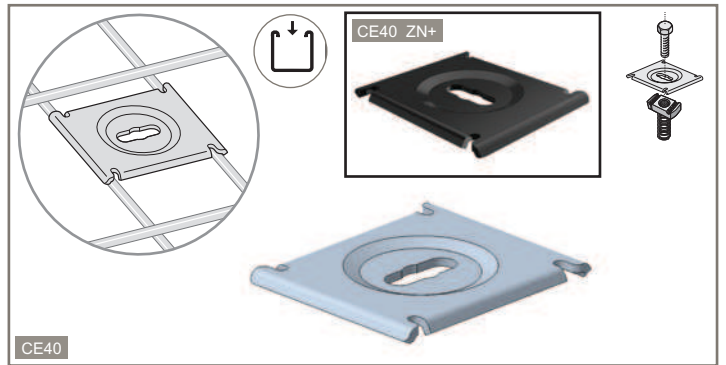


# channel fixings – FASTRUT 41 / CE40 fixing components – CE25/CE30

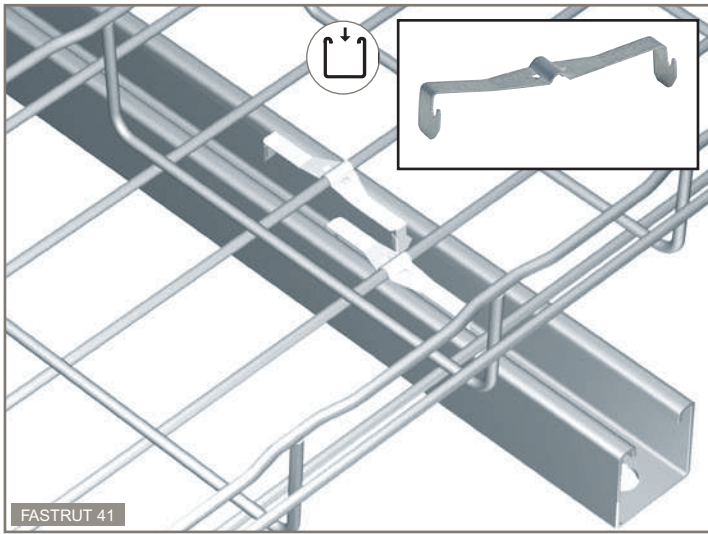

Dimensions and technical information p. 66, 83

**NOTE : please use Cat. No. when placing your order**

Pack	Cat. Nos.	<b>FASTRUT 41 – channel fixing clip</b>
50	<b>DC</b> CM599007	$\updownarrow$ 30 → 150mm $\curvearrowright$ 100 → 600 mm Use to secure steel wire cable tray to channel section or channel type cantilever arms For technical information, see p. 66 

Pack	Cat. Nos.	<b>CE25 / CE30 – fixing components</b>
100	<b>EZ</b>   <b>DC</b> CM801011   CM801017	BTRCC 6 x 20
50	CM558011   CM558013	CE25
50	CM558041   CM558043	CE30

$\updownarrow$  30 → 150 mm  $\curvearrowright$  50 → 600 mm

Pack	Cat. Nos.	<b>CE40 – hold down clamps</b>
25	<b>EZ</b>   <b>DC</b> CM558051   CM558053	$\updownarrow$ 30 → 150mm $\curvearrowright$ 100 → 600 mm For technical information, see p. 83 $\downarrow$ daN 100 
25	<b>304L</b>   <b>316L</b> CM558058   CM558054	
25	<b>ZN+</b> CM350839	

**ZN+ colour : black**

Pack	Cat. Nos.	<b>CE25 / CE30 stainless steel – fixing components</b>
100	<b>304L</b>   <b>316L</b> CM801018   CM801014	BTRCC 6 x 20
50	CM558018   CM558014	CE25
50	CM558048   CM558044	CE30

$\updownarrow$  30 → 150 mm  $\curvearrowright$  50 → 600 mm

<b>Key:</b> <b>EZ</b>	Electrogalvanised after manufacture	<b>DC</b>	Zinc rich coating
<b>ZN+</b>	Zinc nickel plus additional coating (black)	<b>304L</b>	Stainless steel 304 L
		<b>316L</b>	Stainless steel 316 L

For detailed information related to finishes, refer to p. 132-133

All dimensions (mm) are nominal