


Model 668RP

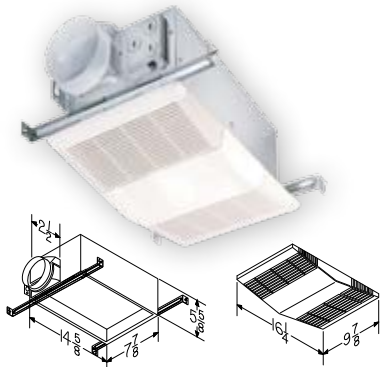

- White polymeric grille
- Rectangular fan light
- Fits in 2" x 6" ceiling construction
- 24" adjustable hanger bars
- Mounting brackets that adjust for ceiling thickness up to 3/4"


Models 8663RP & 8664RP



- Round design eliminates squaring with bathroom walls
- Fits 2" x 6" ceiling construction
- 8663RP features bright 100W incandescent lighting with 7W night light for security and safety (bulbs not included)
- 8664RP features bright 100W incandescent lighting (bulb not included)
- 24" adjustable hanger bars


Model	CFM	Sones	Lighting	Finish
668RP	70	4.0	100W	White
8663RP	100	3.5	100/7W	White
8664RP	100	3.5	100W	White

Models 769RL, 763RLN, and 769RFT

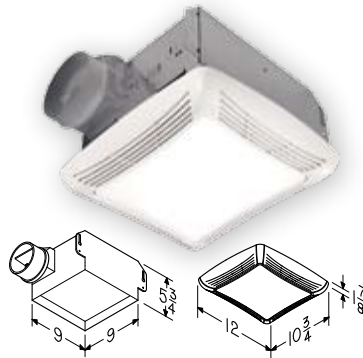


- White polymeric grille
- Fits in 2" x 6" ceiling construction
- 769RFT uses 13W fluorescent bulb (not included)
- All models available in Project Packs

Model 671R & 672R

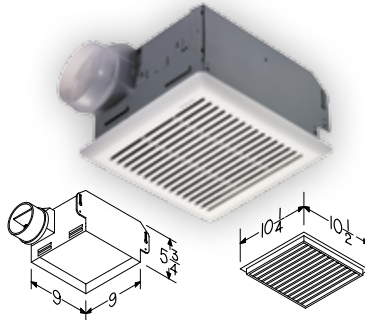

Model 695 & 696N

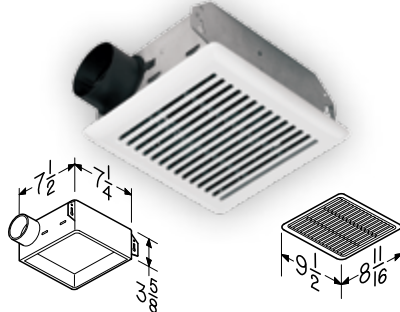


- 50 to 110 CFM centrifugal blower wheel
- Double-strength steel mounting flanges with keyhole slots for fast installation
- Metal grille kits for 695 & 696N S97011308
- UL Listed for use over tub or shower when installed in a GFCI protected branch circuit
- *All models available in Project Packs

Model	CFM	Sones	Notes
769RL	70	3.0	100W White
763RLN	50	2.5	100W White
769RFT	70	3.0	13W fluor. White
671R	90	3.0	Wall/Ceiling mount
672R	110	4.0	Wall/Ceiling mount
695	70	6.0	Wall/Ceiling mount
696N	50	4.0	Wall/Ceiling mount

Available in single packs or project packs.

Model 8814R

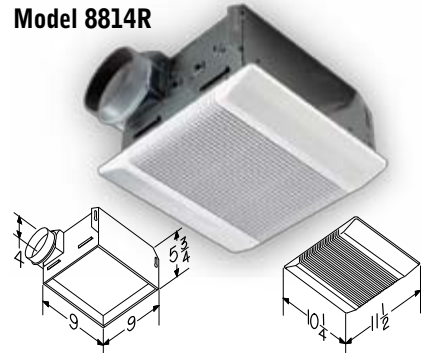


- 80 to 110 CFM
- Centrifugal blower wheel and 4-pole motor deliver high exhaust capacity at low sound levels
- Mounting flanges with keyhole slots for fast installation
- White polymeric grille with torsion spring mounting

Model 8832WH



- White polymeric grille with torsion spring mounting
- Fits 2"x4" construction

Model 8832SA

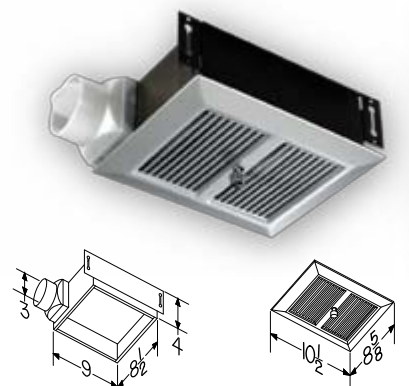

- Silver anodized aluminum grille
- Fits 2"x4" construction

Model	CFM	Sones	Notes
8814R	110	4.0	
8832WH	80	2.5	Not UL tub & shower
8832SA	80	2.5	Not UL tub & shower

Ventilation Fans—Wall Control Selection Guide

		57W, 57V	P59W	61W, 61V	66W, 66V, P66W	68W, 68V	69WL 69VL	70TW	72W, 72V	77DW, 77DV	78W, 78V	DH100W	VS63WH	VS66WH	VS67WH	VS68WH	VS69WH
Ventilation Fans	50NT, 80NT	•	•	•			•	•	•			•					
	671R, 672R		•					•				•	•				
	682NT		•					•					•				
	695, 696N	•	•					•	•			•	•				
	8814R, 8832SA, 8832WH		•					•				•	•				
	HD50NT, HD80NT	•	•	•			•	•	•			•					
	LPN80	•		•			•	•	•								
	QT Fans*	•	•				•	•	•		•		•	•			
	QTRN050						•				•						
	QTXEN110S						•				•						
	XN110H					•	•										
	XN50, XN80, XN110						•										
	ZN110H						•										
	ZN80, ZN110						•										
	ZN80M, ZN110M						•	•									
Ventilation Fan/Lights	668RP	•	•			•		•	•			•	•	•		•	
	742RBNT	•	•			•		•	•			•		•		•	
	744NT, 744FLNT		•			•		•				•		•		•	
	744SFLNT		•			•						•		•		•	
	763RLN, 769RFT, 769RL		•			•		•				•		•		•	
	778WHNT	•		•			•	•	•								
	8663RP	•			•			•	•			•			•		•
	8664RP	•	•			•		•	•			•		•		•	
	HD50LNT, HD80LNT	•				•		•	•	•		•	•				
	QT Fan/Lights	•			•			•	•			•			•		•
	QTNLEDA, QTNLEDB	•			•			•	•			•			•		•
	QTXEN110SFLT, QTXN110SL		•							•							
	XN110HL				•					•							
	XN50L, XN80L, XN110L				•												
	ZN110HL				•												
	ZN80L, ZN110L									•							
	ZN80ML, ZN110ML									•							
Heater/ Fan/Lights	605RP	•	•					•	•				•	•		•	
	665RP		•					•					•		•		•
	765HL, 765HFL	•	•	•	•			•	•			•					
	9412D												•				
	9417DN		•			•		•					•	•		•	
	9422P		•		•	•							•	•		•	
	9427P		•		•			•					•	•	•	•	•
	9905	•	•					•	•				•	•		•	
	9960												•		•		•
	9965							•		•							
	QT9093WH, 9093WH							•		•							
	QTXN110HL, QTXN110HFL	•	•	•	•			•	•	•			•	•			
Utility Fans	8210, 8310, QT200	•	•					•	•			•	•				
	QT300		•					•	•			•	•				

*Does not include models QT200 and QT300.

Ventilation Fans—Product Specifications

Fans

	Page	CFM	Sones HVI certified	Baths up to () Sq Ft	ENERGY STAR*	Duct Size"	Housing Dimensions			Grille Dimensions			Grille finish	Amps
							L"	W"	H"	L"	W"	H"		
110RDB*	28	110	4	105	No	4	8	8 3/4	5 3/4	10 1/2	10 3/4	White Acrylic Metal	0.6	
50NT	26	50	1.5	45	Yes	4	8 3/4	8	5 3/4	10 1/2	10 3/4	White Polymeric	0.2	
671R	27	90	3	85	No	4	9	8 1/2	5 3/4	10 1/2	10 3/4	White Polymeric	0.5	
672R	27	110	4	105	No	4	9	9	5 3/4	10 1/2	10 3/4	White Polymeric	0.7	
682NT	29	—	—	—	No	—	7 1/2	7 1/2	3 3/4	8 1/2	8 1/2	White Polymeric	1	
690NT	29	60	3	55	No	3	See page 28 for compatible models			9 1/2	8 1/2	White Polymeric	1.2	
695	27	70	6	65	No	3	7 1/2	7 1/4	3 3/8	9 1/2	8 1/2	White Polymeric	1.2	
696N	27	50	4	45	No	3	7 1/2	7 1/4	3 3/8	9 1/2	8 1/2	White Polymeric	0.75	
80NT	26	80	2	75	Yes	4	8 3/4	8	5 3/4	10 1/2	10 3/4	White Polymeric	0.3	
80RDB*	28	80	2.5	75	No	4	8	8 3/4	5 3/4	10 3/4	10 3/4	White Acrylic Metal	0.6	
8814R	27	110	4	105	No	4	9	9	5 3/4	11 1/2	10 3/4	White Polymeric	0.85	
8832SA	27	80	2.5	75	No	3	8 1/2	9	4	10 1/2	8 3/4	Silver Anod. Alum	0.75	
8832WH	27	80	2.5	75	No	3	8 1/2	—	—	10 3/4	9 3/8	White Polymeric	0.7	
HD50NT	28	50	1.5	45	Yes	4	8	8 3/4	5 3/4	10 3/4	10 3/4	White Acrylic Metal	0.4	
HD50RDB*	28	50	1.5	45	Yes	4	8	8 3/4	5 3/4	10 3/4	10 3/4	White Acrylic Metal	0.4	
HD80NT	28	80	2.5	75	No	4	8	8 3/4	5 3/4	10 3/4	10 3/4	White Acrylic Metal	0.6	
HD80RDB*	28	80	2.5	75	No	4	8	8 3/4	5 3/4	10 3/4	10 3/4	White Acrylic Metal	0.6	
LPN80	26	80	1.1	75	Yes	3-Apr	8	8 3/4	5 3/4	13	14	White Polymeric	0.3	
QTREN080	20	80	0.8	75	Yes	4	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.7	
QTREN110	20	110	1.3	105	Yes	4	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.9	
QTRN050	20	50	0.4	45	No	4	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.4	
QTRN080	20	80	1	75	No	4	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.4	
QTRN110	20	110	1.5	105	No	4	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.3	
QTXEN050	20	50	<0.3	45	Yes	6	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.3	
QTXEN080	20	80	0.3	75	Yes	6	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.4	
QTXEN110	20	110	0.7	105	Yes	6	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.3	
QTXEN110S	22	110	0.7	100	Yes	6	11 3/4	10 1/2	7 3/8	12 3/8	13 3/8	White Polymeric	0.3	
QTXEN150	20	150	1.4	140	Yes	6	11 3/8	10 1/2	7 3/8	13	14	White Polymeric	0.5	
XN50	17	50	<0.3	45	Yes	4-Jun	10 1/2	11 3/8	7 3/8	13	14	White Polymeric	0.1	
XN80	17	80	<0.3	75	Yes	4-Jun	10 1/2	11 3/8	7 3/8	13	14	White Polymeric	0.1	
XN110	17	110	<0.3	100	Yes	6	10 1/2	11 3/8	7 3/8	13	14	White Polymeric	0.2	
XN110H	17	110	<0.3	100	Yes	6	10 1/2	11 3/8	7 3/8	13 3/8	14	White Polymeric	0.3	
ZN80	17	80	<0.3	75	Yes	4-Jun	10 1/2	11 3/8	7 3/8	13	14	White Polymeric	0.1	
ZN80M	17	80	<0.3	75	Yes	4-Jun	10 1/2	11 3/8	7 3/8	13 3/8	14	White Polymeric	0.1	
ZN110	17	110	<0.3	100	Yes	6	10 1/2	11 3/8	7 3/8	13	14	White Polymeric	0.2	
ZN110H	17	110	<0.3	100	Yes	6	10 1/2	11 3/8	7 3/8	13 3/8	14	White Polymeric	0.3	
ZN110M	17	110	<0.3	100	Yes	6	10 1/2	11 3/8	7 3/8	13 3/8	14	White Polymeric	0.3	

*Model RDA fan housing only sold separately for radiation dampers/fans.

Fan/Lights

	Page	CFM	Sones HVI certified	Baths up to () Sq Ft	Rooms up to () Sq Ft	Lighting Watts Main/Night Light	ENERGY STAR*	Duct Size"	Housing Dimensions			Grille Dimensions			Grille finish	Amps
									L"	W"	H"	L"	W"	D"		
668RP	27	70	4.0	65	85	100W	No	4	14 3/4	7 3/8	5 3/8	16 1/4	9 3/8	—	White Polymeric	2.0
742RBNT	34	70	3.5	65	85	2-60W	No	4	8 3/4	8	5 3/4	13 3/8 Dia	5 3/8	—	Oil-rubbed Bronze	2.2
744NT	32	70	1.5	65	85	75W	No	4	8 3/4	12 3/4	6 3/4	7 3/8 Dia	—	—	White Polymeric	1.2
744FLNT	32	70	1.5	65	85	14W fluor.	Yes	4	8 3/4	12 3/4	6 3/4	7 3/8 Dia	—	—	White Polymeric	1.2
744SFLNT	32	70	1.5	65	85	14W fluor.	Yes	4	8 3/4	12 3/4	6 3/4	7 3/8 Dia	—	—	Matte White	0.7
763RLN	27	50	2.5	45	60	100W	No	4	9	9	5 3/4	12 3/4	10 3/4	—	White Polymeric	1.2
769RFT	27	70	3.0	65	85	13W fluor.	No	4	9	9	5 3/4	12 3/4	10 3/4	—	White Polymeric	1.2
769RL	27	70	3.0	65	85	100W	No	4	9	9	5 3/4	12 3/4	10 3/4	—	White Polymeric	2.0
772RBNT	34	80	2.0	65	85	2-13W	Yes	4	8 3/4	8	5 3/4	13 3/8	6 3/8	—	Oil-Rubbed Bronze	0.8
773BNNT	34	80	2.5	75	75	2-13W	Yes	4	8 3/4	8	5 3/4	13 3/8	5 1/2	—	Brushed Nickel	0.8
778WHNT	26	80	2.0	75	85	2-13W GU24	Yes	4	8 3/4	8	5 3/4	13 3/8 Dia	—	—	White	0.5
8663RP	27	100	3.5	95	125	100W/7W	No	4	9	9	5 3/4	15 Dia	—	—	White Polymeric	1.7
8664RP	27	100	3.5	95	125	100W	No	4	9	9	5 3/4	15 Dia	—	—	White Polymeric	1.7
XN50L	17	50	<0.3	45	—	2-18W GU24/4W	Yes	6 / 4	10 1/2	11 3/8	7 3/8	13	13 3/4	—	White Polymeric	0.7
XN80L	17	80	<0.3	75	—	2-18W GU24/4W	Yes	6 / 4	10 1/2	11 3/8	7 3/8	13	13 3/4	—	White Polymeric	0.7
XN110L	17	110	<0.3	100	—	2-18W GU24/4W	Yes	6	10 1/2	11 3/8	7 3/8	13	13 3/4	—	White Polymeric	0.9
XN110HL	17	110	<0.3	100	—	2-18W GU24/4W	Yes	6	10 1/2	11 3/8	7 3/8	13 3/8	14	—	White Polymeric	1.0
ZN80L	17	80	<0.3	75	—	2-18W GU24/4W	Yes	6 / 4	10 1/2	11 3/8	7 3/8	13	13 3/4	—	White Polymeric	0.8
ZN80ML	17	80	<0.3	75	—	2-18W GU24/4W	Yes	6 / 4	10 1/2	11 3/8	7 3/8	13 3/8	14	—	White Polymeric	0.9
ZN110L	17	110	<0.3	100	—	2-18W GU24/4W	Yes	6	10 1/2	11 3/8	7 3/8	13	13 3/4	—	White Polymeric	0.9
ZN110HL	17	110	<0.3	100	—	2-18W GU24/4W	Yes	6	10 1/2	11 3/8	7 3/8	13 3/8	14	—	White Polymeric	1.0
ZN110ML	17	110	<0.3	100	—	2-18W GU24/4W	Yes	6	10 1/2	11 3/8	7 3/8	13 3/8	14	—	White Polymeric	1.0