



IM, IMA, IC, IS and ISA Series Recess Mounting Rough-in Frames

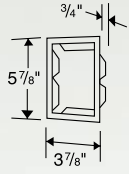


IR3

- Metal housing for ISB53 speaker
- Cutout: 3-7/8" w x 5-7/8" h

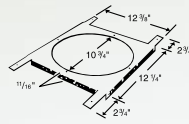


IR70

- Metal housing for IS76 round speaker
- Cutout: 10-3/4" dia.

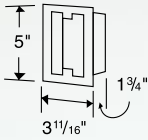


IR6*

 - Metal housing for IS67, IS69 and IS70 series door speakers
- Cutout: 3-11/16" w x 5" h




IR80

- Metal housing for ISA78, ISA338, ISA448, IS518WH series speakers
- Cutout: 8-5/8" w x 10-1/4" h

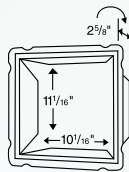


IR9

 - Metal housing for IS79 speaker
- Cutout: 10-1/16" w x 11-1/16" h




IR91

 - Metal housing for ICA331WH, ICA441WH, IC502WH and IC502LW remote controls
- Cutout: 6-1/8" w x 3-1/4" h




IR50

- Metal housing for ISA319, ISA335, ISA419, ISA445, IS515 and IS519 series speakers
- Cutout: 5-3/8" w x 7-3/16" h

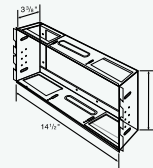


IR104

- Metal housing for IMA3303 Voice Music Intercom
- Cutout: 14-1/2" w x 7" h
- Includes AM/FM antenna and two 301T transformers

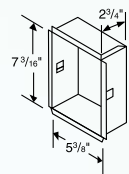

IR55

- Metal housing for ISA319, ISA419 and IS519 series speakers
- Cutout: 5-3/8" w x 7-3/16" h

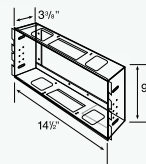

IR105

- Metal housing for IMA4406 Voice Music Intercom
- Cutout: 14-1/2" w x 9" h
- Includes AM/FM antenna and two 801T transformers

Rough-Ins for: IM5000, IMA4406, IMA3303 and IMA516 Systems

Rough-Ins	IR3	IR6	IR9	IR50	IR55	IR70	IR80	IR91	IR104	IR105
IM5000 System		•	•	•	•	•	•	•		
IMA4406 System		•	•	•	•	•	•	•		•
IMA3303 System		•	•	•	•	•	•	•	•	
IMA516 System	•	•	•			•	•			