





## RZR-LED-400

### 4.00" ULTRA THIN LED RAZOR SERIES - 9W

#### Product codes

- RZR-400-9W-3K-WH : WHITE - 3K
- RZR-400-9W-3K-SC : SATIN CHROME - 3K
- RZR-400-9W-4K-WH : WHITE - 4K
- RZR-400-9W-4K-SC : SATIN CHROME - 4K
- RZR-400-9W-3K-BLK : BLACK - 3K
- RZR-400-9W-4K-BLK : BLACK - 4K

This ultra-thin recessed unit is IC and AIR TIGHT rated and with its thin profile allows installation in almost any location. It is suitable for wet locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 9W fixtures that can be installed with a standard 150W LED dimmer is 16 units. The 3K & 4K models replace a 600 lumen 50W halogen style bulb. This product is ETL certified, conforms to UL standard 1598 and CSA standard C22.2 NO. 250.0. A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Although this product is AIR-TIGHT rated, some municipalities will require the use of a vapor barrier. Verify local building codes prior to installation.

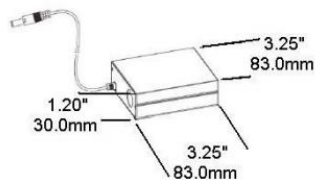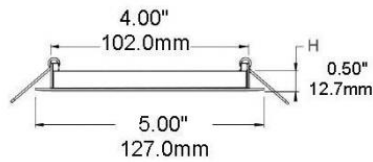

#### Technical information

Cutting hole	4.25" (108.0 mm)
Beam Spread	107°
Color Temperature	3000k / 4000k
Certification	ETL
Certification	Energy Star
CRI	>80
Diameter	5" (127.0 mm)
Dimmable	Y
LED Life	50000 hrs
Light Output - Lumen	650LM
Operating Temperature	-40°c + 40°c
Voltage	120V
Warranty (Years)	5
Watt	9W