



WHITE

BLACK

SATIN  
CHROME

## RZR-LED-600

### 6.00" ULTRA THIN LED RAZOR SERIES - 12W

#### Product codes

RZR-600-12W-27K-WH : WHITE - 27K

RZR-600-12W-3K-WH : WHITE - 3K

RZR-600-12W-3K-BLK : BLACK - 3K

RZR-600-12W-3K-SC : SATIN CHROME - 3K


 
RZR-600-12W-4K-WH : WHITE - 4K

RZR-600-12W-4K-BLK : BLACK - 4K

RZR-600-12W-4K-SC : SATIN CHROME - 4K

This ultra-thin recessed unit is IC and AIR TIGHT rated and with its thin profile allows installation in almost any location. It is suitable for wet locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 12W fixtures that can be installed with a standard 150W LED dimmer is 12 units. The 27K, 3K & 4K model replaces a 800 lumen 65W halogen style bulb. This product is CSA certified in Canada and the US, conforms to UL standard 1598 and CSA standard C22.2 NO. 250.0. A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site.

Although this product is AIR-TIGHT rated, some municipalities will require the use of a vapor barrier. Verify local building codes prior to installation.

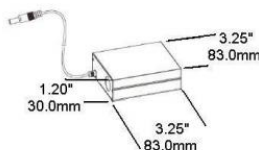

\*\*Height including clip

\*\*Hauteur avec pince  
1.13"  
29mm

#### Données techniques

Cutting hole	6.33" (160.8 mm)
Beam Angle	107° ± 1/2
Color Temperature	27K / 3K / 4K
CRI	>80
Mounting Plate	AMP/MPHB 600
Dimmable	Y
LED Life	50,000hrs
Light Output - Lumen	950LM(3K/4K) 850LM(2.7K)
Operating Temperature	-20°C + 40°C
Voltage	120V
Warranty (Years)	5
Watt	12W