




WHITE

WHITE

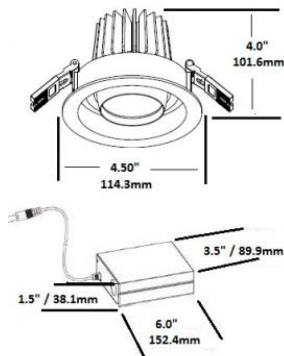

EG-LED-400

4" HIGH PERFORMANCE EDGE SERIES - 12W

Product codes

- EG400-12W-3K-38WH : WHITE - 3K
- EG400-12W-3K-38BK : BLACK - 3K
- EG400-12W-3K-38SV : SILVER - 3K
- EG400-12W-4K-38WH : WHITE - 4K
- EG400-12W-4K-38BK : BLACK - 4K
- EG400-12W-4K-38SV : SILVER - 4K

Integrated COB (chip on board) technology offers low-energy, long lasting performance with outstanding light outputs of 1000 LUMENS.

Includes a standard 38 degree reflector and optic lens set in a convenient pivoting gimbal for optimal light adjustment. A custom 24 degree reflector and solite lens are optionally available.

The body is constructed of die cast aluminum, with junction box manufactured in aluminum extrusion. For easy and quick installation the unit comes with pressure-fit spring clips and quick connect wire connectors. Dimmable driver included.

Well suited for commercial and residential applications, as well rated for damp locations. For an IC application, the use of an isolated box is recommended (NDR #IB400-EG)

Technical information

Cutting hole	3.90" (99.1 mm)
Beam Spread	38°
Color Temperature	3000K / 4000K
CRI	>80
Dimmable	Y
Bulb Life	50000 hrs
Light Output - Lumen	1000
Operating Temperature	-40c + 40c
Voltage	120V
Watt	12W
Warranty (Years)	5

