

**UNL50-L35-40****40" LED - LUCIA SERIES - HARDWIRE****APPLICATION****Product codes**

UNL50-L35-40WH : WHITE

UNL50-L35-40BLK : BLACK

Aluminum construction - Hardwire Application Only

This unit includes a HIGH/LOW/ON-OFF switch, multiple knockout locations for easy and quick installation, as well as diffused frosted glass, which allows for even light distribution. Ideal for use under cabinets, closets and work stations.

LED (Light emitting Diode) offers lower energy consumption and longer life (40,000 hrs) over incandescent and fluorescent lighting.

Color temperature: 3500 Kelvin.  
Non-Dimmable, Maximum of 100 WATTS in sequence

**INCLUDED:**

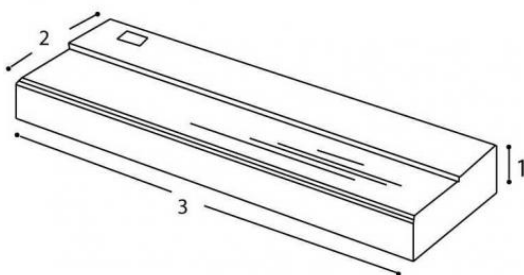
Aluminum construction

Integrated Driver

Easily accessible HIGH/LOW/ON/OFF switch

Installation hardware

Multiple Knockout Locations

**Technical information**

CRI	80
Color Temperature	3500K
Voltage	120V
Watt	14W
Height (1)	1.25" (31.8 mm)
Width (2)	3.5" (88.9 mm)
Length (3)	40" (1,016.0 mm)
Light Output - Lumen	403 - 1344
Warranty (Years)	3

