



**UNL50-L35-8**

**8" LED - LUCIA SERIES - HARDWIRE**

**APPLICATION**

**Product codes**

UNL50-L35-8WH : WHITE

UNL50-L35-8BLK : BLACK

Aluminum construction - Hardwire Application Only


This unit includes a HIGH/LOW/ON-OFF switch, multiple knockout locations for easy and quick installation, as well as diffused frosted glass, which allows for even light distribution. Ideal for use under cabinets, closets and work stations.

LED (Light emitting Diode) offers lower energy consumption and longer life (40,000 hrs) over incandescent and fluorescent lighting.

Color temperature: 3500 Kelvin.  
 Non-Dimmable, Maximum of 100 WATTS in sequence

**INCLUDED:**

- Aluminum construction
- Integrated Driver
- Easily accessible HIGH/LOW/ON/OFF switch
- Installation hardware
- Multiple Knockout Locations

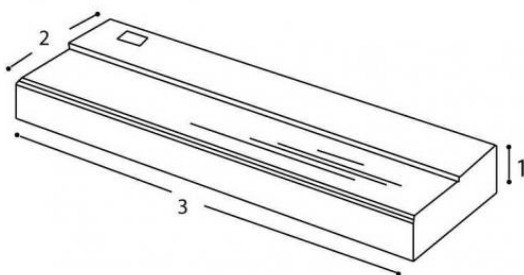

**Technical information**

CRI	80
Color Temperature	3500K
Voltage	120V
Watt	2W
Height (1)	1.25" (31.8 mm)
Width (2)	3.5" (88.9 mm)
Length (3)	8" (203.2 mm)
Light Output - Lumen	74 - 252
Warranty (Years)	3

