





## RZR-LED-420

### 4.00" LOW PROFILE GIMBAL LED RAZOR SERIES - 9W

#### Product codes

RZR-420-9W-3K-WH : WHITE - 3K  
 RZR-420-9W-3K-SC : SATIN CHROME - 3K  
 RZR-420-9W-4K-WH : WHITE - 4K  
 RZR-420-9W-4K-SC : SATIN CHROME - 4K  
 RZR-420-9W-3K-BLK : BLACK - 4K  
 RZR-420-9W-4K-BLK : BLACK - 4K

This low profile gimbal unit is IC and AIR TIGHT rated and with its low profile allows installation in almost any location. It is suitable for damp locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 9W fixtures that can be installed with a standard 150W LED dimmer is 16 units. The 3K & 4K models replace a 600 lumen 50W halogen style bulb. This product is CSA certified, conforms to UL standard 1598 and CSA standard C22.2 NO. 250.0. A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Although this product is AIR-TIGHT rated, some municipalities will require the use of a vapor barrier. Verify local building codes prior to installation.

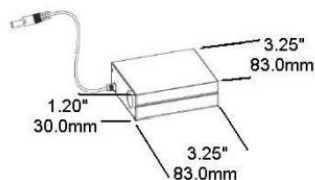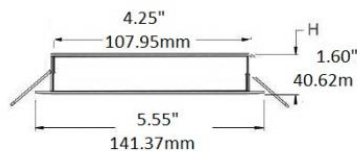

#### Technical information

Cutting hole	4.50" (114.3 mm)
Beam Spread	107°
Color Temperature	3000k / 4000k
CRI	>80
Dimmable	Y
Mounting Plate	MP/AMP/MPHB 450
LED Life	50,000hrs
Light Output - Lumen	600LM
Operating Temperature	-40°c + 40°c
Voltage	120V
Warranty (Years)	5
Watt	9W

