



wireless freedom

The AirGoTM Outdoor Sound System is a portable amplifier speaker dock for an Apple[®] AirPort Express[®]. With the AirGo outdoor you can stream music from an AirPlay[®] compatible device via the Apple AirPort Express.

hotspot flexibility

Since the Apple AirPort Express also has the ability to simultaneously act as a Wi-Fi repeater, the AirGo can also offer a Wi-Fi hotspot while listening to music at the same time, virtually anywhere.

great sound in the great outdoors

As a high performance, quality outdoor sound system, the single large stereo speaker provides excellent sound quality and a wide sound stage. Place it on the deck near the house to cover the deck and backyard while having a cookout. Put it on the driveway near the garage when washing the car. Place it on the ground near the front door during seasonal events to play music and sound effects of your choice to match the occasion!



fun to the next level

The AirGo Outdoor is easy and fun to use. With the Apple AirPort Express installed, stream music from your iPhone[®], iPad[®], Mac[®], iTunes[®] or PC (requires AirFoil or like program for AirPlay) and surf the net from your internet device at the same time. The bottom line is the AirGo Outdoor is fun, sounds great and brings outdoor recreation to the next level.

access your music anywhere, including outdoors!

- Stream music from any AirPlay compatible device via an Apple AirPort Express Patent Pending
- Hotspot flexibility
- Incredible sound in the great outdoors
- A single large stereo speaker provides excellent sound in a wide sound stage


AirPort Express sold separately.



AirGo Dimensions:

Height: 12.6" (32.1 cm)
Width: 12.9" (32.8 cm)
Length: 10.2" (25.9 cm)
Weight: 16.25 lbs (7.37 kg)

3120-533747 AGO-1 EU
3120-533754 AGO-1 UK
3120-533815 AGO-1 AU

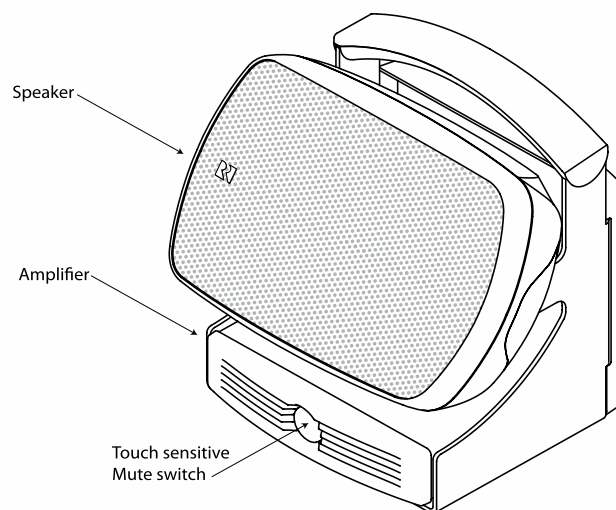


set up is a breeze

- 1 Install an Apple® AirPort Express® directly into the weather-proof APX pocket of the AirGo™ outdoor loudspeaker.
- 2 Configure the Apple AirPort Express Manual to suit your network needs.
- 3 Connect via AirPlay® on your iPhone®, iPad®, iPod Touch®, Mac® or a PC running iTunes®.
- 4 Sit back and enjoy!

Phone: +1.855.MY.AIRGO
Fax: +1.603.659.5388
Email: AirGo@Russound.com
Website: www.russound.com/airgo

To learn more about AirGo Outdoor Sound Station, scan with your Smartphone!

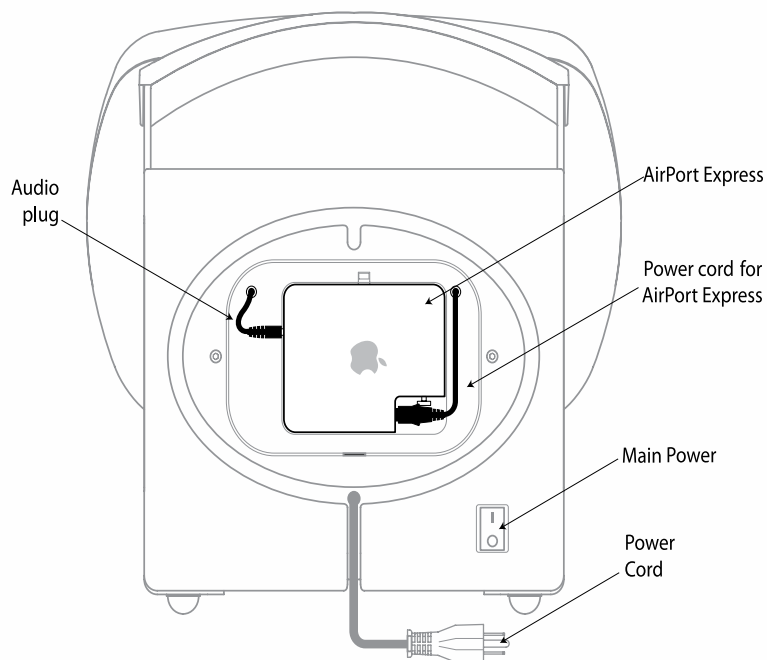

©2011 Russound. All rights reserved. All trademarks are property of their respective owners. Specifications are subject to change without notice. Patent Pending. AirPlay, AirPort Express, iPad, iPhone, iPod touch, iTunes and Mac are trademarks of Apple Inc.

Outdoor Speakers & Speaker Accessories

Outdoor audio performance that blends into any landscape and withstands the elements. The cast enclosure is made from a glass-reinforced resin to provide a sturdy, waterproof cabinet with low acoustic resonance for better sound.

89 dB (1W @ 1m), 10-100W, 8 ohms. Dimensions: 14" W x 10" H x 9.25" D (35.6 x 25.4 x 23.5 cm)

8" OutBack Rock Speakers

5R82 2-Way Rock Speakers

Shipping Weight 11 lbs (4.95 kg)

3165-533464 5R82-G Gray Granite
3165-533471 5R82-S Sandstone
3165-533600 5R82-W Weathered Granite


5R82S Single-Point-Stereo

Shipping Weight 11.2 lbs (5.04 kg)

3165-533495 5R82S-G Gray Granite
3165-533501 5R82S-S Sandstone
3165-533617 5R82S-W Weathered Granite



Rough-In Speaker Brackets

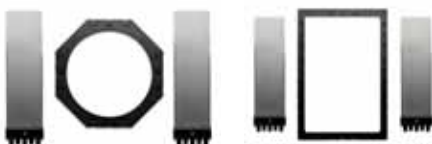

In-Ceiling

6" 3901-530722 SB-C67
6" 3901-531811 SB-C67-6P 6 Pack
8" 3901-530739 SB-C80
8" 3901-531828 SB-C80-6P 6 Pack

In-Wall

6.5" 3901-530746 SB-W60
6.5" 3901-531835 SB-W60-6P 6 Pack
3901-530760 SB-W80
3901-531859 SB-W80-6P 6 Pack

Acclaim 7 Series 8" 3-way In-Wall

3901-530791 SB-7LCR
3901-531880 SB-7LCR-6P 6 Pack

Acclaim 7 Series 8" 3-way In-Wall

 
3901-530777 SB-W83
3901-531866 SB-W83-6P 6 Pack

Acclaim 7 Series Fixed Tilt

3901-532795 SB-FT50
3901-532801 SB-FT50-6P 6 Pack

Flexbox Back Boxes

Flexbox speaker back boxes reduce background noise, provide a moisture barrier, diffuse distortion and improve sound quality. The flexible construction allows for easy installation in retrofit or new construction settings. Both models are flame retardant and meet ASTM E119 and UL 263/ NFPA 251 (1-hour) and ASTM E84/NFPA 70 standards.



FBC1-FR In-Ceiling




FBW1-FR In-Wall



- 1" (25 mm) nominal thickness, proprietary composite
- STC Rating: 32, Flame Spread: 23
- Smoke Density: 30 (ASTM E84/ NFPA 70)
- Thermal Value: R 4.2
- -40° F to 350° F (-40° C to 177° C)
- Fire Rating: CLASS 1 Fire Rated ASTM E119 /NFPA 251 and UL 263 for 1 Hour Fire Rating

- 1" (25 mm) nominal thickness, proprietary composite
- STC Rating: 32, Flame Spread: 23
- Smoke Density: 30 (ASTM E84/ NFPA 70)
- Thermal Value: R 4.2
- -40° F to 350° F (-40° C to 177° C)
- Fire Rating: CLASS 1 Fire Rated ASTM E119 /NFPA 251 and UL 263 for 1 Hour Fire Rating

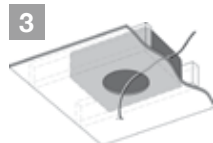

Dimensions: 14" W x 6" D x 17.5" H (355 x 152 x 445 mm)
Weight: 6.7 lbs (3 kg)
3801-531286 FBC1-FR

Dimensions: 14" W x 3.65" D x 16.5" H (368 x 89 x 406 mm)
Weight: 5.4 lb (2.4 kg)
3801-531262 FBW1-FR