





C-Series Systems

Diagram

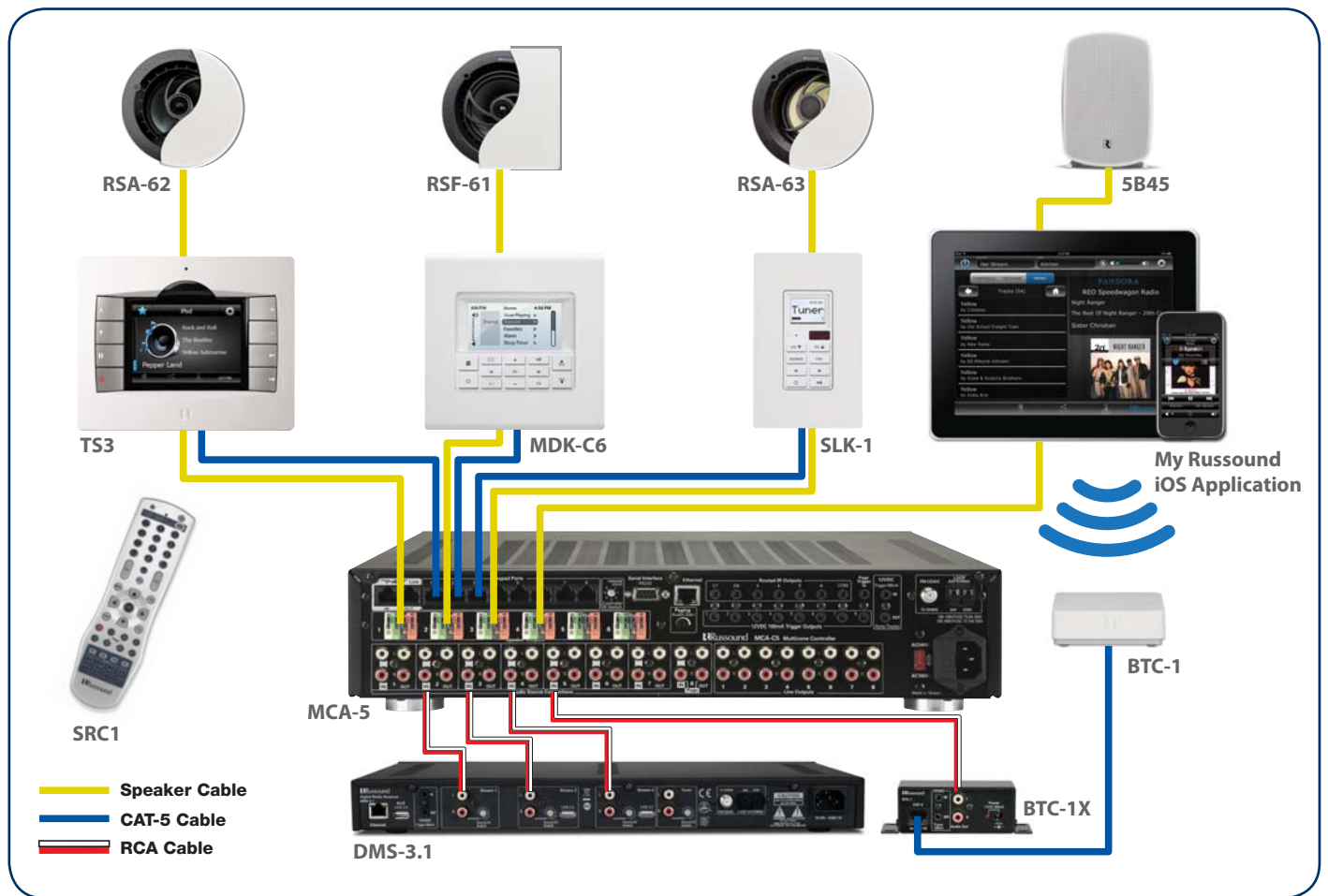

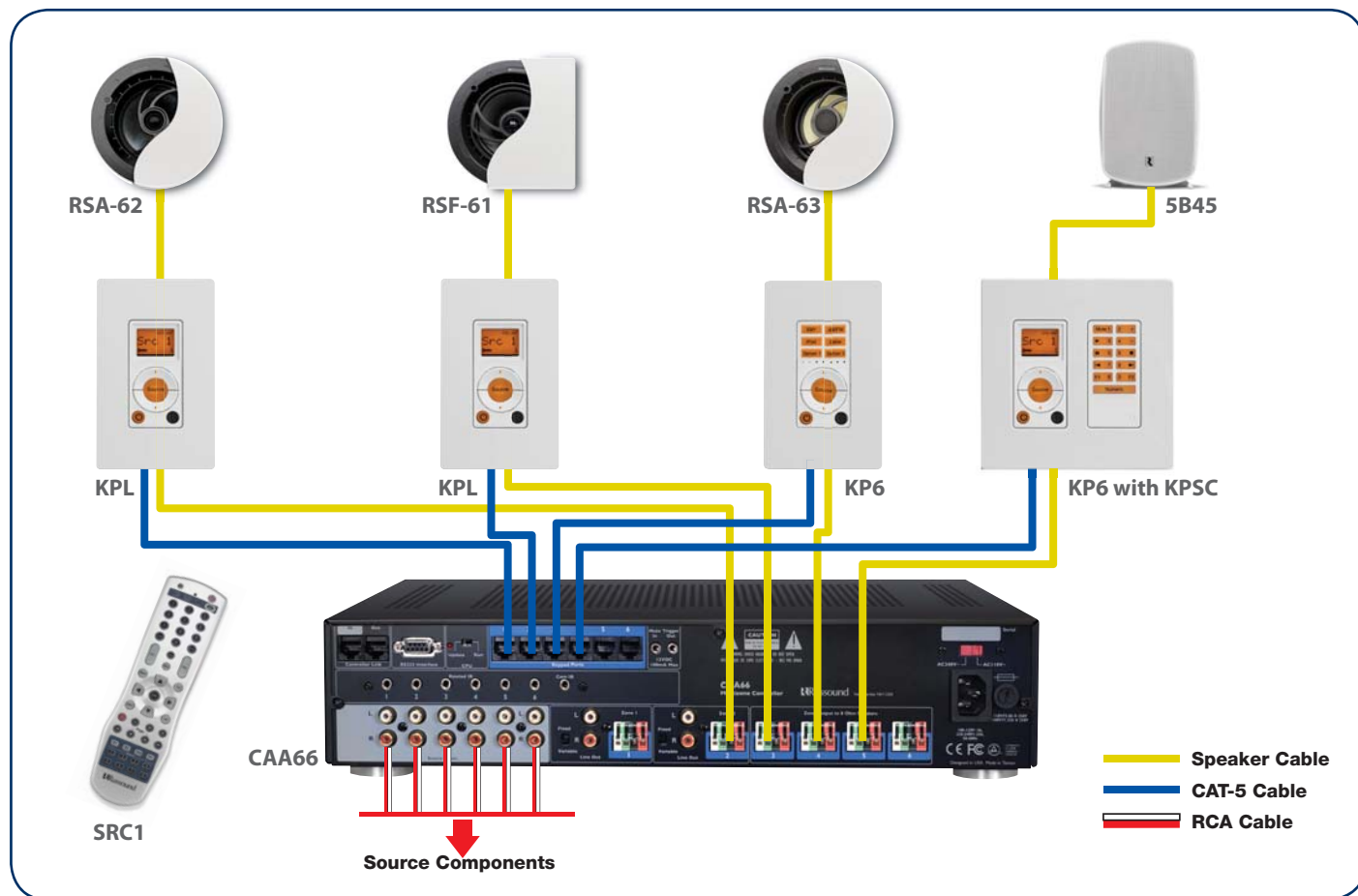

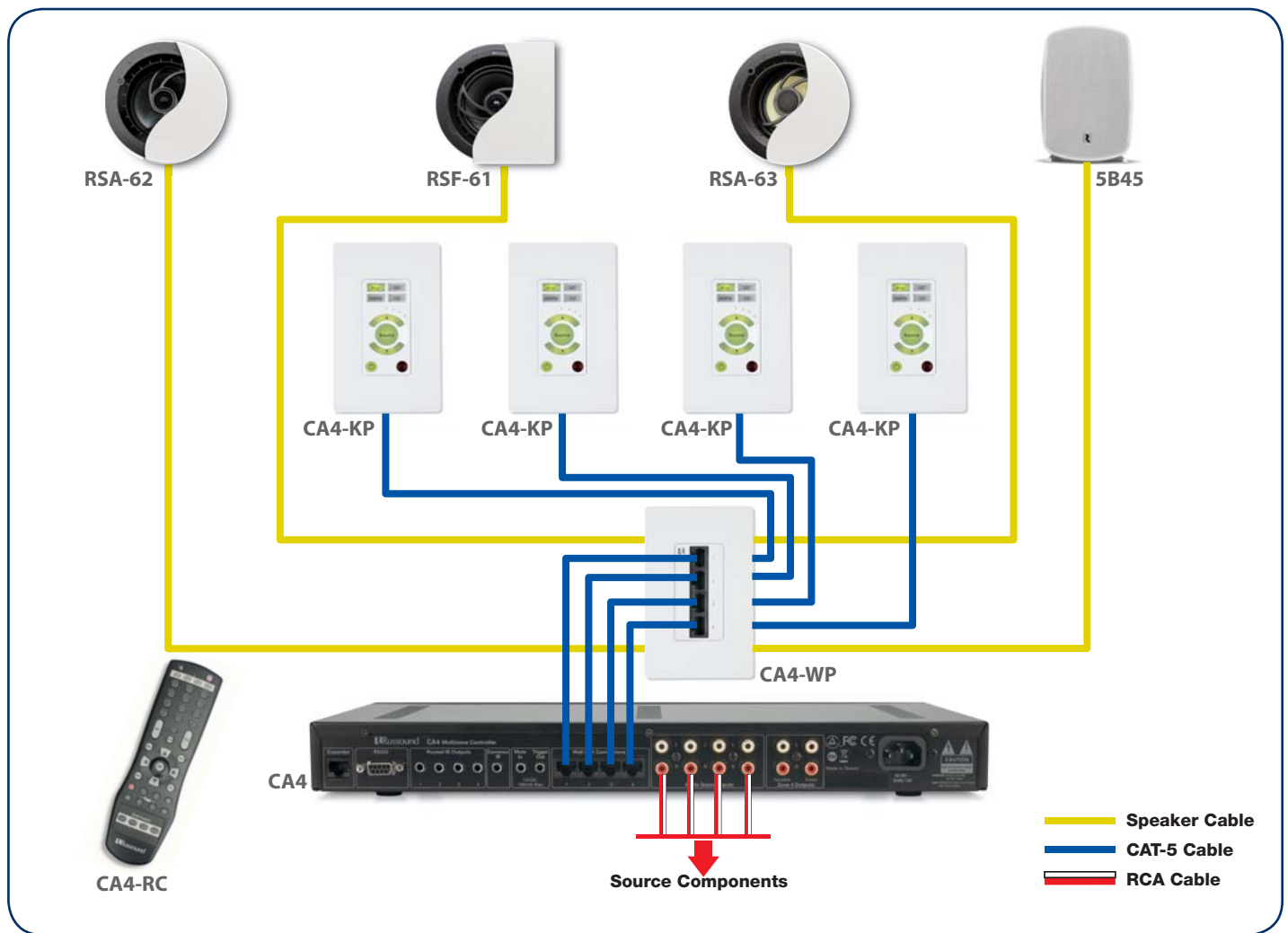

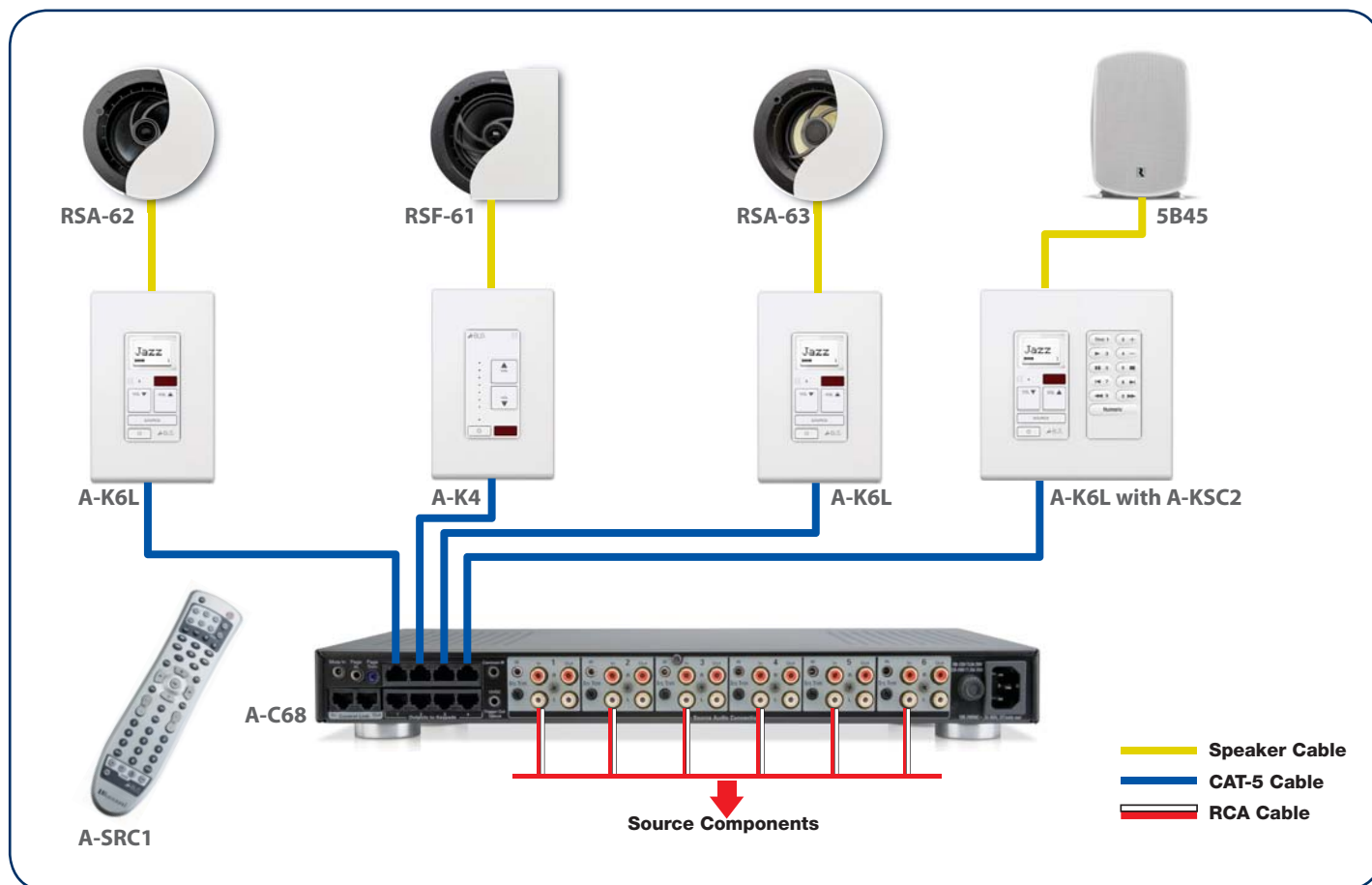



Acclaim® Thin Bezel Series

A great new look to a great speaker line. Russound Acclaim Speakers sport a thin bezel with magnetic grilles.

Like all Russound speakers, they combine acoustic technology with durability and will provide years of musical enjoyment. The speaker line provides solutions for background music, dedicated music listening and home theater.

The Acclaim Thin Bezel Series combines premium acoustic materials, with our most advanced drivers to deliver exceptional performance in every application. From background music to spectacular home theater, Acclaim Thin Bezel speakers offer the finest sound around.

Russound Acclaim Thin Bezel Series speakers feature high quality drivers, sophisticated crossover networks, and advanced designs to ensure optimum reproduction in your home, no matter what the source material may be.

* See pages 24 and 25 for a complete listing of specifications

In-Ceiling, In-Wall Flat Speakers



RSF-61 6.5" 2-Way

\$125.00/pr

Shipping Weight:
8.1 lbs (3.7 kg)

3175-533945 RSF-61
Sold in pairs



RSF-62 6.5" 2-Way

\$249.00/pr

Shipping Weight:
8.2 lbs (3.7 kg)

3175-533952 RSF-62
Sold in pairs



RSF-63 6.5" 2-Way

\$375.00/pr

Shipping Weight:
9 lbs (4.1 kg)

3175-533969 RSF-63
Sold in pairs



RSF-64 6.5" 2-Way

\$499.00/pr

Shipping Weight:
10.5 lbs (4.8 kg)

3175-533976 RSF-64
Sold in pairs



RSF-61T 6.5"
Single Point Stereo

\$149.00/ea

Shipping Weight:
5.1 lbs (2.3 kg)

3175-533983 RSF-61T
Sold individually

In-Ceiling Angled Speakers



RSA-61 6.5" 2-Way

\$199.00/ea

Shipping Weight:
4.2 lbs (1.9 kg)

3175-533914 RSA-61
Sold individually



RSA-62 6.5" 2-Way

\$299.00/ea

Shipping Weight:
4.8 lbs (2.17 kg)

3175-533921 RSA-62
Sold individually



RSA-63 6.5" 2-Way

\$399.00/ea

Shipping Weight:
5.6 lbs (2.5 kg)

3175-533938 RSA-63
Sold individually



RSG-R

\$24.99/ea

included
Shipping Weight:
0.7 lbs (0.3 kg)

3175-534287 RSG-R
Sold individually



RSG-S

\$24.99/ea

Optional
Shipping Weight:
0.7 lbs (0.3 kg)

3175-533990 RSG-S
Sold individually, separately

Grilles

Acclaim Thin Bezel

Model	Type	Woofer	Woofer Material	Tweeter	Tweeter Material	Frequency Range (-6dB/+0dB)
RSF-61	2-way in-ceiling/in-wall	6.5"/165 mm	polypropylene cone	0.75"/19 mm Pivoting	PEI	50Hz–20kHz
RSF-62	2-way in-ceiling/in-wall	6.5"/165 mm	polypropylene cone	1.0"/25 mm Pivoting	silk	50Hz–20kHz
RSF-63	2-way in-ceiling/in-wall	6.5"/165 mm	IMPP ribbed cone	1.0"/25 mm Pivoting	silk	40Hz–20kHz
RSF-64	2-way in-ceiling/in-wall	6.5"/165 mm	Kevlar cone	1.0"/25 mm Pivoting	Teteron	40Hz–20kHz
RSF-61T	Single-Point Stereo in-ceiling	6.5"/165 mm	IMPP ribbed cone	2 x 0.75"/1.9 mm	silk	40Hz–20kHz
RSA-61	15° angled 2-way in-ceiling	6.5"/165 mm	polypropylene cone	1.0"/2.5 mm Pivoting	PEI	50Hz–20kHz
RSA-62	15° angled 2-way in-ceiling	6.5"/165 mm	IMPP ribbed cone	1.0"/2.5 mm Pivoting	silk	45Hz–20kHz
RSA-63	15° angled 2-way in-ceiling	6.5"/165 mm	Kevlar cone	1.0"/2.5 mm Pivoting	Teteron	40Hz–20kHz

5 Series Outdoor

Model	Type	Woofer	Woofer Material	Tweeter	Tweeter Material	Frequency Range (-6dB/+0dB)
5B45	2-way	4"/101.6 mm	IMPP cone	1.0"/25 mm	Teteron	80Hz–20kHz
5B55	2-way	5.25"/133.4 mm	IMPP cone	1.0"/25 mm	Teteron	72Hz–20kHz
5B65	2-way	6.5"/165 mm	IMPP cone	1.0"/25 mm	Teteron	64Hz–20kHz
5B65S	Single-Point Stereo	6.5"/165 mm	IMPP cone	2 x 1.0"/25 mm	Teteron	62Hz–20kHz

Grille Type	Sensitivity dB SPL (2.83V @ 1m)	Nominal Impedance	Max Amp. Power	Feature	Cutout Dimensions	Mounting Depth	Rough-in Bracket
steel magnetic	88 dB	8 ohms	80W	Flat	8.375"/212.7mm	3.49"/88.6mm	SB-C67
steel magnetic	90 dB	8 ohms	90W	Flat	8.375"/212.7mm	3.49"/88.6mm	SB-C67
steel magnetic	90 dB	8 ohms	100W	Flat	8.375"/212.7mm	3.53"/89.7mm	SB-C67
steel magnetic	90 dB	8 ohms	120W	Flat	8.375"/212.7mm	3.69"/93.7mm	SB-C67
steel magnetic	90 dB	8 ohms	120W	Flat	8.375"/212.7mm	3.69"/93.7mm	SB-C67
steel magnetic	90 dB	8 ohms	80W	15° angled	8.375"/212.7mm	4.28"/108.7mm	SB-C67
steel magnetic	90 dB	8 ohms	100W	15° angled	8.375"/212.7mm	4.40"/111.8mm	SB-C67
steel magnetic	90 dB	8 ohms	120W	15° angled	8.375"/212.7mm	4.56"/115.8mm	SB-C67

Grille Type	Sensitivity dB SPL (2.83V @ 1m)	Nominal Impedance	Max Amp. Power	Surface mount	Pole Mount	Bookshelf Stand
Aluminum	88 dB	8 ohm	100W	Yes	Yes	Yes
Aluminum	90 dB	8 ohm	125W	Yes	Yes	Yes
Aluminum	91 dB	8 ohm	150W	Yes	Yes	Yes
Aluminum	91 dB	8 ohm	150W	Yes	Yes	No

Speaker Selectors

Speaker selectors are an efficient, cost-effective means of expanding the audio system in your home or office. From four to twelve rooms, with or without volume controls, multiple A/B amplifier inputs to automatic A/B switching devices, Russound speaker selectors can be used to accommodate a number of applications from the simple to sophisticated.

Single Source Selectors



SS-4.2 4 Pair

\$119.00

100W/channel RMS, zone labels. 4 Ω stable amplifiers & receivers. Resettable circuit protection. Impedance bypass switch for use with impedance matching volume controls.

Dimensions:
8.5" W x 1.875" H x 6.25" D
(220 x 48 x 160 mm)

Shipping Weight: 2.75 lbs
(1.2 kg)

3630-520679 SS-4.2



SS-6.2 6 Pair

\$159.00

70W/channel RMS, zone labels. 4 Ω stable amplifiers & receivers. Resettable circuit protection. Impedance bypass switch for use with impedance matching volume controls.

Dimensions:
11.5" W x 1.875" H x 6.25" D
(295 x 48 x 160 mm)

Shipping Weight: 3.5 lbs (1.6 kg)

3630-520686 SS-6.2



SDB-2.1 2 Pair

\$199.00

100W/channel RMS. Color-coded detachable 14-gauge snap connector. Standard configuration is 4x, and installer may change configuration to 2x or 8x. Zone identifying labels included.

Dimensions:
8.5" W x 3" H x 6.25" D
(220 x 80 x 160 mm)

Shipping Weight: 5.5 lbs (2.5 kg)

3615-604010 SDB-2.1



SDB-4.1 4 Pair

\$399.00

200W/channel RMS. Color-coded detachable 14-gauge snap connectors. Standard configuration is 4x, and installer may change configuration to 2x or 8x. Zone identifying labels included.

Dimensions:
17" W x 3" H x 6.25" D
(435 x 80 x 160 mm)

Shipping Weight: 2.75 lbs
(1.2 kg)

3615-604027 SDB-4.1



SDB-6.1 6 Pair

\$499.00

150W/channel RMS, zone label. 4 Ω stable amplifiers & receivers. Resettable circuit protection.

Dimensions:
17" W x 3" H x 6.25" D
(435 x 80 x 160 mm)

Shipping Weight:
11 lbs (5 kg)

3615-604034 SDB-6.1

Autoformer-Based Selectors/Impedance Matching



PRO-6 HP 6 Pair

\$319.00

100W/channel RMS with subsonic filter built in. Color-coded detachable 14-gauge snap connectors. Zone labels included.

Dimensions:
17" W x 2.875" H x 8" D (435 x 75 x 205 mm)

Shipping Weight: 9.5 lbs (4.3 kg)

3610-603075 PRO-6 HP



PRO-8 HP 8 Pair

\$349.00

100W/channel RMS with subsonic filter, built in. Color-coded detachable 14-gauge snap connectors. Zone labels included.

Dimensions:
17" W x 2.875" H x 8" D (435 x 75 x 205 mm)

Shipping Weight: 10 lbs (4.5 kg)

3610-603136 PRO-8 HP



PRO-12 HP 12 Pair

\$449.00

100W/channel RMS with subsonic filter built in. Color-coded detachable 14-gauge snap connectors. Zone labels included.

Dimensions:
17" W x 2.875" H x 8" D (435 x 75 x 205 mm)

Shipping Weight: 10 lbs (4.5 kg)

3610-603037 PRO-12 HP

Miscellaneous Speaker Selectors



AB-2.2
Tabletop
Dual-Source

\$79.00

A single pair of speakers to be driven by either of two amplifiers or allow a single amplifier to drive either of two pairs of speakers.

Dimensions:
5.5" W x 2.875" H x 3" D (140 x 73.5 x 76.5 mm)

Shipping Weight: 1.25 lbs (0.57 kg)

3699-520525 AB-2.2



AB-3.2 Source Selector

\$139.00

Automatic A/B speaker selector, speaker level switching, selectable delay and sensitivity. Color-coded detachable 14-gauge snap connectors. Detachable 12v DC power supply.

Dimensions:
6.25" W x 2" H x 1.55" D (159 x 51 x 39 mm)

Shipping Weight: 1.7 lbs (0.8 kg)

3699-520914 AB-3.2



AB-1.2 Dual-Source

\$79.00

Allows a single pair of speakers to be driven by either of two amplifiers or allow a single amplifier to drive either of two pairs of speakers. Decora® wallplate not included.

Dimensions:
1" W x 2.75" H x 1.75" D (25.5 x 70 x 44.5 mm)

Shipping Weight: 3 oz (85 g)

3699-520501 White AB-1.2

3699-520532 Almond AB-1.2

3699-520556 Bone AB-1.2

3699-521294 Brown AB-1.2

3699-521317 Black AB-1.2