



ELECTRONIC/GLASS FUSES

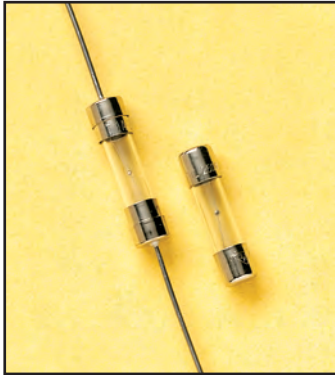

SMG / SMG-V

Glass Body
Fast Acting
5 x 15mm 2AG
1-1/2" Axial Leads Optional

1/10A & 3/8A, 250VAC, UL Listed CSA Certified
1/8A through 7A, 350VAC, UL and CSA Recognized
8A & 10A, 125VAC

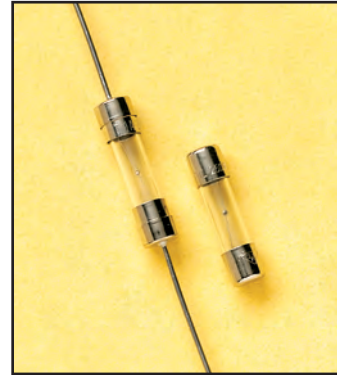

STG / STG-V

Glass Body
Time Delay
5 x 15mm 2AG
1-1/2" Axial Leads Optional

3/8A 250VAC, UL Listed and CSA Certified
1/4A through 7A, 350VAC, UL and CSA Recognized

C

Standard Fuse Ampere Ratings

| CATALOG NUMBER | AXIAL LEAD CAT. NO | AMPERE RATING | VOLTS | I.R. |
|----------------|--------------------|---------------|-------|------|
| SMG1/10 | SMG-V1/10 | 1/10A | 250V | 1 |
| SMG1/8 | SMG-V1/8 | 1/8A | 350V | 2 |
| SMG1/4 | SMG-V1/4 | 1/4A | 350V | 2 |
| SMG3/8 | SMG-V3/8 | 3/8A | 250V | 1 |
| SMG1/2 | SMG-V1/2 | 1/2A | 350V | 2 |
| SMG3/4 | SMG-V3/4 | 3/4A | 350V | 2 |
| SMG1 | SMG-V1 | 1A | 350V | 2 |
| SMG1-1/2 | SMG-V1-1/2 | 1-1/2A | 350V | 2 |
| SMG2 | SMG-V2 | 2A | 350V | 2 |
| SMG2-1/2 | SMG-V2-1/2 | 2-1/2A | 350V | 2 |
| SMG3 | SMG-V3 | 3A | 350V | 2 |
| SMG3-1/2 | SMG-V3-1/2 | 3-1/2A | 350V | 2 |
| SMG4 | SMG-V4 | 4A | 350V | 2 |
| SMG5 | SMG-V5 | 5A | 350V | 2 |
| SMG6 | SMG-V6 | 6A | 350V | 2 |
| SMG7 | SMG-V7 | 7A | 350V | 2 |
| SMG8 | SMG-V8 | 8A | 125V | 3 |
| SMG10 | SMG-V10 | 10A | 125V | 3 |

1. 250VAC @ 35A I.R./125VAC @ 10kA I.R.
2. 350VAC @ 100A I.R./140VDC @ 150A I.R.
3. 125VAC @ 10kA I.R.

Standard Fuse Ampere Ratings

| CATALOG NUMBER | AXIAL LEAD CAT. NO | AMPERE RATING | VOLTS | I.R. |
|----------------|--------------------|---------------|-------|------|
| STG1/4 | STG-V1/4 | 1/4A | 350V | 2 |
| STG3/8 | STG-V3/8 | 3/8A | 250V | 1 |
| STG1/2 | STG-V1/2 | 1/2A | 350V | 2 |
| STG6/10 | STG-V6/10 | 6/10A | 350V | 2 |
| STG3/4 | STG-V3/4 | 3/4A | 350V | 2 |
| STG8/10 | STG-V8/10 | 8/10A | 350V | 2 |
| STG1 | STG-V1 | 1A | 350V | 2 |
| STG1-1/4 | STG-V1-1/4 | 1-1/4A | 350V | 2 |
| STG1-1/2 | STG-V1-1/2 | 1-1/2A | 350V | 2 |
| STG2 | STG-V2 | 2A | 350V | 2 |
| STG2-1/2 | STG-V2-1/2 | 2-1/2A | 350V | 2 |
| STG3 | STG-V3 | 3A | 350V | 2 |
| STG3-1/2 | STG-V3-1/2 | 3-1/2A | 350V | 2 |
| STG4 | STG-V4 | 4A | 350V | 2 |
| STG5 | STG-V5 | 5A | 350V | 2 |
| STG6 | STG-V6 | 6A | 350V | 2 |
| STG7 | STG-V7 | 7A | 350V | 2 |

1. 250VAC @ 35A I.R./125VAC @ 10kA I.R.
2. 350VAC @ 100A I.R./125VAC @ 10kA I.R.
3. 1140V DC @ 150A I.R.