

# Panelboards

## A-Series™ Panelboards

### Product Options

## Section 11

### Enclosure Options

**BOX EXTENSIONS**—For additional end gutter space or conduit skirt applications—see page 11-20.

### Equipment Grounds—Factory Supplied with Panelboard

Description	Product Number
Field installed kits	
Standard bonded to box—for each 12 branch positions	TGL2
Copper bonded to box—for each 12 branch positions	TGC2
Standard-isolated/insulated—for each 12 branch positions	EGS12
Copper-isolated/insulated—for each 12 branch positions	EGC12
Main lug for above terminal kits	TGL20

### Optional Equipment Grounds

Description	Product Number
Aluminum Extruded Bonded	AEBG
Copper Extruded Bonded	AEBGC
Aluminum Extruded Isolated	AEIG
Copper Extruded Isolated	AEIGC
Copper Isolated/Bonded	ASPGIBC

### THQB/THHQB/THQL/THHQL/TEY Filler Plates

#### Product Number

TQLFP1

### TQD/THQD/TED4/SE/FB Filler Plates

#### Product Number

TEDFP1

### Breaker Mounting<sup>1</sup> Hardware Kits

Description	Product Number
Breaker type TED/THED4/SE	ASPTED3P
Breaker type TQD/THQD	ASPTQD3P
Breaker type FB—for mounting 12 poles	ASPFB12p <sup>2</sup>
Breaker type FB—for mounting 3 poles	ASPFB3P <sup>3</sup>

<sup>1</sup>Use to mount breaker in existing space.

<sup>2</sup>Includes mounting screws and washers only.


<sup>3</sup>Includes screws, washers and A-Series panelboard connectors.




AEBG



AEBGC

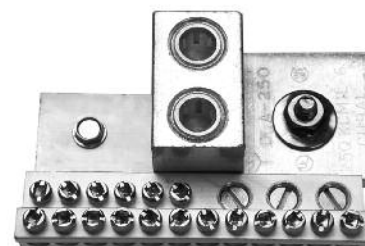

AEIG

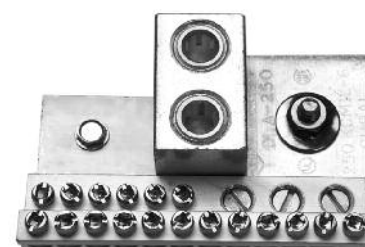

AEIGC



ASPGIBC

