




## Multi-Function Push Buttons



### Selection Process

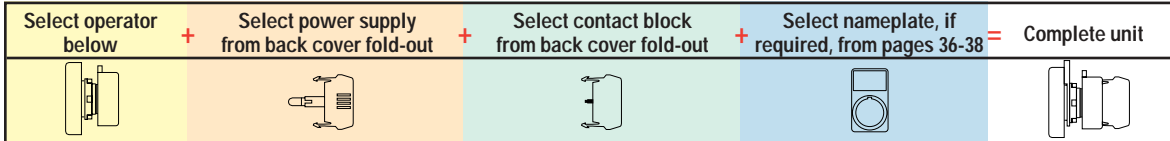


### NEMA 1 Operators


Color	Type	Marking	Illuminated & Non-illuminated	
			Catalog No.	List Price, GO-10GC
Black Top, Red Bottom	Flush	None	P9DPLNRG00	\$21.50
		Top - I Bottom-0	P9DPLNRG01	21.50
	Flush Top, Extended Bottom	None	P9DPLNRS00	21.50
		Top - I Bottom-0	P9DPLNRS01	21.50
Green Top, Red Bottom	Flush	None	P9DPLVRG00	21.50
		Top - I Bottom-0	P9DPLVRG01	21.50
	Flush Top, Extended Bottom	None	P9DPLVRS00	21.50
		Top - I Bottom-0	P9DPLVRS01	21.50

### Rubber boot for conversion of multi-function push buttons (flush type only) to NEMA 3, 3R, 3S, 4, 4X, 12 & 13 and IP66


Description	Catalog No.	List Price, GO-10GC
Silicone rubber boot for use with flush operators	080CPDT	\$5.00

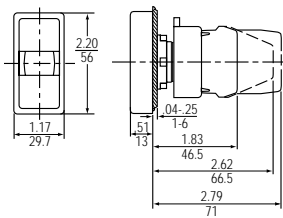

Double Push Button  
(Top & Bottom Flush)

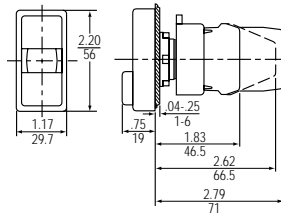

Double Push Button  
(Top Flush & Bottom Extended)

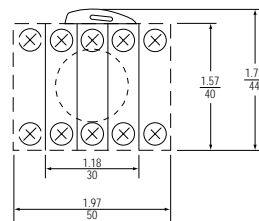

Typical Back Side View

Dimensions shown in  $\frac{\text{inches}}{\text{millimeters}}$