



# Plastic Enclosures, Nameplates, Contact Blocks & Power Supplies For Base-Mounted Pilot Devices

(NEMA 1, 3, 3R, 3S, 4, 4X, 12, 13 & IP66)

For use with operators from pages 9-61 to 9-81.

**Plastic Enclosures—Use only with P9S or P9X plastic operators.**

Holes	Color	Catalog No.	List Price, GO-10GC
1	Gray With Yellow Cover	P9EPEG1	\$15.00
1	Gray	P9EPE01	15.00
2	Gray	P9EPE02	17.50
3	Gray	P9EPE03	22.50
4	Gray	P9EPE04	32.00
6	Gray	P9EPE06	49.00

### Ground Terminal

Catalog No.	List Price, GO-10GC
P9AEMT	\$1.00

### Legend Plates For Plastic Enclosures (Self-adhesive, black background)

List Price \$1.50 each, GO-10GC							
Symbol		English		French		Spanish	
Symbol	Catalog No.	Legend	Catalog No.	Legend	Catalog No.	Legend	Catalog No.
→	P9AELN006	Stop	P9AELN201	Arret	P9AELN301	Cerrar	P9AELN501
I	P9AELN028	Start	P9AELN202	Arriere	P9AELN302	Adelante	P9AELN502
0	P9AELN029	Down	P9AELN203	Avant	P9AELN303	Izquierda	P9AELN504
II	P9AELN035	Up	P9AELN204	Descente	P9AELN304	Bajar	P9AELN505
III	P9AELN038	Close	P9AELN205	Droite	P9AELN305	Abrir	P9AELN506
0-I	P9AELN039	Open	P9AELN206	Gauche	P9AELN306	Subir	P9AELN507
I-0-II	P9AELN042	On	P9AELN212	Marche	P9AELN308	Atras	P9AELN508
		Off	P9AELN213	Fermer	P9AELN309	Derecha	P9AELN509
		Forward	P9AELN214	Manuel	P9AELN312	Marcha	P9AELN510
		Reverse	P9AELN215	Ouvrir	P9AELN316	Paro	P9AELN511
		Auto	P9AELN219			Rapido	P9AELN512
		Left	P9AELN222			Rearme	P9AELN515
		Right	P9AELN224			Linea	P9AELN523

Type	Catalog No.	List Price Each, GO-10GC
Blank	P9AELN	\$ .50
Custom engraved, seven characters maximum	P9AELNEN	8.00

① Package quantity is five; order in multiples of five.

### Base-Mount Power Supplies (Screw Terminals Only)




Replace asterisk (\*) in LED catalog number with code from LED colors table below.

Type	Voltage AC/DC	Catalog No. With Incandescent Bulb	List Price, GO-10GC	Catalog No. With LED	List Price, GO-10GC	Catalog No. With Neon Bulb	List Price, GO-10GC
Full-Voltage	No Lamp	P9PDNBO	\$17.50	—	—	—	—
	6	P9PDNBA	21.00	P9PDNBAL*	\$36.00	—	—
	12	P9PDNBB	21.00	P9PDNBBL*	36.00	—	—
	24	P9PDNBD	21.00	P9PDNBDL*	36.00	—	—
	48	P9PDNBG	21.00	P9PDNBGL*	36.00	—	—
	60	P9PDNBH	21.00	—	—	—	—
	110	—	—	—	—	P9PDNBIN	\$25.00
	120	—	—	—	—	P9PDNBIL*	36.00
	130	P9PDNBL	21.00	—	—	—	—
	220	—	—	—	—	P9PDNBMN	25.00
Standard Resistor	110-120	P9PRNBJ	14.00	—	—	—	—
	220-240	P9PRNBN	14.00	—	—	—	—
Diode Resistor	220-240	P9PRDBN	35.00	—	—	—	—
Long-Life Resistor	110-120	P9PRLBJ	35.00	—	—	—	—

② AC only.

③ Must be used with P9PDNBH full-voltage power supply (wired-in series).

④ Must be used with P9PDNBL full-voltage power supply (wired-in series).

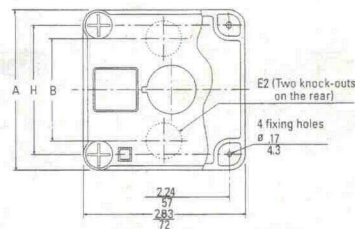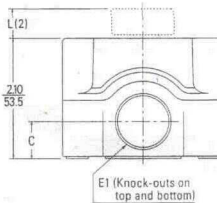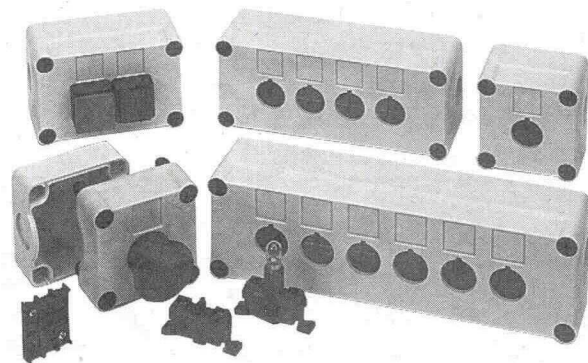



### Dimensions (in./mm)

Holes	Center Distance		A		B		C		E1 Ø		E2 Ø		H	
	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm
1	—	—	2.83	72	1.81	46	.65	16.5	.91	23	.61	15.5	2.24	57
2	1.18	30	4.33	110	3.07	78	.65	16.5	.91	23	.85	21.5	3.74	95
3	1.18	30	5.51	140	4.25	108	.65	16.5	.91	23	.85	21.5	4.92	125
4	1.18	30	6.89	175	5.63	143	.65	16.5	.91	23	.85	21.5	6.30	160
6	1.18	30	9.25	235	7.87	200	.77	19.5	1.14	29	.91	23	8.66	220

⑤ 1-, 2-, 3-, and 4-hole enclosures suitable for cable gland, with locknut, PG16 or 1/2" NPT. 6-hole enclosure suitable for cable gland, with locknut, PG21 or 3/4" NPT.

### Base-Mount Contact Blocks (Screw Terminals Only)

Type	Contacts	Catalog No.	List Price, GO-10GC
Base-Mount	1NO	P9B10BN	\$7.50
Base-Mount	1NC	P9B01BN	7.50

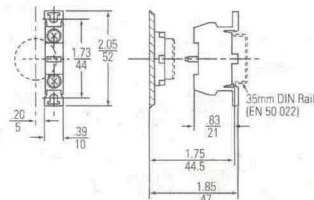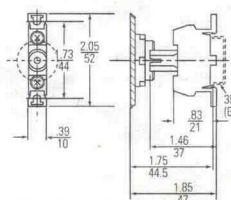

**Base Mount Power Supply**

**Base Mount Contact Blocks With Screw Terminals**

### \* LED Colors

Colors	Red	Green	Yellow	Orange	White	Blue
*Color code	R	V	G	A	B	L




**GE Push Buttons**

# C-2000™ Push Buttons

600 Volts Max. AC/300 Volts Max. DC  
10 Amps. Continuous AC/2.5 Amps. Continuous DC


## Sheet Steel & Stainless Steel Enclosures

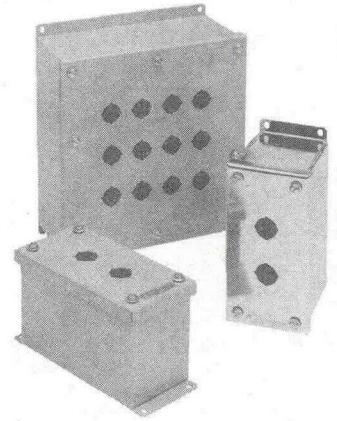

Holes	Sheet Steel		Stainless Steel		Dimensions (inches/mm)						
	Catalog No.	List Price, GO-10GC	Catalog No.	List Price, GO-10GC	A	B	C	D	E	F	Hub (inches)
1	080HEG11	\$ 42.00	080HES11	\$102.00	5.50/139.7	3.50/88.9	4.25/108.0	5.00/127.0	2.38/60.4	.31/7.9	3/4
2	080HEG12	45.00	080HES12	120.00	7.75/196.8	3.50/88.9	4.25/108.0	7.25/184.2	2.38/60.4	.31/7.9	3/4
3	080HEG13	48.00	080HES13	132.00	10.00/254.0	3.50/88.9	4.25/108.0	9.50/241.3	2.38/60.4	.31/7.9	3/4
4	080HEG14	54.00	080HES14	156.00	13.38/339.8	3.50/88.9	4.25/108.0	12.88/327.2	2.38/60.4	.31/7.9	1
6	080HEG32	72.00	080HES32	198.00	8.25/209.6	6.50/165.1	4.25/108.0	7.75/196.8	5.88/149.4	.31/7.9	1
9	080HEG33	84.00	080HES33	312.00	10.50/266.7	9.25/235.0	4.25/108.0	10.00/254.0	5.88/149.4	.31/7.9	1 1/4
12	080HEG43	108.00	080HES43	336.00	10.50/266.7	9.25/235.0	4.25/108.0	10.00/254.0	8.19/208.0	.31/7.9	1 1/2
16	080HEG44	138.00	080HES44	432.00	12.75/323.8	11.50/292.1	4.25/108.0	12.25/311.2	8.19/208.0	.31/7.9	1 1/2
24	080HEG64	216.00	080HES64	660.00	12.75/323.8	11.50/292.1	4.25/108.0	12.25/311.2	10.38/263.6	.31/7.9	1 1/2
30	080HEG65	240.00	080HES65	780.00	15.00/381.00	11.50/292.1	4.25/108.0	14.50/368.3	10.38/263.6	.38/9.6	1 1/2



### Special Assembled Unwired Stations

Holes	Sheet Steel		Stainless Steel	
	Catalog No.	List Price, GO-10GC	Catalog No.	List Price, GO-10GC
1	080HEG11B	\$ 60.00	080HES11B	\$120.00
2	080HEG12B	69.00	080HES12B	144.00
3	080HEG13B	78.00	080HES13B	162.00
4	080HEG14B	90.00	080HES14B	192.00
6	080HEG32B	120.00	080HES32B	246.00
9	080HEG33B	150.00	080HES33B	378.00
12	080HEG43B	192.00	080HES43B	420.00
16	080HEG44B	246.00	080HES44B	540.00
24	080HEG64B	378.00	080HES64B	822.00
30	080HEG65B	432.00	080HES65B	972.00

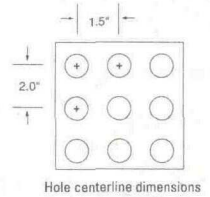

When ordering assembled, unwired stations, specify units and nameplates by hole position as shown below. Prices do not include operators, terminals, nameplates, etc.

### Hole Arrangements

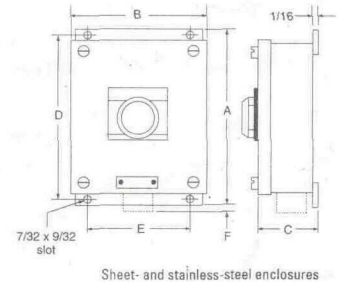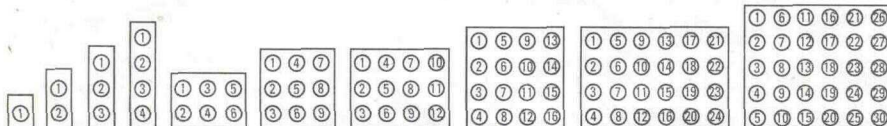

9 PUSH BUTTONS