


Molded Case Circuit Breakers Industrial Circuit Breakers

15-150A Circuit Breakers
Electronic Trip
Spectra® RMS
SE150 Line Circuit Breakers

Product Number Structure

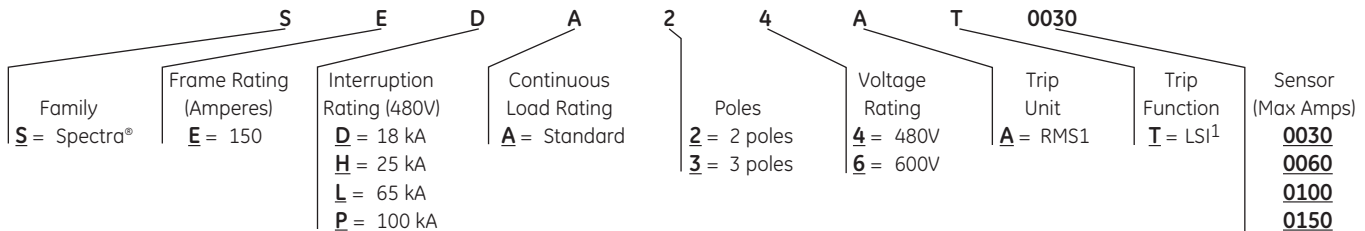

¹Adjustable Instantaneous with Tracking Short Time (Long Time established via Interchangeable Rating Plugs).
Note: This information is provided for interpreting product numbers (it should not be used to build product numbers).

SE150 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350 SED, SEH; 2-Pole, UL/CSA: 150A, 480 Vac Max., IEC 947-2: 160A, 415 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)		
Adj. Inst. Ampere Rating	Trip Range	Inst. Amps	Product Number	List Price GO-1355	UL 489 IC @480 Vac		UL 489 IC @480 Vac			Product Number	List Price GO-1355	Wire Range
					Current Sensor	Product Number	List Price GO-1355	Product Number	List Price GO-1355			
15	43	182	SRPE30A15	\$106.00	30	SEDA24AT0030	\$214.00	SEHA24AT0030	\$530.00	TCAL18	\$3.00	12-3/0 Cu 12-3/0 Al
20	58	254	SRPE30A20	\$106.00								
25	73	332	SRPE30A25	\$106.00								
30	87	415	SRPE30A30	\$106.00								
40	118	501	SRPE60A40	\$106.00								
50	148	637	SRPE60A50	\$106.00	60	SEDA24AT0060	\$214.00	SEHA24AT0060	\$530.00			
60	178	777	SRPE60A60	\$106.00								
70	206	863	SRPE100A70	\$106.00								
80	236	999	SRPE100A80	\$106.00	100	SEDA24AT0100	\$312.00	SEHA24AT0100	\$634.00			
90	267	1138	SRPE100A90	\$106.00								
100	297	1280	SRPE100A100	\$106.00								
110	328	1426	SRPE150A110	\$106.00	150	SEDA24AT0150	\$837.00	SEHA24AT0150	\$1427.00			
125	374	1640	SRPE150A125	\$106.00								
150	450	1991	SRPE150A150	\$106.00								

SE150 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350 SEL, SEP²; 2-Pole, UL/CSA: 150A, 480 Vac Max., IEC 947-2: 160A, 415 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)		
Adj. Inst. Ampere Rating	Trip Range	Inst. Amps	Product Number	List Price GO-1355	UL 489 IC @480 Vac		UL 489 IC @480 Vac			Product Number	List Price GO-1355	Wire Range
					Current Sensor	Product Number	List Price GO-1355	Product Number	List Price GO-1355			
15	43	182	SRPE30A15	\$106.00	30	SELA24AT0030	\$549.00	SEPA24AT0030	\$895.00	TCAL18	\$3.00	12-3/0 Cu 12-3/0 Al
20	58	254	SRPE30A20	\$106.00								
25	73	332	SRPE30A25	\$106.00								
30	87	415	SRPE30A30	\$106.00								
40	118	501	SRPE60A40	\$106.00								
50	148	637	SRPE60A50	\$106.00	60	SELA24AT0060	\$549.00	SEPA24AT0060	\$895.00			
60	178	777	SRPE60A60	\$106.00								
70	206	863	SRPE100A70	\$106.00								
80	236	999	SRPE100A80	\$106.00	100	SELA24AT0100	\$744.00	SEPA24AT0100	\$1179.00			
90	267	1138	SRPE100A90	\$106.00								
100	297	1280	SRPE100A100	\$106.00								
110	328	1426	SRPE150A110	\$106.00	150	SELA24AT0150	\$1808.00	SEPA24AT0150	\$2777.00			
125	374	1640	SRPE150A125	\$106.00								
150	450	1991	SRPE150A150	\$106.00								

²SEL, SEP UL current limiting.
Note: All Spectra® breakers UL listed as HACR type.
All Spectra® breakers marked CE.



Molded Case Circuit Breakers Industrial Circuit Breakers

15-150A Circuit Breakers

Electronic Trip

Spectra® RMS

SE150 Line Circuit Breakers

Section 3

Page Updated 11 / 2008

SE150 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350

SED, SEH; 3-Pole, UL/CSA: 150A, 600 Vac Max., IEC 947-2: 160A, 690 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)		
					UL 489 IC @480 Vac		UL 489 IC @480 Vac					
					18kA		25kA					
Ampere Rating	Adj. Inst. Trip Range Amps		Product Number	List Price GO-135S	Current Sensor	Product Number	List Price GO-135S	Product Number	List Price GO-135S	Product Number	List Price GO-135S	Wire Range
	Low	High										
15	43	182	SRPE30A15	\$106.00	30	SEDA36AT0030	\$382.00	SEHA36AT0030	\$632.00	TCAL18	\$3.00	12-3/0 Cu
20	58	254	SRPE30A20	\$106.00								
25	73	332	SRPE30A25	\$106.00								
30	87	415	SRPE30A30	\$106.00								
40	118	501	SRPE60A40	\$106.00								
50	148	637	SRPE60A50	\$106.00	60	SEDA36AT0060	\$382.00	SEHA36AT0060	\$632.00			12-3/0 Al
60	178	777	SRPE60A60	\$106.00								
70	206	863	SRPE100A70	\$106.00								
80	236	999	SRPE100A80	\$106.00	100	SEDA36AT0100	\$492.00	SEHA36AT0100	\$734.00			
90	267	1138	SRPE100A90	\$106.00								
100	297	1280	SRPE100A100	\$106.00								
110	328	1426	SRPE150A110	\$106.00	150	SEDA36AT0150	\$1253.00	SEHA36AT0150	\$1815.00			
125	374	1640	SRPE150A125	\$106.00								
150	450	1991	SRPE150A150	\$106.00								

SE150 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350

SEL, SEP¹; 3-Pole, UL/CSA: 150A, 600 Vac Max., IEC 947-2: 160A, 690 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)		
					UL 489 IC @480 Vac		UL 489 IC @480 Vac					
					65kA		100kA					
Ampere Rating	Adj. Inst. Trip Range Amps		Product Number	List Price GO-135S	Current Sensor	Product Number	List Price GO-135S	Product Number	List Price GO-135S	Product Number	List Price GO-135S	Wire Range
	Low	High										
15	43	182	SRPE30A15	\$106.00	30	SELA36AT0030	\$753.00	SEPA36AT0030	\$1189.00	TCAL18	\$3.00	12-3/0 Cu
20	58	254	SRPE30A20	\$106.00								
25	73	332	SRPE30A25	\$106.00								
30	87	415	SRPE30A30	\$106.00								
40	118	501	SRPE60A40	\$106.00								
50	148	637	SRPE60A50	\$106.00	60	SELA36AT0060	\$753.00	SEPA36AT0060	\$1189.00			12-3/0 Al
60	178	777	SRPE60A60	\$106.00								
70	206	863	SRPE100A70	\$106.00								
80	236	999	SRPE100A80	\$106.00	100	SELA36AT0100	\$895.00	SEPA36AT0100	\$1482.00			
90	267	1138	SRPE100A90	\$106.00								
100	297	1280	SRPE100A100	\$106.00								
110	328	1426	SRPE150A110	\$106.00	150	SELA36AT0150	\$2165.00	SEPA36AT0150	\$3477.00			
125	374	1640	SRPE150A125	\$106.00								
150	450	1991	SRPE150A150	\$106.00								

¹SEL, SEP UL current limiting.

Note: All Spectra® breakers UL listed as HACR type.

All Spectra® breakers marked CE.

SE 150 Reference Publications

Plug-in Mounting Base	GEH-4610
STDA Flange Handle	GEH-5314
Rating Plug	GEH-5549
Shunt Trip and Undervoltage Release	GEH-5551
Spectra® E-Frame Installation Instruction	GEH-5591
Auxiliary Switch and Bell Alarm	GEH-5593
TDR Operating Mechanism	GEH-5609
TDM Operating Mechanism	GEH-5611
Motor Operator	GEH-5613
Mechanical Interlock	GEH-5615
STDA Operating Mechanism	GEH-5684
Cable Operator Mechanism	GEH-6290
Lug	GEJ-3051
Padlocking Device - Standard	GEJ-3056
Back Connected Studs	GEJ-3609
SE150 Outline Drawing	168D1109SH1



Publications and Reference: See Section 22 for a complete list of additional product-related publications