


Molded Case Circuit Breakers Industrial Circuit Breakers

300-1200A Circuit Breakers
Electronic Trip
Spectra® RMS

Product Number Structure

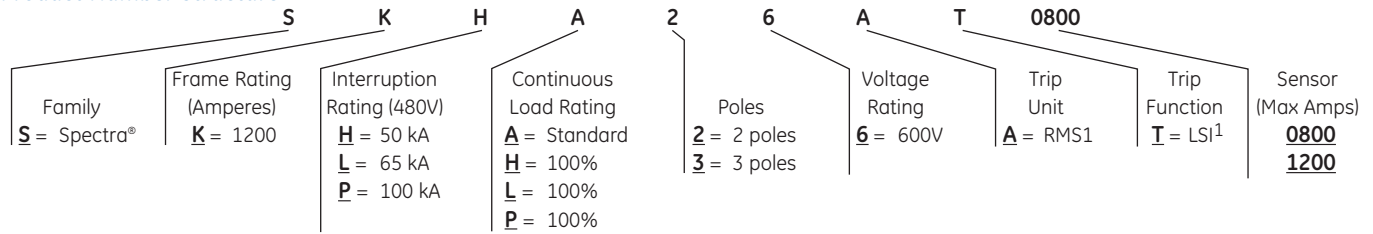

¹Adjustable Instantaneous with Tracking Short Time (Long Time established via Interchangeable Rating Plugs).

Note: This information is provided for interpreting product numbers (it should not be used to build product numbers).

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 800A, 600 Vac Max., IEC 947-2:800A 690 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)			
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	List Price GO-1355	Current Sensor	Poles	UL 489 IC @480 Vac		UL 489 IC @480 Vac		Product Number	List Price GO-1355	Wire Range
	Low	High					50kA	65kA					
300	940	3015	SRPK800A300	\$106.00	800	2	SKHA26AT0800	\$3377.00	SKLA26AT0800	\$4301.00	TCAL81	\$47.00	(3) 3/0-500 Cu
400	1255	4015	SRPK800A400	\$106.00			Product Number	List Price GO-1355	Product Number	List Price GO-1355			
500	1570	5020	SRPK800A500	\$106.00		3	SKHA36AT0800	\$4323.00	SKLA36AT0800	\$5234.00	TCAL81	\$47.00	(3) 3/0-500 Al
600	1875	6195	SRPK800A600	\$106.00									
700	2155	7420	SRPK800A700	\$106.00									
800	2440	8705	SRPK800A800	\$106.00									

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 800A, 600 Vac Max., IEC 947-2:800A 690 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)			
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	List Price GO-1355	Current Sensor	Poles	UL 489 IC @480 Vac		Product Number	List Price GO-1355	Product Number	List Price GO-1355	Wire Range
	Low	High					100kA						
300	940	3015	SRPK800A300	\$106.00	800	2	SKPA26AT0800	\$6746.00	SKPA36AT0800	\$8240.00	TCAL81	\$47.00	(3) 3/0-500 Cu
400	1255	4015	SRPK800A400	\$106.00			Product Number	List Price GO-1355					
500	1570	5020	SRPK800A500	\$106.00		3	SKPA36AT0800	\$8240.00	TCAL81	\$47.00	(3) 3/0-500 Al		
600	1875	6195	SRPK800A600	\$106.00									
700	2155	7420	SRPK800A700	\$106.00									
800	2440	8705	SRPK800A800	\$106.00									

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 1200A, 600 Vac Max., IEC 947-2: 1250A, 690 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)			
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	List Price GO-1355	Current Sensor	Poles	UL 489 IC @480 Vac		UL 489 IC @480 Vac		Product Number	List Price GO-1355	Wire Range
	Low	High					50kA	65kA					
600	1825	6110	SRPK1200A600	\$106.00	1200	2	SKHA26AT1200	\$7057.00	SKLA26AT1200	\$7958.00	TCAL125	\$76.00	(4) 250-500 Cu
700	2125	7125	SRPK1200A700	\$106.00			Product Number	List Price GO-1355	Product Number	List Price GO-1355			
800	2430	8145	SRPK1200A800	\$106.00		3	SKHA36AT1200	\$7679.00	SKLA36AT1200	\$8586.00	TCAL125	\$76.00	(4) 250-500 Al
900	2735	9160	SRPK1200A900	\$106.00									
1000	3040	10180	SRPK1200A1000	\$106.00									
1200	3650	12215	SRPK1200A1200	\$106.00									

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 1200A, 600 Vac Max., IEC 947-2: 1250A, 690 Vac Max.

Rating Plug					Frame					Terminal Lugs for Front Connection (Cu/Al)			
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	List Price GO-1355	Current Sensor	Poles	UL 489 IC @480 Vac		Product Number	List Price GO-1355	Product Number	List Price GO-1355	Wire Range
	Low	High					100kA						
600	1825	6110	SRPK1200A600	\$106.00	1200	2	SKPA26AT1200	\$10136.00	SKPA36AT1200	\$11183.00	TCAL125	\$76.00	(4) 250-500 Cu
700	2125	7125	SRPK1200A700	\$106.00			Product Number	List Price GO-1355					
800	2430	8145	SRPK1200A800	\$106.00		3	SKPA36AT1200	\$11183.00	TCAL125	\$76.00	(4) 250-500 Al		
900	2735	9160	SRPK1200A900	\$106.00									
1000	3040	10180	SRPK1200A1000	\$106.00									
1200	3650	12215	SRPK1200A1200	\$106.00									

Note: All Spectra® breakers UL listed as HACR type.

All Spectra® breakers marked CE.



Publications and Reference: See Section 22 for a complete list of additional product-related publications

Molded Case Circuit Breakers Industrial Circuit Breakers

300-1200A Circuit Breakers
Electronic Trip
Spectra® RMS

Section 3

Page Updated 11 / 2008

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350

100% UL Rated, 3-Pole: 800A, 600 Vac Max.; IEC 947-2: 800A, 690 Vac Max.

Rating Plug					Frame									
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	List Price GO-1355	UL 489 IC @480 Vac		UL 489 IC @480 Vac		UL 489 IC @480 Vac		UL 489 IC @480 Vac			
	Low	High			50kA		65kA		100kA		100kA			
					Current Sensor	Poles	Product Number	List Price GO-1355	Product Number	List Price GO-1355	Product Number	List Price GO-1355		
300	940	3015	SRPK800A300	\$106.00										
400	1255	4015	SRPK800A400	\$106.00										
500	1570	5020	SRPK800A500	\$106.00	800	3	SKHH36AT0800	\$7514.00	SKLL36AT0800	\$9325.00	SKPP36AT0800	\$10712.00		
600	1875	6195	SRPK800A600	\$106.00										
700	2155	7420	SRPK800A700	\$106.00										
800	2440	8705	SRPK800A800	\$106.00										

Terminal Lugs for Front Connection (Cu/Al)

Product Number	Wire Range	List Price GO-1355
	(3) 3/0-500 Cu	
TCAL81		\$47.00
	(3) 3/0-500 Al	

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350

100% UL Rated, 3-Pole: 1200A, 600 Vac Max.; IEC 947-2: 100A, 690 Vac Max.

Rating Plug					Frame									
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	List Price GO-1355	UL 489 IC @480 Vac		UL 489 IC @480 Vac		UL 489 IC @480 Vac		UL 489 IC @480 Vac			
	Low	High			50kA		65kA		100kA		100kA			
					Current Sensor	Poles	Product Number	List Price GO-1355	Product Number	List Price GO-1355	Product Number	List Price GO-1355		
600	1825	6110	SRPK1200A600	\$106.00										
700	2125	7125	SRPK1200A700	\$106.00										
800	2430	8145	SRPK1200A800	\$106.00	1200	3	SKHH36AT1000	\$11051.00	SKLL36AT1000	\$13678.00	SKPP36AT1000	\$14538.00		
900	2735	9160	SRPK1200A900	\$106.00										
1000	3040	10180	SRPK1200A1000	\$106.00										
1200	3650	12215	SRPK1200A1200	\$106.00										
						3	SKHH36AT1200 ¹	\$11450.00	SKLL36AT1200 ¹	\$14250.00	SKPP36AT1200 ¹	\$15235.00		

Terminal Lugs for Front Connection (Cu/Al)

Product Number	Wire Range	List Price GO-1355
	(4) 250-500 Cu	
TCAL125		\$76.00
	(4) 250-500 Al	

¹100% UL rated SK1200 supplied with back-connected assembly which increases breaker depth. Refer to outline drawings for details.

Lugs not required

Note: All Spectra® breakers UL listed as HACR type.

All Spectra® breakers marked CE.

SK1200 Reference Publications

Plug-in Mounting Base	GEH-4342
STDA Flange Handle	GEH-5314
Rating Plug	GEH-5549
Shunt Trip and Undervoltage Release	GEH-5551
Spectra® K-Frame Installation Instruction	GEH-5592
Auxiliary Switch and Bell Alarm	GEH-5593
TDR Operating Mechanism	GEH-5610
TDM Operating Mechanism	GEH-5612
Motor Operator	GEH-5614
STDA Operating Mechanism	GEH-5684
Lug Cover	GEH-5699
Mechanical Interlock	GEH-5874
Padlocking Device - Standard	GEH-5877
Cable Operator Mechanism	GEH-6291
Back Connected Studs	GEJ-3619
SK1200 Outline Drawings	208C1757SH1
SK1200 Outline Drawings (1200A 100%)	168D1678SH2

